


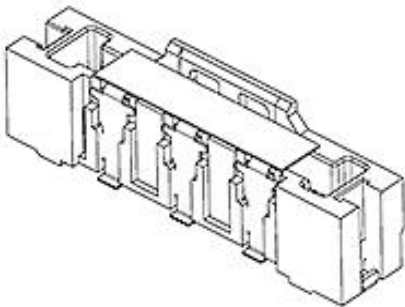

Part Number : [5017864080](#)
Product Description : Easy-On FFC/FPC-to-Board Connector, 0.50mm Pitch, Receptacle Housing Assembly, Vertical, Surface Mount, without Grounding Terminals, Tin-Bismuth Plating, 40 Circuits
Series Number : 501786
Status : Active
Product Category : FFC / FPC Connectors



Documents and Resources

Drawings

[5017864080 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

[5017864080.dxf](#)

Specifications

[SPK-501786-001-001.pdf](#)

[PS-501786-002-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	501786
Description	Easy-On FFC/FPC-to-Board Connector, 0.50mm Pitch, Receptacle Housing Assembly, Vertical, Surface Mount, without Grounding Terminals, Tin-Bismuth Plating, 40 Circuits
Comments	Requires a custom FFC/FPC with notches
Product Name	Easy-On
UPC	887191250656

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Actuator Type	Flexi-Latch
Circuits (Loaded)	40

Color - Resin	Black
Contact Position	N/A
Durability (mating cycles max)	20
Mated Height	8.95mm
Material - Metal	Copper Alloy
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	Liquid Crystal Polymer (LCP)
Net Weight	671.548/mg
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	Yes
PCB Mounting	Surface Mount
PCB Retention	No
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

Mates With / Use With

Use with Part(s)

Description	Part Number
0.50mm Pitch FFC-to-Board Plug Jacket, 40 Circuits	<u>5017834009</u>
0.50mm Pitch FFC-to-Board Plug Jacket Cover, 40 Circuits	<u>5017844009</u>

This document was generated on Jun 06, 2026