


Data Sheet | Item Number: 272-104/101-000
Power supply connector; without push-buttons; without snap-in mounting feet; with screw-type ground contact; 4-pole; 2,50 mm²; white
<https://www.wago.com/272-104/101-000>



Color: white

Similar to illustration

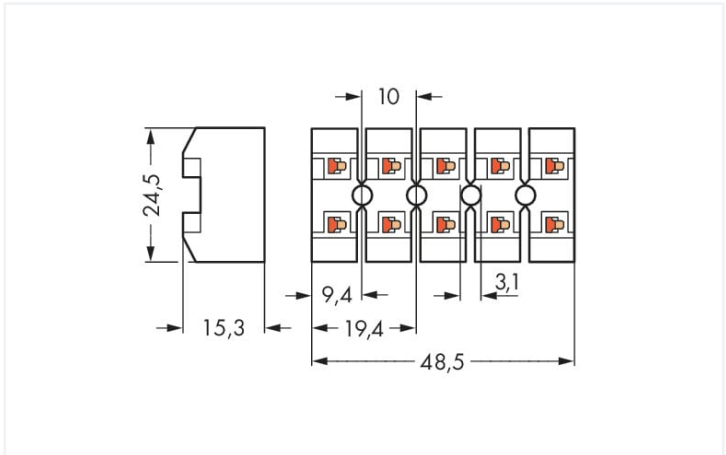

Dimensions in mm

Electrical data

Ratings per IEC/EN	
Ratings per	IEC/EN 60664-1
Rated voltage (III/2)	400 V
Rated impulse voltage (III/2)	4 kV
Rated current	18 A
Legend (ratings)	(III / 2) Δ Overvoltage category III / Pollution degree 2

Connection data

Connection points	16
Total number of potentials	4
Number of connection types	1

Connection 1	
Connection technology	PUSH WIRE®
Strip length	8 ... 9 mm / 0.31 ... 0.35 inches
Pole number	4

Physical data

Width	38.5 mm / 1.516 inches
Height	15.3 mm / 0.602 inches
Depth	24.5 mm / 0.965 inches

Material Data

Note (material data)		Information on material specifications can be found here
Color	white	
Material group	I	
Insulation material	Polyamide (PA66)	
Flammability class per UL94	V0	
Fire load	0.189 MJ	
Weight	12.6 g	



Commercial data		
Product Group	8 (Misc. Chassis Mount Blocks)	
eCl@ss 10.0	27-14-11-04	
eCl@ss 9.0	27-14-11-04	
ETIM 8.0	EC000446	
ETIM 7.0	EC000446	
PU (SPU)	500 pcs	
Packaging type	Box	
Country of origin	DE	
GTIN	4044918437028	
Customs tariff number	85369010000	

Approvals / Certificates		
General approvals		
		
Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2 No. 158	70048844

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 272-104/101-000	

Documentation			
Additional Information			
Technical Section	03.04.2019	pdf 1949.09 KB	

1 Compatible Products
1.1 Optional Accessories
1.1.1 Ferrule



1.1.1.1 Pin terminal



Item No.: 209-157
Pin terminals; insulated; suitable for 271 and 272 Series; blue



Item No.: 209-151
Pin terminals; insulated; suitable for 271 and 272 Series; green



Item No.: 209-164
Pin terminals; insulated; suitable for 271 and 272 Series; natural

1.1.2 Installation

1.1.2.1 Mounting accessories



Item No.: 271-702
Pins; for plate thickness 1 mm



Item No.: 271-711
Pins; for plate thickness 1 mm



Item No.: 271-712
Pins; for plate thickness 1.5 mm

1.1.3 Marking

1.1.3.1 Marking devices



Item No.: 210-110
Fiber-tip pen

1.1.4 Tool

1.1.4.1 Operating tool



Item No.: 271-120
Push-button; white