


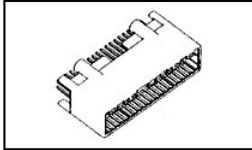

1376111-7 Product Details

[Share](#) | [Print](#) | [Email](#)

1376111-7

TE Internal Number: 1376111-7

 **Active**
[View 3D PDF](#)

0.025 Series and Hybrid Connectors and Contacts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Connector
- Connector Assembly
- Connector Style = Receptacle
- Contact Type = Tab
- Receptacle Configuration = 025

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [025 SERIES 24 POSITION \(PCB V-TYPE\) CAP HOUSING ASSEMBLY](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [025 IDC Connectors \(1\)](#) (PDF, Japanese)
- [025 IDC Connectors \(2\)](#) (PDF, Japanese)
- [025 SERIES I/O CONNECTORS \(H-Type V-Type 2Row, W... \(1\)](#) (PDF, Japanese)
- [025 SERIES I/O CONNECTORS \(H-Type V-Type 2Row, W... \(2\)](#) (PDF, Japanese)
- [0.64III SERIES CONNECTOR 2ROW \(1\)](#) (PDF, Japanese)
- [0.64III SERIES CONNECTOR 2ROW \(2\)](#) (PDF, Japanese)

Application Specifications:

- [Crimping of 025 Receptacle Contact](#) (PDF, Japanese)

Instruction Sheets:

- [025 SERIES I/O CONNECTORS \(H-Type, V-Type 2Row\) \(1\)](#) (PDF, Japanese)
- [025 SERIES I/O CONNECTORS \(H-Type, V-Type 2Row\) \(2\)](#) (PDF, Japanese)

CAD Files: (CAD Format & Compression Information)

- [2D Drawing](#) (DXF, Version B5)
- [3D Model](#) (IGES, Version B5)
- [3D Model](#) (STEP, Version B5)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- Connector Type = Connector Assembly
- [Receptacle Configuration](#) = 025
- [Mount](#) = Printed Circuit Board
- PCB Mounting Orientation = Straight

Body Features:

- [Number of Positions](#) = 24

Contact Features:

- Contact Type = Tab
- [Contact Mating Area Plating \(Signal\)](#) = Selective Tin
- Contact Base Material = Brass

Housing Features:

- Connector Style = Receptacle
- [Housing Material](#) = PBT - GF
- [Housing Color](#) = Natural

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- [Applies To](#) = Printed Circuit Board

Packaging Features:

- [Packaging Method](#) = Paper Box, Tube

Other:

- Brand = Tyco Electronics

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:

[Twitter](#) [Facebook](#) [Flickr](#) [LinkedIn](#) [YouTube](#)

Visit Us On:

