

# Plug-In Outlet Center® Units

## Plug-In Outlet Center Units

**Wiremold®** Plug-In Outlet Center Units bring power safely and conveniently to wherever you need it. These units are ideal for use in a wide variety of settings, including relay racks and cabinets, laboratories, workshops, classrooms and offices.

Plug-In Outlet Center Units include rack mount, CabinetMATE®, compact, 90 degree, deluxe control, industrial, and international units. Units are available in 15 Amp configurations.




16291 (Front & Back)

### FEATURES & BENEFITS

- **User-ready outlets.** Plug-In Outlet Center units provide power distribution in a portable, plug-in unit.
- **Rugged construction.** Durable 2" x 1 3/4" [44mm x 51mm] or 3 1/2" x 2" [89mm x 44mm] aluminum housing. Some Plug-In Outlet Center Units are available with an impact resistant plastic housing.
- **Space saving.** Rack mount units fit standard 19" [482mm] relay racks. Compact 1U design takes up minimum space.
- **Low profile.** CabinetMATE units offer a narrow 1 1/2" x 1 3/16" [38mm x 20mm] aluminum housing.
- **Aesthetically pleasing.** Rack mount units have a black matte finish and a black cord. CabinetMATE compact and industrial units have a gray finish and a black cord.
- **Flexible mounting.** Each unit features one of four different mounting types. Each mounting method has been designed to optimize the performance of the product. Complete mounting hardware and installation instructions are included with every unit.
- **Cord properly rated to load requirements.** 15A units have a 14/3 SJT cord and a NEMA 5-15P plug.
- **Lighted switch.** Most units have lighted on/off switch(es) to control power to the unit.
- **Resettable circuit breaker.** Provides overload protection.
- **Two year product warranty.**
- **UL and cUL Listed or Recognized.** Units are UL and cUL Listed to UL1363 standards. Rack mount units are UL and cUL Recognized to UL1363 standards.


### 15A RACK MOUNT PLUG-IN OUTLET CENTERS

Part No.	Description/Specifications
16291 16292	<b>Rack Mount Plug-In Outlet</b> Eight rear outlets, lighted switch. Receptacles rotated 90° and four outlets spaced to accommodate transformers. 6' (1.8m) (16291) or 15' (4.6m) (16292) cord. Receptacle center-to-center 1 1/2" (38mm) and 2" (51mm). Color: Black

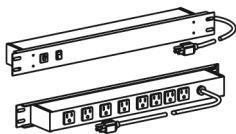


### COMPACT PLUG-IN OUTLET CENTERS

Part No.	Description/Specifications
16303 16304	<b>Compact Plug-In Outlet Center</b> Six outlets, lighted switch. 6' (1.8m) (16303) or 15' (4.6m) (16304) cord Length 12 1/4" (311mm). Receptacle center-to-center 1 1/4" (32mm). Color: Aluminum Gray

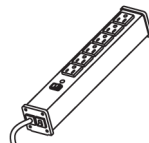


### COMPACT PLUG-IN OUTLET CENTERS

Part No.	Description/Specifications
16295 16296	<b>Compact Plug-In Outlet Center</b> Six outlets, lighted switch. 6' (1.8m) (16303) or 15' (4.6m) (16304) cord Length 12 1/4" (311mm). Receptacle center-to-center 1 1/4" (32mm). Color: White

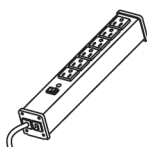

### MOUNTING TYPES

 Part No.	Description/Specifications
Snap-on/Slide-off	<b>Mounting Bracket</b> Mount unit in any position. Includes two aluminum mounting clips that snap onto mounting rails on the back of the unit. Screws also included. Used for all units with 2" (51mm) housing.



**Note:** For UL units.

## C2G & WIREMOLD PART NUMBER CHART

C2G Part Number	Wiremold Part Number	Item Description: Rack Mount Power
16291	J08B0B	Black Rack Mount 8-Outlet 15A Power Strip - 6ft
16292	J08B2B	Black Rack Mount 8-Outlet 15A Power Strip - 15ft
16295	R610	White 6-Outlet Power Strip - 6ft
16296	R612	White 6-Outlet Power Strip - 15ft
16303	UL207BC	Aluminum Gray 6-Outlet Power Strip - 6ft
16304	UL207BD	Aluminum Gray 6-Outlet Power Strip - 15ft



**CABLES TO GO**

Cables To Go  
3555 Kettering Blvd.  
Moraine, OH 45439  
Phone: 800.287.2843  
[www.c2g.com](http://www.c2g.com)

Follow Us

