


Part Number : [190710229](#)
Product Description : InsulKrimp Ring Tongue
Terminal for 6 AWG Wire, Carton
Series Number : 19071
Status : Active
Product Category : Ring and Spade Terminals
Engineering Part Number : E-660-56X

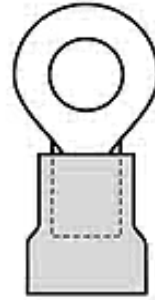

Documents and Resources

Drawings

[190710229_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


Specifications

[PS-19902-009-001.pdf](#)

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2020)4578-DC (25 June 2020) |
| EU RoHS | Compliant per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC

- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | Ring and Spade Terminals |
| Series | 19071 |
| Description | InsulKrimp Ring Tongue Terminal for 6 AWG Wire, Carton |
| Keyword | Ring Terminal, Ring Terminals |
| Product Name | InsulKrimp |
| Style | Ring |
| Type | Ring Terminal |
| UPC | 800753071889 |

Agency

| | |
|----|--------|
| UL | E32244 |
|----|--------|

Physical

| | |
|---------------------------|---------|
| Barrel Type | Closed |
| Color - Resin | Natural |
| Flammability | 94V-0 |
| Insulation | PVC |
| Material - Plating Mating | Tin |
| Net Weight | 5.655/g |
| Packaging Type | Carton |

| | |
|-----------------------------|----------------------|
| Plating min - Mating | 2.540µm |
| Plating min - Termination | 2.540µm |
| Stud Size | 5/16" (M8) |
| Termination Interface Style | Crimp or Compression |
| Wire Insulation Diameter | 11.20mm max. |
| Wire Size (AWG) | 6 |

Application Tooling

Global

| Description | Part Number |
|--|------------------|
| PremiumGrade Hand Crimp Tool for 8-2 AWG Terminals | <u>640013900</u> |

This document was generated on Apr 29, 2026