


Solder pin angled .370" with mounting bracket and threaded lock

Directive 2002/95/EC
„RoHS“
Compliant

(click on the schematic(s) for a more detailed view)

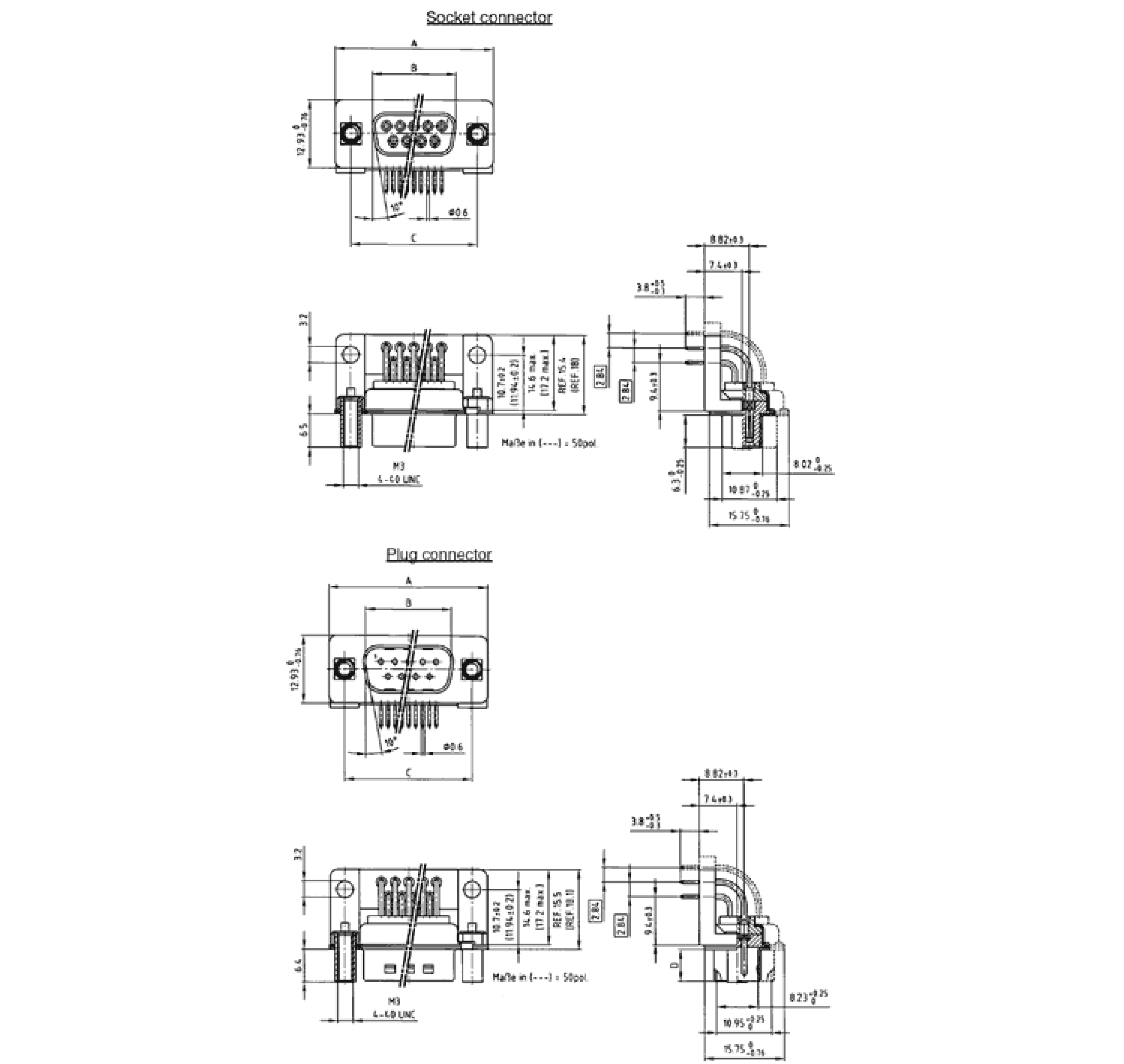

Socket connector:

No. of pos.	A -0,76	B-0,25	C
9	31,19	16,46	25,00 ^{+0,12} _{-0,13}
15	39,52	24,79	33,30 ^{+0,15} _{-0,10}
25	53,42	38,50	47,04 ^{±0,13}
37	69,70	54,96	63,50 ^{±0,13}
50	67,31	52,55	61,10 ^{+0,14} _{-0,11}

Plug connector:

No. of pos.	A -0,76	B+0,25	C	D -0,30
9	31,19	16,79	25,00 ^{+0,12} _{-0,13}	6,12
15	39,52	25,12	33,30 ^{+0,15} _{-0,10}	6,12
25	53,42	38,84	47,04 ^{±0,13}	5,99
37	69,70	55,30	63,50 ^{±0,13}	5,99
50	67,31	52,68	61,10 ^{+0,14} _{-0,11}	5,99

Part Numbers

No.of Pos.	Socket connector tin - plated	
	UNC 4 - 40	M 3
9	164 A 11609 X	164 A 13049 X
15	164 A 11619 X	164 A 13059 X
25	164 A 11629 X	164 A 13069 X
37	164 A 11639 X	164 A 13079 X
50	164 A 12269 X	164 A 15549 X

No.of Pos.	Plug connector tin -plated with ground indent	
	UNC 4 - 40	M 3
9	163 A 14409 X	163 A 14569 X
15	163 A 14419 X	163 A 14579 X
25	163 A 14529 X	163 A 14589 X
37	163 A 14299 X	163 A 14599 X
50	163 A 14279 X	163 A 15169 X