

## HARTING IE Cat.7A 4x2xAWG26/7 PUR, 1000m

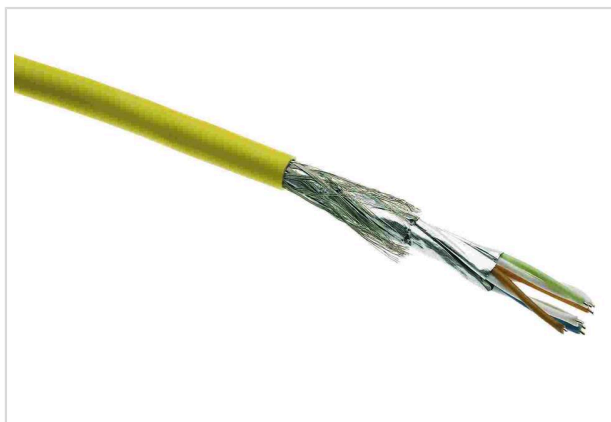


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 600 0751
Specification	HARTING IE Cat.7A 4x2xAWG26/7 PUR, 1000m
HARTING eCatalogue	<a href="https://b2b.harting.com/09456000751">https://b2b.harting.com/09456000751</a>

### Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (round)

### Version

Cable length	1,000 m
Number of cores	8
Core structure	4x 2x AWG 26/7

### Technical characteristics

Transmission characteristics	Cat. 7 Class II up to 2000 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Limiting temperature	-40 ... +70 °C unmoved -10 ... +50 °C moved
Conductor resistance @ 20 °C	≤120 Ω/km

### Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Yellow



**Pushing Performance**  
Since 1945

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

## Commercial data

Packaging size	1,000
Net weight	53 g
Country of origin	Germany
European customs tariff number	85444290
GTIN	5713140273757
ETIM	EC003249
eCl@ss	27061801 Data and communication cable (copper)