


Color: ■ light gray

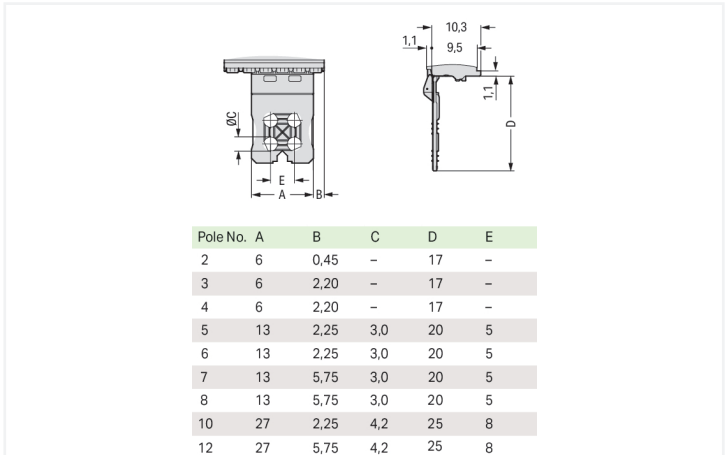

Dimensions in mm

Physical data

Pin spacing	3.5 mm / 0.138 inches
Width	13 mm

Mechanical data

Design	with sliding connector release
--------	--------------------------------

Material data

Note (material data)	Information on material specifications can be found here
Color	light gray
Flammability class per UL94	V0
Fire load	0.011 MJ
Weight	0.3 g

Commercial data

PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821437246
Customs tariff number	85389099990

Product classification

UNSPSC	39121409
--------	----------



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance
2091-1602/002-000

↓

Documentation

Additional Information

Technical Section	03.04.2019	pdf 2027.26 KB	↓
-------------------	------------	-------------------	---

Installation Notes

Strain relief



Gripping plates are suitable for factory and field assembly.