

01

0107



DIN circular connectors



DIN chassis socket with bayonet lock, shielded, with metal housing, flange and solder terminals


01

0107

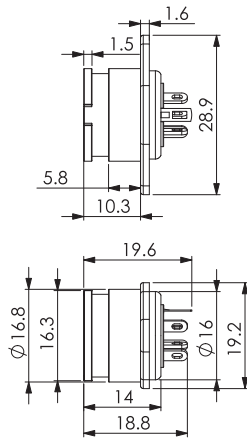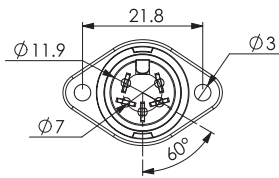


Pin configurations, solder side view

 DIN 41524




0107 03

 


0107 04

 DIN 41524




0107 05

 DIN 45322




0107 05-1

 DIN 45329



0107 07-1

 DIN 45326



0107 08-1

Environmental conditions

Temperature range -25 °C/+80 °C

Materials

Insulating body PA, V-0 according to UL94
 Contact spring CuZn, silver-plated
 Shielding contact Cu, nickel-plated
 Housing Zn alloy, nickel-plated

Mechanical data

Mating cycles 1000
 Insertion force ≤ 50 N
 Withdrawal force ≥ 5 N

Electrical data (at T_{amb} 20 °C)

Contact resistance ≤ 30 mΩ (contact spring)
 ≤ 50 mΩ (housing)
 Rated current 4 A
 Rated voltage 100 V AC
 Rated impulse voltage 250 V AC RMS/60 s
 Insulation resistance ≥ 100 MΩ

Associated products

Counterparts
 ☞ 0131 ☞ 0132 ☞ 0134

01

0107

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
0107 03	3	50	150
0107 04	4	50	150
0107 05	5	50	150
0107 05-1	5	50	150
0107 07-1	7	50	150
0107 08-1	8	50	150

Packaging:

in individual plastic bags, in a cardboard box