


## YAV14H1, Uninsulated Ring Terminal For 16 - 14 AWG

By Burndy

Catalog # [YAV14H1](#)

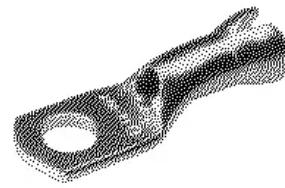

Copper Compression Lug, Heavy Duty, Ring Tongue with Shroud, 1 Hole w/ Inspection Hole, AN 20-14, #6-#8 Stud, Short Barrel, Tin Plated.

### Features

- Manufactured from seamless pure electrolytic copper tubing to provide maximum conductivity, low resistance and excellent ductility for crimping
- Seamless tubular crimp barrel design - No seams to split resulting in a very high quality electrical connection, also can be used on solid conductor
- Double thick tongue structurally a very strong terminal tongue
- Produced from tubular copper, extra copper material assures the compression connector will operate cooler than the conductors it connects
- Internally bevelled barrel for easy cable entry, especially for flexible conductors
- Inspection hole provides easy visual check for proper conductor insertion
- Electro-tin plated for a long lasting durable corrosion resistance

### Application

For Use On Copper Commercial (Code) Cable, Type AN Aircraft Cable And Extra Flexible Conductors

### General

Catalog Number	YAV14H1
Connector Type	Ring Terminal
EU RoHS Indicator	Yes
Feature - Barrel Style	Shrouded
Feature - Barrel Type	Standard
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810024966
UPC 14 Digit GTIN	00781810024966

### Dimensions

Dimension - B Length fraction	1/4 in
Dimension - B Length inch	0.247 in
Dimension - Bolt Size fraction	#8
Dimension - D inch	0.42 in
Dimension - Length Overall inch	0.95 in
Dimension - N inch	0.16 in
Dimension - Outside Diameter inch	0.24 in
Dimension - Pad Width inch	0.31 in
Dimension - Stud Size inch	#8
Dimension - Z (inch)	0.24 in

### Conductor Related

Conductor - Copper Str Size Range	20 AWG;18 AWG;16 AWG;14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	<ul style="list-style-type: none"> <li>CU C Solid-Size</li> <li>CU C Str-Size</li> </ul>

### Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	1000
Minimum Pack Quantity	1000
Pallet Quantity	99999

### Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)

[Product Cross Section Image\(s\) - BUR\\_YAV14H\\_LineArt](#)  
[Sales Drawings - 50094162](#)  
[Specifications - YAV14H1](#)



A Hubbell brand

©2025 Hubbell Incorporated. All rights reserved  
BRDY-YAV14H1-SPEC-EN | REV 7/2025