




Part Number : [150320213](#)

Product Description : 0.30mm Pitch Premo-Flex FFC/FPC Jumper with Latching Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 13 Circuits

Series Number : 15032

Status : Active

Product Category : Flat-Flexible Cable (FFC)

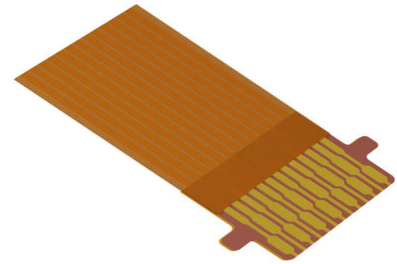

Documents and Resources

Drawings

[150320213 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[150320001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15032
Description	0.30mm Pitch Premo-Flex FFC/ FPC Jumper with Latching Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 13 Circuits
Product Name	Premo-Flex FFC/FPC Jumper
UPC	195842789104

Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Physical

Cable Length	51.00mm
Circuits (Loaded)	13
Contact Layout Type	A (same side)
Design Feature	Miniaturization, Superior Retention
Material - Plating Mating	Gold
Net Weight	0.049/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC/FPC Connector
Wire/Cable Type	Flexible Printed Circuit (FPC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FPC Connector, 0.30mm Pitch, Right-Angle, Bottom Contact, 0.95mm Height, 13 Circuits, Gold over Nickel Plating	<u>5035661302</u>

This document was generated on Jun 10, 2026