


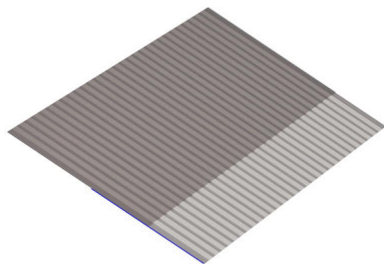

**Part Number :** [151660325](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Tin (Sn) Plating, 30 Circuits  
**Series Number :** 15166  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)




Documents & Resources

**Drawings**  
[151660325 sd.pdf](#)  
[STEP AP242](#)  
[SOLIDWORKS](#)  
[Creo](#)

**Specifications**  
[PS-15166-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15166
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Tin (Sn) Plating, 30 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	884982848238

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

**Physical**

Cable Length	152.00mm
Circuits (Loaded)	30
Contact Layout Type	A (same side)
Design Feature	Ultra-Flexible
Material - Plating Mating	Tin
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 30 Circuits, Copper Alloy, Tin-Bismuth Plating	<a href="#"><u>5019513000</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>524353072</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>524373072</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>541043096</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>541323097</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>525593072</u></a>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin	<a href="#"><u>781193010</u></a>

Bismuth Plating, Short Terminal Type, Black, 30 Circuits	
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 30 Circuits	<u>781273010</u>

---

This document was generated on Sep 17, 2025