


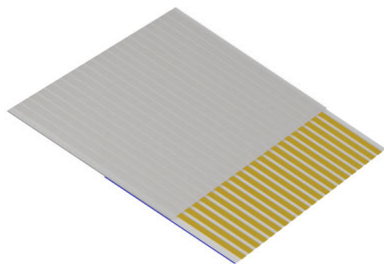

**Part Number :** [150200909](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 21 Circuits  
**Series Number :** 15020  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings


- [150200909 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15020-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

**Part Details**

**General**

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 21 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	884982181847

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

**Physical**

Cable Length	152.00mm
Circuits (Loaded)	21
Contact Layout Type	A (same side)
Design Feature	Flexible
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector

Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 21 Circuits, Phosphor Bronze, Gold Plating	<a href="#"><u>5019512130</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 21 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<a href="#"><u>5019512150</u></a>
Easy-On FFC/FPC Connector 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 21 Circuits, Gold over Nickel Plating	<a href="#"><u>5051102191</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 21 Circuits, Gold Plating	<a href="#"><u>524352171</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 21 Circuits, Gold Plating	<a href="#"><u>524372171</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 21 Circuits, Gold Plating	<a href="#"><u>525592152</u></a>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Top Contact Style, 21 Circuits, Gold (Au) Plating	<a href="#"><u>545502172</u></a>
0.50mm Pitch Easy-On FFC/FPC	<a href="#"><u>781192120</u></a>

Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 21 Circuits	
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 21 Circuits	<u>781272120</u>

---

This document was generated on Sep 10, 2025