


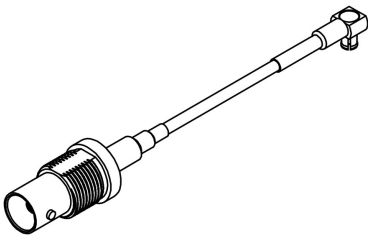

Part Number : [897626990](#)
Product Description : BNC Straight Jack,
Bulkhead Rear Mount-to-MCX Right-Angle
Plug, RG-179 Cable, 72.00mm Length, 75
Ohms
Series Number : 89762
Status : Active
Product Category : RF Cable Assemblies



Documents & Resources

Drawings
[Drawing 897626990_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	RF Cable Assemblies
Series	89762
Description	BNC Straight Jack, Bulkhead Rear Mount-to-MCX Right-Angle Plug, RG-179 Cable, 72.00mm Length, 75 Ohms
Assembly Configuration	Dual Ended Connectors
Connector to Connector	BNC-to-MCX
Product Family	RF Standard Cable Assemblies Solutions
Product Name	BNC,MCX
Type	RF Cable Assembly
UPC	889056323284

Electrical

Impedance	75Ω
-----------	-----

Physical

Cable Length	72.00mm
Gender	Jack/Plug
Net Weight	8.100/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	RG-179

This document was generated on Sep 22, 2024