




+ CONNECTORS

CRIMP D-SUB CONNECTORS

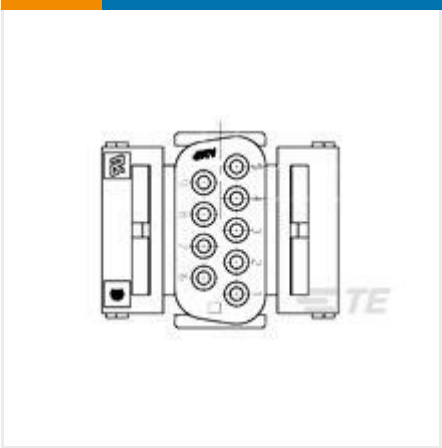

✓ Active

TE CONNECTIVITY (TE)
9 CONTACT HSG
AMPLIMITE | Crimp Snap

207752-3
TE Internal Number: 207752-3

EU RoHS Compliant
EU ELV Compliant
Connector Style Receptacle
Shell Size 1
Mating Connector Lock Without
Number of Positions 9

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

RECEPTACLE HOUSING, 9 POSITION, AMPLIMITE
PDF
English

CAD Files

Customer View Model
2D_DXF.ZIP
English

Customer View Model
3D_IGS.ZIP
English

Customer View Model
3D_STP.ZIP

English

3D PDF

PDF

English

Instruction Sheets

Instruction Sheet (U.S.)

AMPLIMITE Cord Guard Assemblies And AMPLIMITE Squeeze-To-Release Cord Guard Assemblies

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

- Connector Style Receptacle
- Shell Size 1
- Product Type Connector
- Shell Type All Plastic
- Grounding Indents Without
- Grade Standard

Configuration Features

- Number of Positions 9

Mechanical Attachment

- Mating Connector Lock Without

Housing Features

- Housing Color Black
- Housing Material Thermoplastic

Operation/Application

- For Use With Size 20 Crimp Snap-in Contacts

Industry Standards

- UL Flammability Rating UL 94V-0

Statement of Compliance

Statement of Compliance

PDF