


# Female Disconnects – Non-Insulated Butted Seam



| Product Number <sup>†</sup> | UPC (054007-) | Wire Range (AWG)** | Mates with Male Tab<br>Width(W') x Thickness | L    | Barrel Length | Barrel I.D. | Terminals per: |      |
|-----------------------------|---------------|--------------------|----------------------------------------------|------|---------------|-------------|----------------|------|
|                             |               |                    |                                              |      |               |             | Carton         | Case |
| MU20-110DFK*                | 00984         | 26-20              | 0.110 x 0.020                                | 0.48 | 0.13          | 0.055       | —              | 1000 |
| MU20-110/32DFK*             | 00985         | 26-20              | 0.110 x 0.032                                | 0.48 | 0.13          | 0.055       | —              | 1000 |
| MU18-187DFK                 | 02366         | 22-18              | 0.187 x 0.020                                | 0.58 | 0.25          | 0.085       | —              | 1000 |
| MU18-250DFX                 | 16725         | 22-18              | 0.250 x 0.032                                | 0.66 | 0.25          | 0.080       | 100            | 500  |
| MU18-250DFK                 | 01300         | 22-18              | 0.250 x 0.032                                | 0.66 | 0.25          | 0.080       | —              | 1000 |
| MU14-110DFX*                | 22815         | 16-14              | 0.110 x 0.020                                | 0.54 | 0.19          | 0.115       | 100            | 500  |
| MU14-110DFK*                | 13995         | 16-14              | 0.110 x 0.020                                | 0.54 | 0.19          | 0.115       | —              | 1000 |
| MU14-187DFX                 | 22831         | 16-14              | 0.187 x 0.020                                | 0.58 | 0.25          | 0.085       | 100            | 500  |
| MU14-187DFK                 | 01767         | 16-14              | 0.187 x 0.020                                | 0.58 | 0.25          | 0.085       | —              | 1000 |
| MU14-250DFX                 | 22849         | 16-14              | 0.250 x 0.032                                | 0.66 | 0.25          | 0.080       | 100            | 500  |
| MU14-250DFK                 | 01768         | 16-14              | 0.250 x 0.032                                | 0.66 | 0.25          | 0.080       | —              | 1000 |

\* Not ULListed or CSACertified

\*\* For #10-12 AWG, see MI10-250DF.

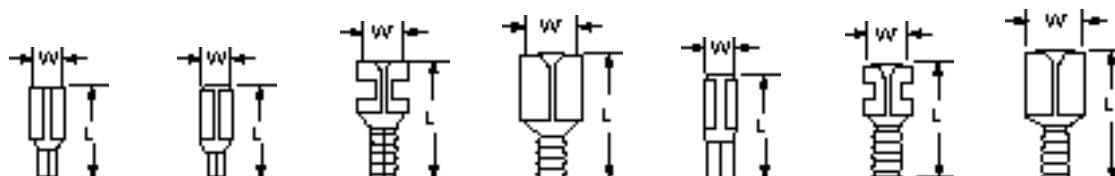

| Wire Range     | MU20-110DF<br>26-20 | MU20-110/32DF<br>26-20 | MU18-187DF<br>22-18 | MU18-250DF<br>22-18 | MU14-110DF<br>16-14 | MU14-187DF<br>16-14 | MU14-250DF<br>16-14 |
|----------------|---------------------|------------------------|---------------------|---------------------|---------------------|---------------------|---------------------|
| Suggested Mate | 0.110 Male Tab      | 0.110 Male Tab         | MU18-187DM          | MU18-250DM          | 0.110 Male Tab      | MU14-187DM          | MU14-250DM          |