


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	50-00028	Connector, dc plug, 4.75x1.7xL20 mm, EIAJ-3, molding style, spring contacts	1	
2	30-00692	Wire, 2C TS, 24 AWG, UL2464, 300V, 80C, 4.0 mm, VW-1, PVC	1	
3	24-00180		1	black

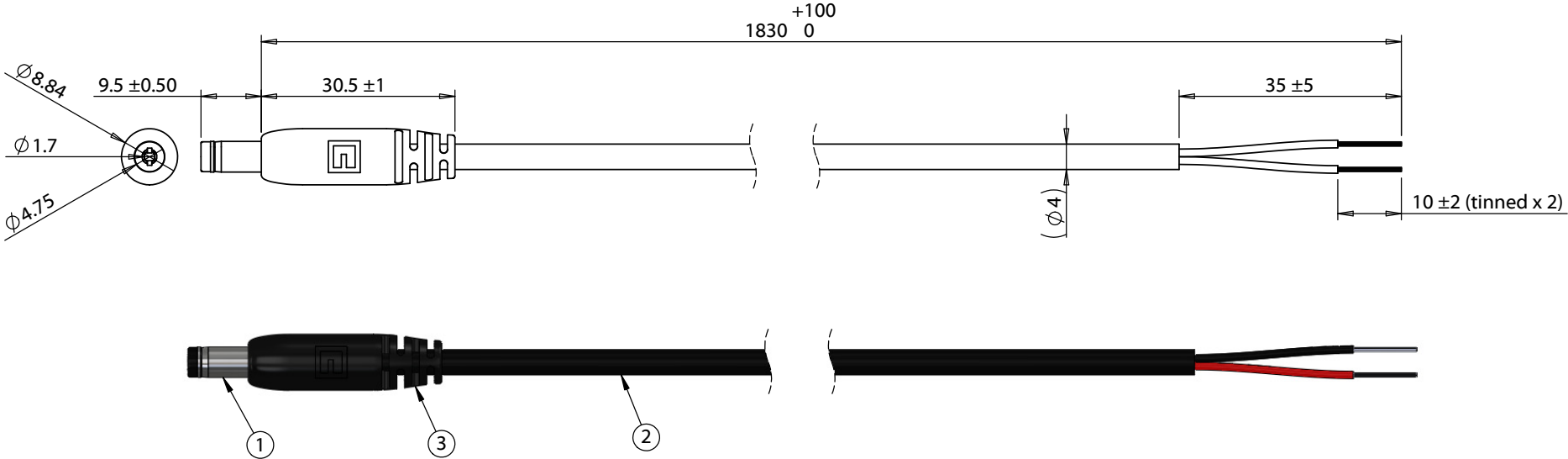

Notes:
 Functionally equivalent components may be substituted

Electrical requirements: 4.5 A, 48 Vdc

Wiring Diagram	
50-00028	wire color
center	red
sleeve	black

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	9/14/2016	Initial release	Verified:	RoHS and REACH compliant			
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Function test: no open, no short circuit, no intermittent	Size: Part number: A 10-02238		
				Description: Cable, 1830 mm, 4.75x1.7x9.5 mm 50-00028 dc plug to stripped tinned, 24 AWG, 30-00692 wire			
						Scale: 1:1	