



RED
GREEN
YELLOW

SERIES 5100H FLASHER

FEATURES

- Built-in flashing circuit
- No external resistor required

Mounting: Will snap fit in .249/.254 (6.33/6.45) dia. hole in panels .031/.062


Wire Leads: No. 24 AWG, 6" (152.4) insulated, bonded strands, stripped 1/2" (12.7)

Anode (+): Red Lead

Housing: Black Nylon




OUTLINE DIMENSIONS

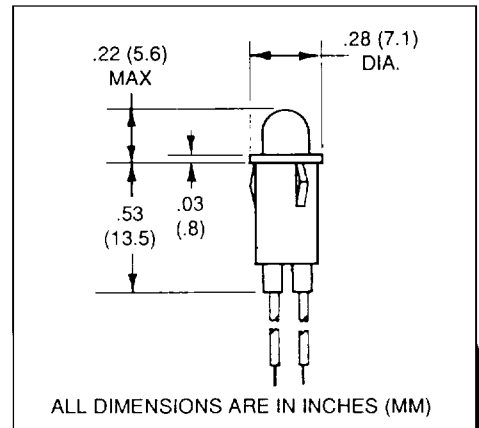

For more complete LED data, refer to 4380H pages.

 Note: Use of incorrect circuit polarity will cause permanent damage to these LEDs



MODEL NO.	—	—	mcd	mA	V	V	V	mA	V _{BR}	mA	Hz	nm
5100H1FL	Red	Diffused	12.5	20	3.5	9 - 12	13.0	38 - 56	0.5	6 - 70	2.5-1.5	625
5100H5FL	Green	Diffused	8.0	20	3.5	9 - 12	13.0	38 - 56	0.5	6 - 70	2.5-1.5	565
5100H7FL	Yellow	Diffused	12.5	20	3.5	9 - 12	13.0	38 - 56	0.5	6 - 70	2.5-1.5	590

Industrial Devices, Inc., 260 Railroad Ave., Hackensack, NJ 07601 • (201) 489-8989 • FAX: 201-489-6911