







Product Status	Production
Applications	Commercial Grade
Feature	PowerPower line
Series	MPZ
Brand	TDK
Environmental Compliance	<div><div>RoHS</div><div>REACH</div><div>Halogen Free</div><div>Lead Free</div></div>





Size	
Length(L)	2.00mm ±0.20mm
Width(W)	1.25mm ±0.20mm
Thickness(T)	0.85mm ±0.20mm
Recommended Land Pattern (A)	0.80mm Nom.
Recommended Land Pattern (B)	1.00mm Nom.
Recommended Land Pattern (C)	1.20mm Nom.

Electrical Characteristics	
Impedance at 100MHz	600Ω ±25%
Rated Current	2A
DC Resistance (Max.)	100mΩ

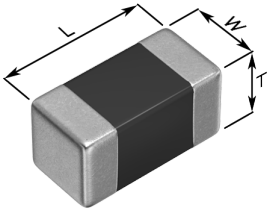Other	
Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	4000pcs
Weight	0.008g
FIT (Failure In Time)	 This will be displayed when you <a href="#">login</a> to myTDK

Characteristic Graphs(This is reference data, and does not guarantee the products characteristics.)

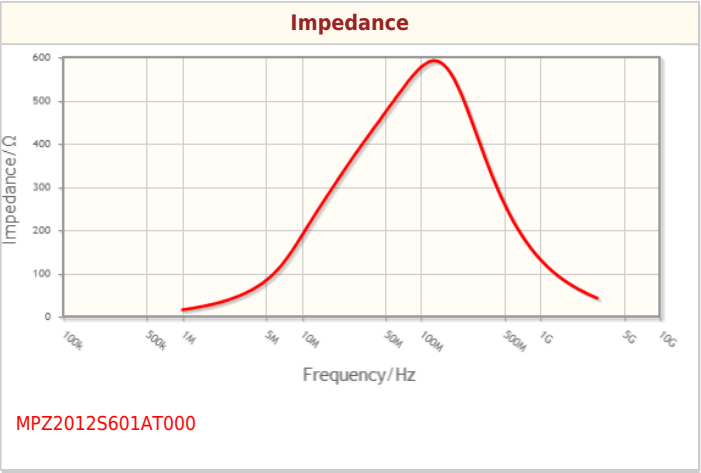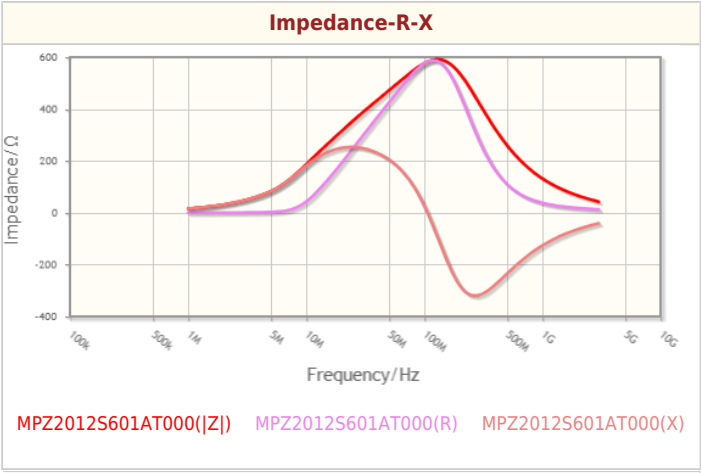

# Associated Images

