 



Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- X-Lok >
- M Series >
- Accessory
- M5
- Guided M8
- M8
- M10.5
- M12 (A)
- M12 (B)
- M12 (D)
- M12 (I)
- M12 (K)
- M12 (L)
- M12 (S)
- M12 (T)
- M12 (U)
- M23
- FLOS & FLOS+ >
- Power >
- RBL >
- HS-Lok >
- NMEA 2000 >
- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

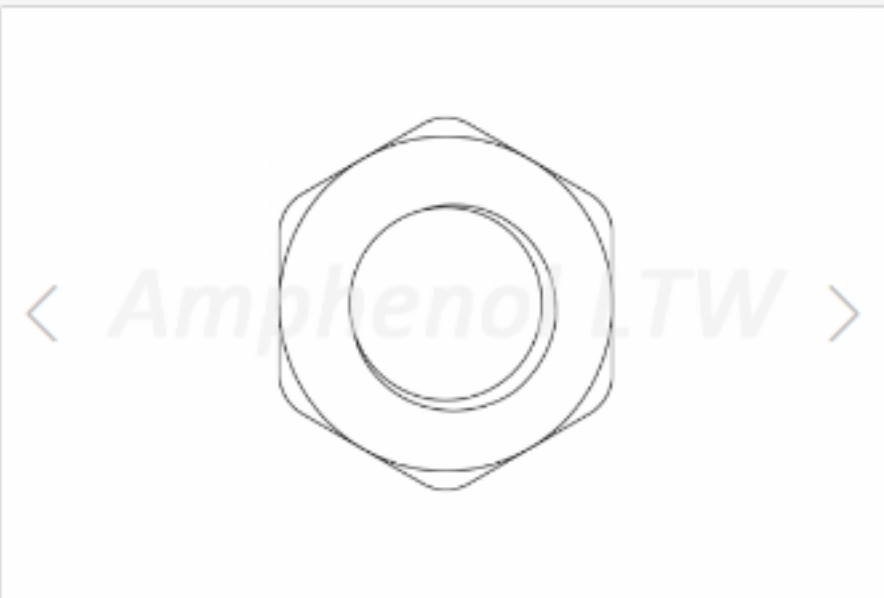

APTM-AMBPA012-001

- Operating Temperature: N/A
- Transmission Speed: N/A
- Shielded: Metal, Non-shielded
- Jacket Material: N/A
- Certificate: N/A

You must login first to view the price

Quantity

-

1

+

Check Stock

Add to Cart

Inquiry

Can't find? [Customize your part](#)

Specifications	Download / CAD
Nominal Current N/A	Connector Type Nut
Shielded Metal, Non-shielded	No. of Contacts N/A
Connector Gender N/A	Backshell N/A
Mating Style N/A	IP Rating N/A

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

Assembly Style N/A
More Options

People Also Bought

