

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731000256

Status:

Active

Overview:

SMB RF Connectors

Description:

75 Ohms, SMB Plug, Right-Angle, Crimp, RG-179 Cable, Accepts Non-standard .015" Pin, Tray

Documents:

[3D Model](#)

[Drawing \(PDF\)](#)

[3D Model \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Comments

Overview

Product Name

Style

Type

UPC

Wire/Cable Type

RF/Coax Connectors

[73404](#)

Accepts Non-standard .015" Pin

[SMB RF Connectors](#)

SMB

Cable

Subminiature

800753680524

RG-179

Physical

Gender

Keying to Mating Part

Net Weight

Orientation

PCB Mounting

Packaging Type

Panel Mount

Panel Mount Method

Reverse Polar

Plug

None

2.907/g

Right Angle

N/A

Tray

No

N/A

No

Electrical

Frequency

Impedance

Power / Voltage

4 GHz

75Ω

VOLTAGE: 335 Vrms@Sea Level

Solder Process Data

Lead-freeProcess Capability


N/A

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-73100-0256-001, SD-73404-300-001

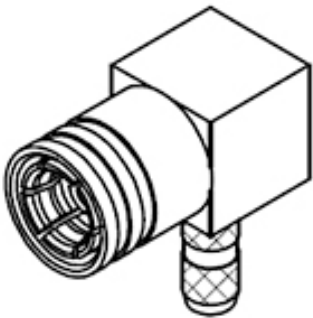

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c),6(b)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[73404](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION