
 


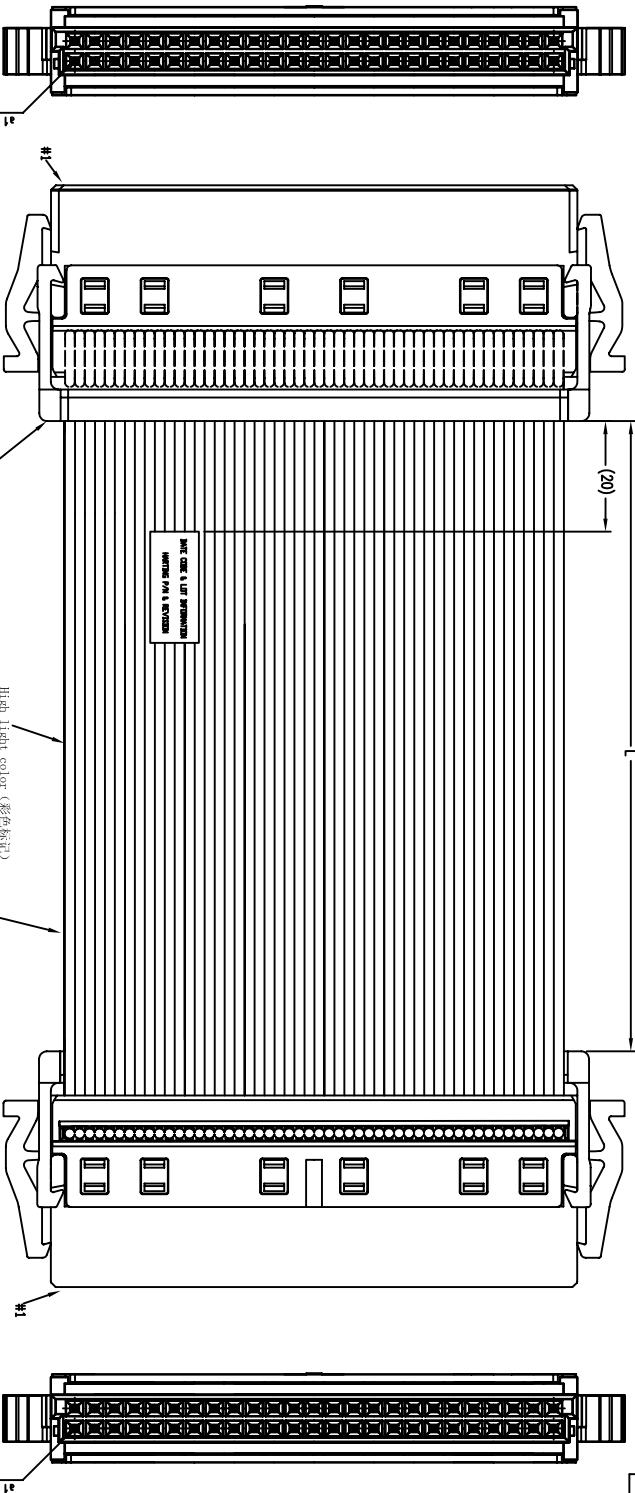

Har-Flex 50P female connector

Flat cable, pitch 0.635mm, AWG30, 50 conductors

Har-Flex 50P female connector



Part-No. / 产品号码	Length/长度
33 15 243 050 0015 .00	500±5
33 15 243 020 0014 .00	200±3
33 15 243 010 0013 .00	100±3

DATE CODE & LOT INFORMATION
HARTING P/N & REVISION

- NOTES/要求:
- 1.) CABLE MUST BE PERFORMED 100% CONTINUITY TEST
AND HI-POT (300VDC) TEST.
 - 2.) CABLE OPERATION TEMPERATURE= -30° C TO +105° C .
 - 3.) WHITE LABEL CONTENT:

Rev.	Description	Appr.	Date
01	Add side view.	Lucy/Z	15/04/13
00	Prototype	Andrew/H	15/1/13

				All Dimensions in mm Original Size DIN A4		Ref. MB
Free size tol.						Mat.
V=		cm ³	A=		cm ²	SEE BILL OF MATERIAL
Name		Date	Scale			
Detail			Sheet			
Insp.			1 of 1			
Approved						
Har-Flex female 50pole, double ended						
Flat cable assembly, L=xMM						