


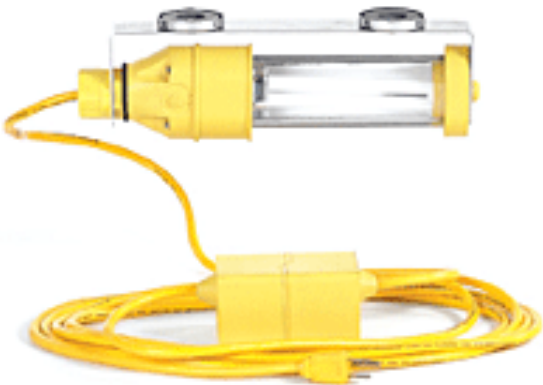

Part Number : 1301080148
Product Description : Super-Safeway 40W
Fluorescent Machine Light, Magnet Mount
with 18/3 SJTOOW Cord Type, Overall Cord
Length 4.57m (15.0')
Series Number : 130108
Status : Active
Product Category : Lamps and Lights
Engineering Number : 1097-3MM



Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Lamps and Lights

Series	130108
Description	Super-Safeway 40W Fluorescent Machine Light, Magnet Mount with 18/3 SJTOOW Cord Type, Overall Cord Length 4.57m (15.0')
NEMA Configuration	NEMA 5-15
Product Family	Wide-Area Lighting Products
Product Name	Super-Safeway
Type	Wide Area Lamps
UPC	78678861255

Agency

CSA	LR85374
UL	E174254

Electrical

Lamp Wattage - Maximum	40W
Lumens	2970
On/Off Switch	Yes
Voltage (Fixture) - Maximum	120VAC 60 HZ

Physical

Bulb Type	Fluorescent
Cord Length - Primary	4.57m (15.0')
Cord Length - Secondary	N/A
Cord Type - Primary	18/3 SJTOOW
Depth	76.20mm (3.000")
Duty	Industrial
Guard Included	No
Guard Type	N/A
Height	57.15mm (2.250")
Lamp Type	PL-L 40/41
Length	798.83mm (31.450")
Material - Globe	Clear Polycarbonate
Material - Guard	Nitrile Rubber 80 Shore A
Mounting Style	Magnetic-Bracket

Outlet	None
Packaging Type	Carton

This document was generated on Jan 05, 2024