




Part Number : [1061141400](#)

Product Description : EMI MPO Adapter, Simplex, Metal Body, Flange Mount with M2 Holes Style, Shutter, Silicone Gasket

Series Number : 106114

Status : Active

Product Category : Fiber Optic Adapters

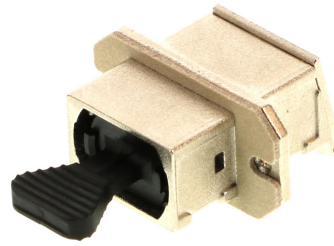

Documents & Resources

Drawings

[1061141400_sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Not Relevant |
| China RoHS | |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2020)9139-DC (19 Jan 2021) |
| EU RoHS | Compliant per EU 2015/863 |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

| | |
|----------------|--|
| Status | Active |
| Category | Fiber Optic Adapters |
| Series | 106114 |
| Description | EMI MPO Adapter, Simplex, Metal Body, Flange Mount with M2 Holes Style, Shutter, Silicone Gasket |
| Component Type | EMI Shielding |
| Product Family | Optical EMI Shielding Adapters |
| Product Name | MPO |
| Type | Adapter |
| UPC | 884982151437 |

Electrical

| | |
|-------------|------------|
| Shield Type | EMI Gasket |
| Shielded | Yes |

Physical

| | |
|-------------------------------|---------------|
| Alignment Sleeve | N/A |
| Angled Physical Contact (APC) | N/A |
| Color - Resin | N/A |
| Gender | Female-Female |
| Material - Housing | Die-Cast |
| Mounting Style | Flange |
| Net Weight | 10.946/g |
| Orientation | Straight |
| Panel Mount | With Flange |
| Ports | 1 |
| Shutter | One Side |

Solder Process Data

| | |
|------------------------------|-----|
| Lead-Free Process Capability | N/A |
|------------------------------|-----|

This document was generated on Oct 08, 2024