





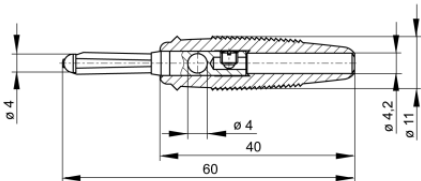


## Plugs

### BUELA 20 K



Product	BUELA 20 K
description	Multiple-spring wire plug, shatter-proof, flexible insulated sleeve with transverse hole. The tapering sleeve end also serves as kinking protection for the lead. Screw connection up to maximum cable cross-section of 1.5 mm <sup>2</sup> . Nickel-plated brass contact material.
operating instruction	BA410
article-no. / *colour	9307261xx <div>  00 black            01 red            02 blue            03 yellow            04 green            07 white </div> <div>Ni</div>
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(2)</sup>
rated current (consider derating curve)	16 A
material plug	brass, nickel plated
housing material	PVC-P
temperature range acc. To IEC61010 <sup>(1)</sup>	-25 °C to +70 °C

<sup>(1)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(2)</sup> without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022

4 mm system