



Right-Angle Shapes, VG style

Helashrink 1100 Series, with rib

Features and benefits

- Used in conjunction with a circular grooved adaptor
- Provides strain relief and an environmental seal




1152-4-G recovered onto a connector.



For Material / Adhesive information please refer to page 260, 261.



1155-4 supplied.

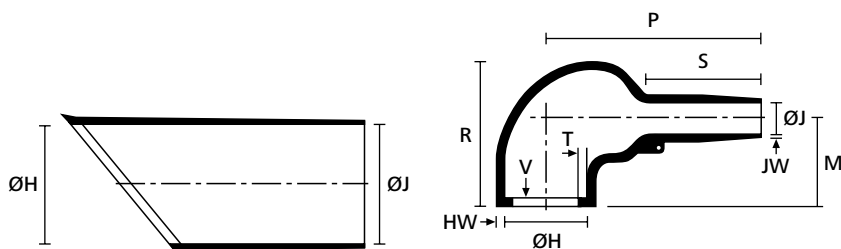

a: Expanded form (supplied)

b: Fully recovered form (after heating)

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10 %	R ± 10 %	HW ± 20 %	JW ± 20 %	V max.	T ± 20 %	M nom.	S nom.	Designation as per VG-Norm	Article-No.
1152-4-G	24.0	10.5	24.0	6.0	32.0	25.0	1.3	0.5	3.3	1.0	19.0	10.0	VG 95343 T06 E 001 A	411-52480
1154-4-G	30.0	14.5	30.0	6.0	41.0	27.0	1.5	0.8	3.3	1.0	19.0	12.0	VG 95343 T06 E 002 A	411-54480
1155-4-G	31.0	18.0	31.0	7.0	51.0	31.0	1.8	1.0	3.3	1.0	21.0	15.0	VG 95343 T06 E 003 A	411-55480
1156-4-G	36.0	22.5	36.0	8.5	59.0	38.0	1.8	1.0	3.3	1.0	26.0	15.0	VG 95343 T06 E 004 A	411-56480
1157-4-G	43.0	28.5	43.0	10.0	71.0	45.0	2.0	1.0	3.3	1.7	30.0	16.0	VG 95343 T06 E 005 A	411-57480
1158-4-G	60.0	35.0	60.0	16.0	101	54.0	3.3	1.5	3.3	1.7	35.0	30.0	VG 95343 T06 E 006 A	411-58480
1159-4-G	66.0	45.0	66.0	17.0	134	68.0	3.8	2.0	3.3	2.0	42.0	51.0	VG 95343 T06 E 007 A	411-59480
1160-4-G	82.0	61.0	82.0	25.0	152	84.0	4.0	4.0	3.3	2.0	52.0	39.0	VG 95343 T06 E 008 A	411-60480

All dimensions in mm. Subject to technical changes.



For product specific approvals and specifications please refer to the Appendix.