




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 3/8 Hex Male-Female Standoffs

3/8 HEX MALE-FEMALE STANDOFFS

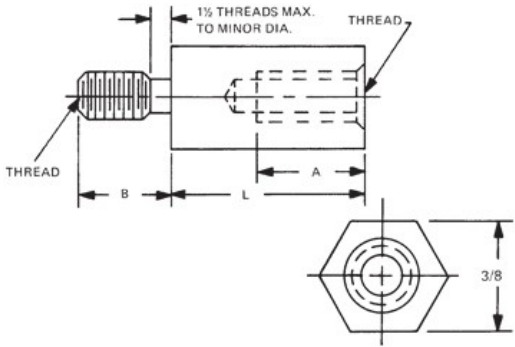

Qty1 *

Qty2

Qty3

☐	4631T	31/32
☐	4632	1"
☐	4633	1-1/16
☐	4634	1-1/8
☐	4635	1-3/16
☐	4636	1-1/4
☐	4637	1-5/16
☐	4638	1-3/8
☐	4639	1-7/16
☒	4640	1-1/2
☐	4641	1-9/16
☐	4642	1-5/8
☐	4643	1-11/16

Thread *

Select	Code	Thread
☐	1224	12-24
☐	440	4-40
☐	632	6-32
☒	832	8-32
☐	1032	10-32

Material *

Select	Code	Material	RoHS
☐	AL	Aluminum	YES
☐	B	Brass	YES
☒	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code

xxxxx	xxxx	xx	x
Length	Thread	Material	Finish

PART: 4640 832 SS

Red ?'s show missing selections. [Help](#)

[Material Specifications](#)
[Ordering non-standard items](#)
[Request a Drawing](#)

Add to Cart

Thread Length Code

Thread	A	B
4-40	1/4	3/16
6-32	3/8	1/4
8-32	7/16	3/8
10-32	1/2	3/8
12-24	1/2	3/8

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☒	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite
☐	7-Clear iridite
☐	9-Alodine 1200*
☒	10-Bright chrome
☒	11-Satin chrome
☐	12-Zinc