


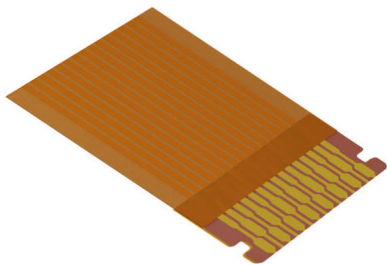

Part Number : [150310215](#)
Product Description : 0.30mm Pitch Premo-Flex FFC
Jumper with Notches, Same Side Contacts (Type A),
51.00mm Cable Length, Gold (Au) Plating, 15 Circuits
Series Number : 15031
Status : Active
Product Category : Flat-Flexible Cable (FFC)



Documents and Resources

Drawings

- [150310215 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Specifications

- [150310001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15031
Description	0.30mm Pitch Premo-Flex FFC Jumper with Notches, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 15 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	195842784550

Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Physical

Cable Length	51.00mm
Circuits (Loaded)	15
Contact Layout Type	A (same side)
Design Feature	Miniaturization, Superior Retention
Material - Plating Mating	Gold
Net Weight	0.060/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C

Termination Style	FFC Connector
Wire/Cable Type	Flat Flexible Cable (FFC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On Back Flip FPC Connector with Lock Terminal, 0.30mm Pitch, LA75 Series, Right-Angle, Surface Mount, Dual Contact Style, 0.75mm Height, 15 Circuits	<u>5047541500</u>

This document was generated on Jun 08, 2026