
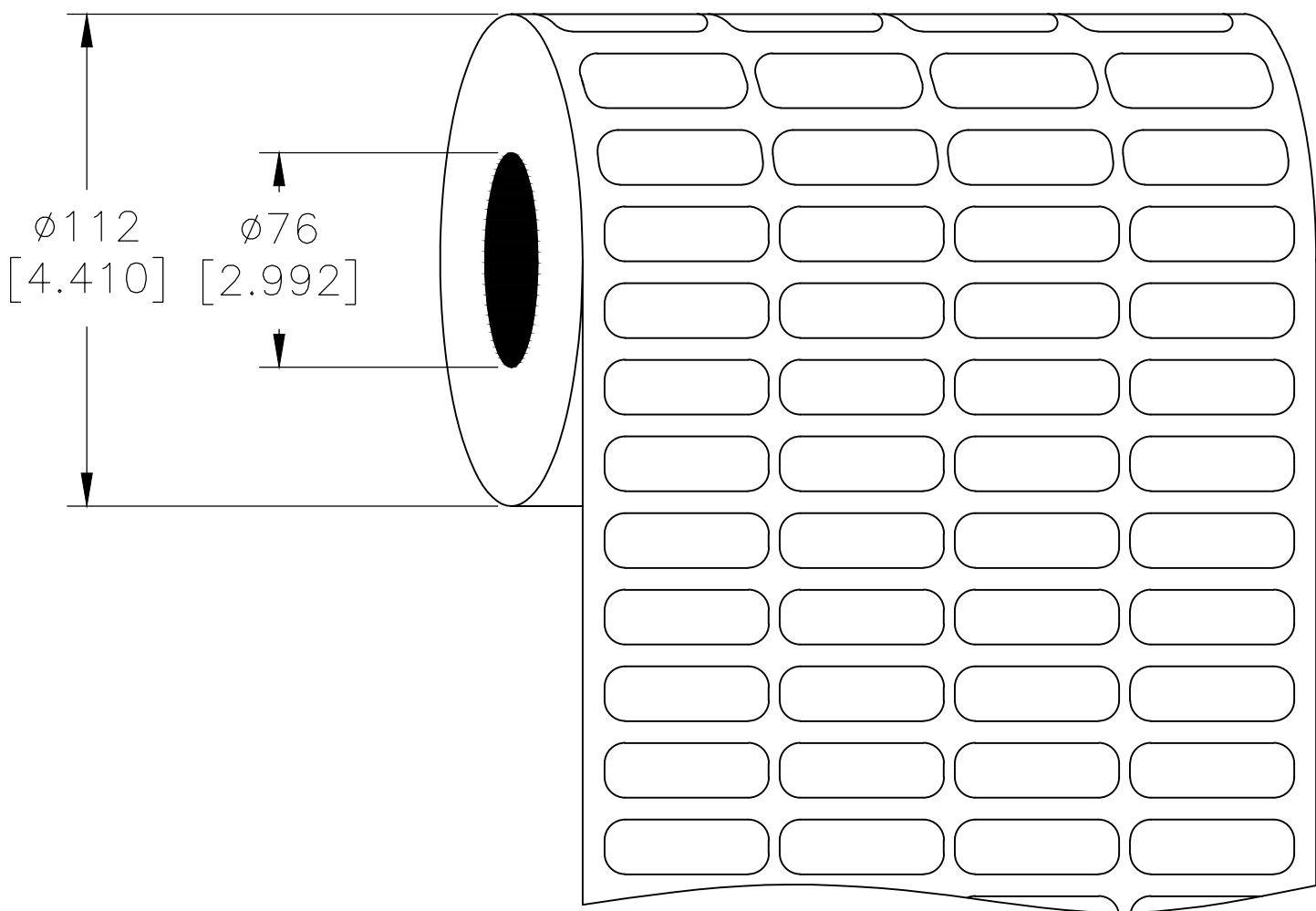


LABEL AND LINER DESIGN

PRESENTATION

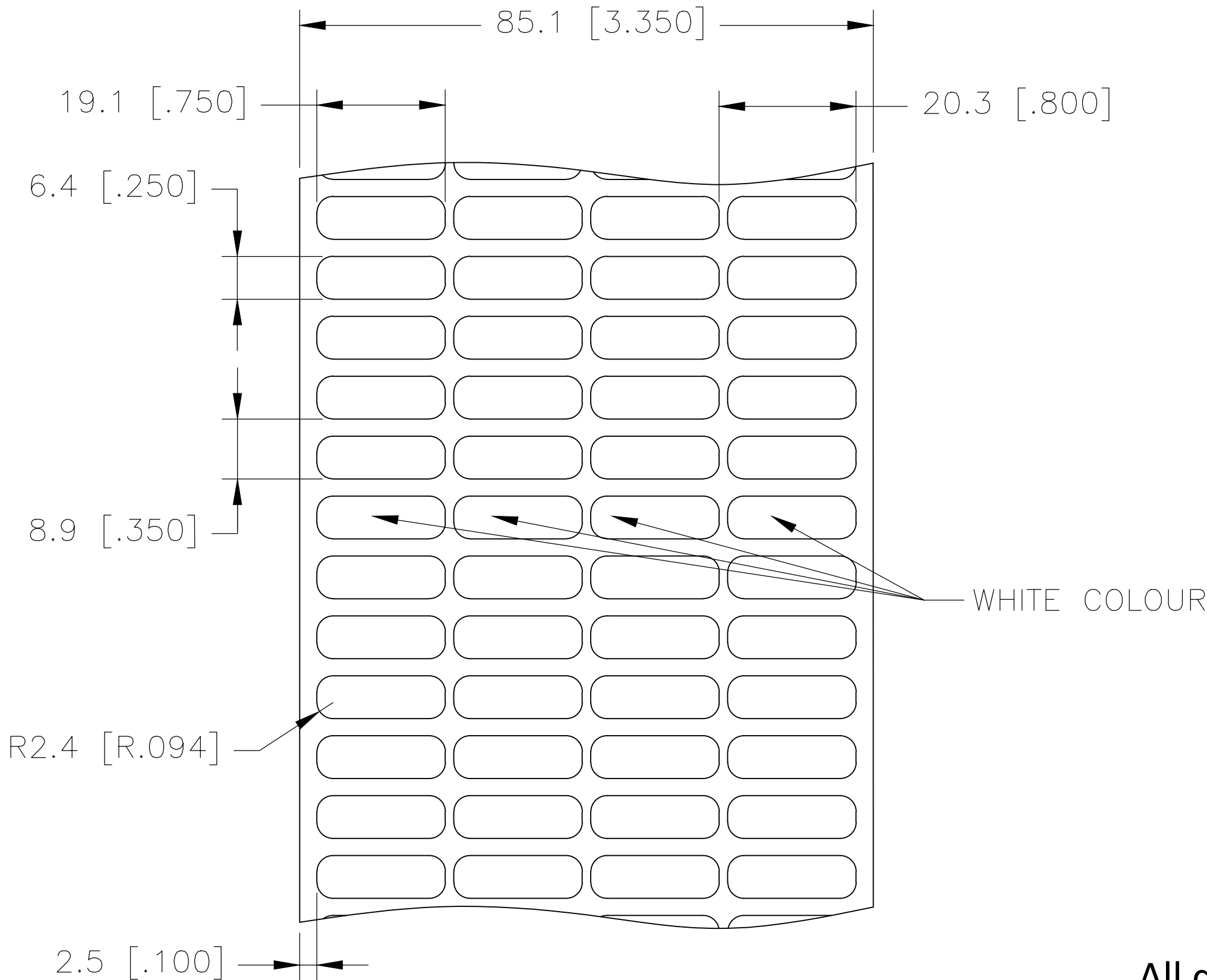

OUTSIDE WOUND
LABEL ACROSS: 4
PER ROLL QTY: 10,000

All dimensions in mm [Inch]

TE PN: 940010-000

MATERIAL		POLYVINYL FLUORIDE (TEDLAR®)			
ADHESIVE TYPE		PERMANENT ACRYLIC			
LINEAR		BROWN KRAFT			
DWN 12MAY2020 CHK 12MAY2020 D.BURGAT APVD 12MAY2020 D.BURGAT PRODUCT SPEC TTDS-005 APPLICATION SPEC		NAME TEDLAR® LABEL – WHITE – 4 ACCROSS 19.05mm x 6.4mm (0.75inch x 0.2inch)			
WEIGHT 0.017g		SIZE A2	CAGE CODE FB1U7	DRAWING NO C=TTVF075025WE10	RESTRICTED TO –
CUSTOMER DRAWING			SCALE NTS	SHEET 1 OF 1	REV A1

TOLERANCES mm [INCH]		THIS DRAWING IS A CONTROLLED DOCUMENT.	
LABEL HEIGHT:	±0.3 [.012]	DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
LABEL WIDTH:	±0.3 [.012]		
WEB WIDTH:	±0.8 [.031]		0 PLC ± ±
VERTICAL REPEAT:	±0.8 [.031]*		1 PLC ± ±
HORIZONTAL REPEAT:	±0.8 [.031]*		2 PLC ± ±
PRINT POSITIONING:	±0.8 [.031]*		3 PLC ± ±
			4 PLC ± ±
LEFT MARGIN:	±0.4 [.016]	ANGLES ± ±	
QUANTITY:	-0 % +2 %	MATERIAL	FINISH
*NON ACCUMULATING		SEE TABLE	GLOSS