




Part Number : [5005920800](#)

Product Description : 2.50mm Pitch CP-2.5 Mini Wire-to-Wire Receptacle Housing, Positive Lock, Single Row, 8 Circuits

Series Number : 500592

Status : Active

Product Category : Connector Housings

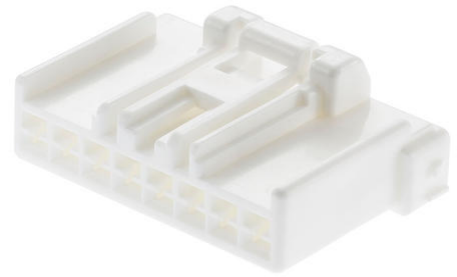

Documents and Resources

Drawings

[5005920800_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


Specifications

[5005929200-200.pdf](#)

[PS-500592-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025) SCIP:f5fd00e3-6ae4-49d8-b873-e8db11e5d3ea
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Housings
Series	500592
Description	2.50mm Pitch CP-2.5 Mini Wire-to-Wire Receptacle Housing, Positive Lock, Single Row, 8 Circuits
Application	Signal, Wire-to-Wire
Product Name	CP-2.5 Mini
UPC	756054724996

Physical

Circuits (maximum)	8
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	1604.400/mg
Number of Rows	1
Packaging Type	Bag

Panel Mount	No
Pitch - Mating Interface	2.50mm
Temperature Range - Operating	-40° to +85°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
CP-2.5 Mini Single Row Plug Housings	<u>500593</u>

Use with Part(s)

Description	Part Number
CP-2.5 Mini and CP-3.3 Female Crimp Terminals	<u>50397</u>
CP-2.5 Mini Terminal Position Assurance (TPA) Retainers	<u>500817</u>

This document was generated on Dec 12, 2025