


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	TLY-13	NEMA 5-15P	1	PVC, black
2	30-01362	Wire, 3C, 14 AWG, UL SJT, 300V, 105C, 9.25 mm, VW-1, PVC	1	

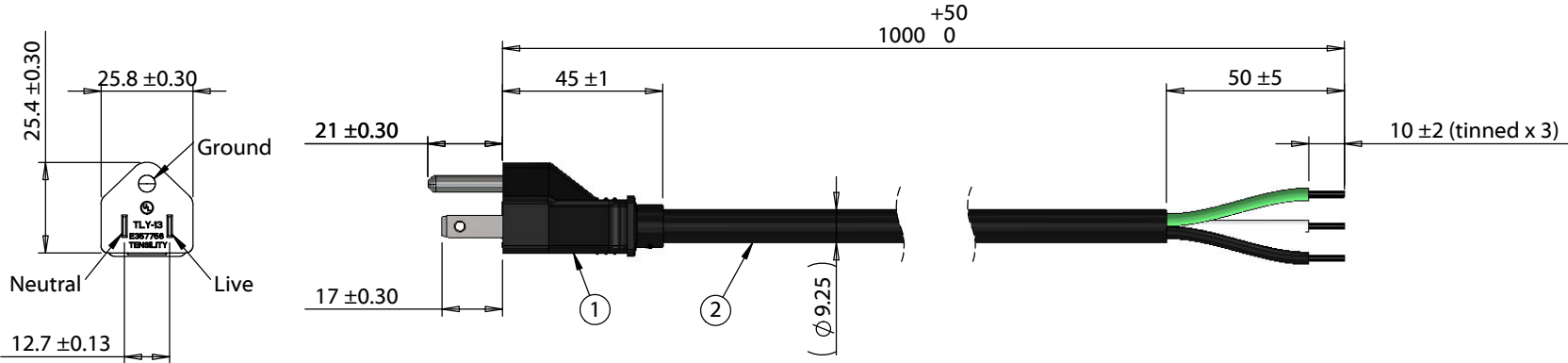

Notes:
Cable rated for 18 A, 125 Vac

Wiring Diagram	
TLY-13	wire color
Live	black
Neutral	white
Ground	green

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com	
A	5/19/2020	Initial release	Verified:			
			Dimensions are in millimeters.	Description:	Size:	Part number:
			Tolerances:		A	11-00120
			X: ± 0.5 mm	Ac cord, 1000 mm, U.S., Nema 5-15P plug, TLY-13 to 10 mm tinned, 14 AWG, SJT wire, 30-01362	Scale:	1:2
			X.X: ± 0.3 mm			
			X.XX: ± 0.05 mm			