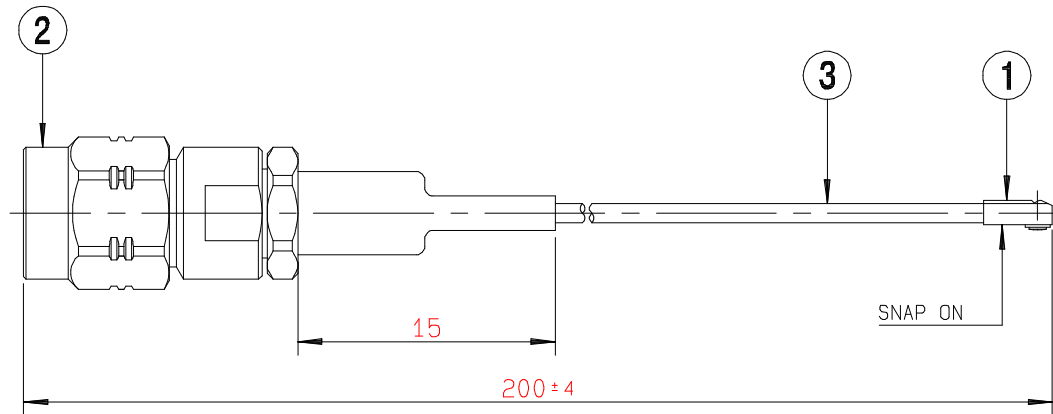


MALE SMA-MALE UMP
R285.025.211
CABLE 0.8/50 S-BR LENGHT: 20 CM

 Series : **CORD-STD**

PACKAGING

Standard	Unit	Other
20	'W' option	Contact us

* 1 * Connector A : **R107.011.000**
 * 2 * Connector B : **R124.086.020**
 * 3 * Cable : **C291.042.066**
 Type : **CAB HF 0.8/55S ETU132390FTX BL**

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 ° C
VSWR	NA + 0.000 x F(GHz) Maxi
Insertion loss	NA $\sqrt{F}$ (GHz) dB Maxi
Voltage rating	100 Veff Maxi
Dielectric withstanding voltage	350 Veff mini
Insulation resistance	1000 M Ω mini

SPECIFICATION

Weight	0.000 g
Cable retention	20 N mini
Others :	



Edition : 0145 A

Design changes may be in order to improve the product.