

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191600042

Status:


Active

Overview:

Splices

Description:

Twist Lock Splice for 10-22 AWG Wire, Yellow

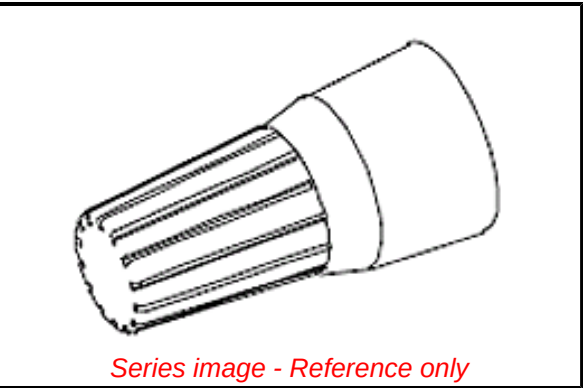

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR700095
UL	E32244
General	
Product Family	Splices
Series	19160
Crimp Quality Equipment	Yes
Overview	Splices
Product Name	Closed-End Twist Lock
UPC	800753110465
Physical	
Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.984/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	11.18mm max.
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	TL-Y
Reference - Drawing Numbers	
Product Specification	PS-19902-013-001
Sales Drawing	SD-19160-005

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19160 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION