



Search

TJG116701

Find

TJG116701

Find

Locate Inventory

Find

Part Number Search


Displaying 1 - 1 of 1

TJG116701


Series:	Series 1
Type:	Ground
Number of Contacts:	8
Number of Contacts per Size:	8
Contact Size:	14, 16
Contact Type:	Pin
Contact Part Number:	M39029/1-102
QPL:	M81714/27-16
Mil-Spec:	Non-Active Mil-Spec
Temperature (Degrees C):	-65 to 200
Insulation Resistance:	N/A
Dielectric Withstanding Voltage:	N/A
Amperage:	13 Amps
Vibration and Shock:	MIL-T-81714 Paragraph 3.5.5 and 3.5.8
Body:	Polyetherimide per ASTM-D5205
Grommet:	Silicone Blend Elastomer per A-A-59588
Contact Retainers:	Stainless Steel
Socket/Pin Contacts:	Copper Alloy, Hard Gold Plated in Accordance with MIL-G-45204
With/Without:	With
Color:	Blue
Electronic Component Type:	N/A
Electronic Component Part No.:	N/A
Electronic Req. Qty:	N/A
Engineering PDF:	 TJG116701_C.pdf

Dimension Image:

 
Top View



Size 22, 20

 


Size 16

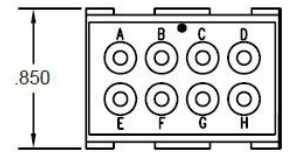


Size 12


Side View

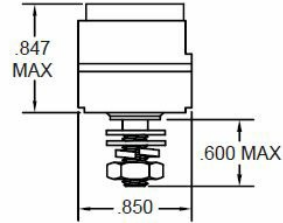

Size 22, 20

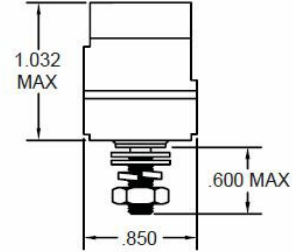

Size 16

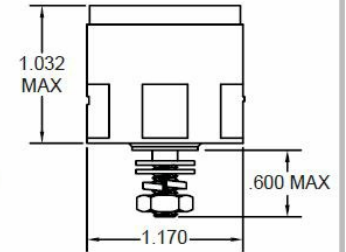

Size 12