
 


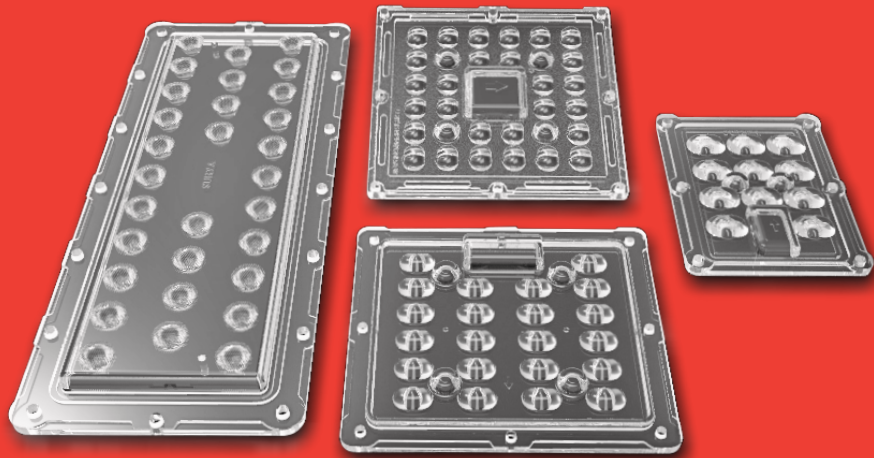

Datasheet DFY Series

Available Distribution



LED



Recommand Applications



General Information

PC 110°C -40°C	PC 1250Z HB RTI 1.5mm 125°C	PC LUX 2180T V-2 RTI 1.5mm 130°C	400nm~900nm >90%	400nm~900nm >90%	400nm~900nm >90%
----------------------	--------------------------------------	---	---------------------	---------------------	---------------------


- Lens Material L19: PC L-1250Z 100 / L52: PC LUX2180T
- Operating Temperature -40°C~+110°C
- UL Flammability L19:HB / L52:V-2@1.5mm
- UL RTI Elec L19:125°C / L52:130°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Dimensions

Part Number	L×W	Height
LL11SE-DFY40130Lxx-W	82×62	7.9
LL22SE-DFY40130Lxx-W	109×119	9.5
LL28SE-DFY40130Lxx-W	100×100	9.1
LL30SE-DFY45L52-W	204×84	8.9

*All dimensions are in millimeters.

Packaging Details (SPQ)

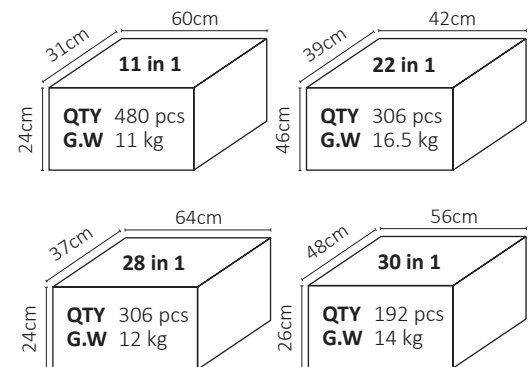

Accessories




- Available with Waterproof Gasket
LL01A00S2X2 (LL28SE-DFY40130Lxx-W)

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL11SE-DFY40130Lxx-W

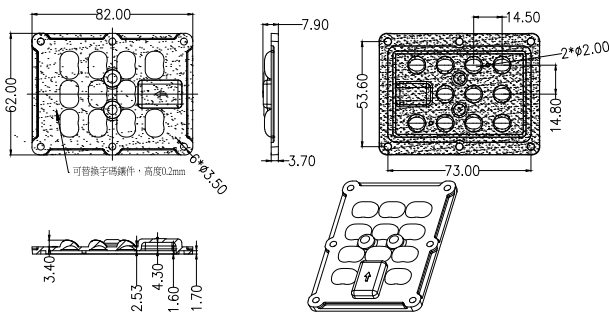


Lens Dimension

LL22SE-DFY40130Lxx-W

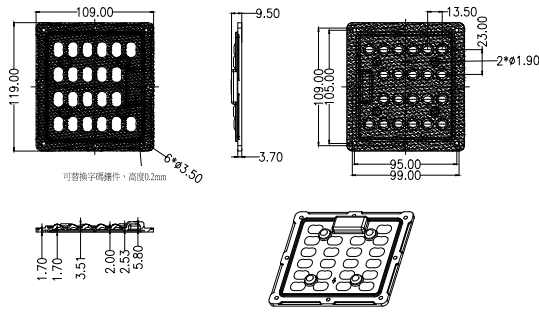


Lens Dimension

LL28SE-DFY40130Lxx-W

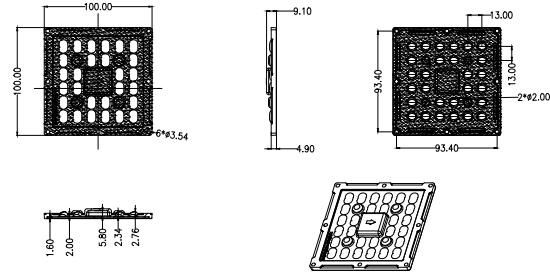


Waterproof Gasket Dimension

LL01A00SZX2

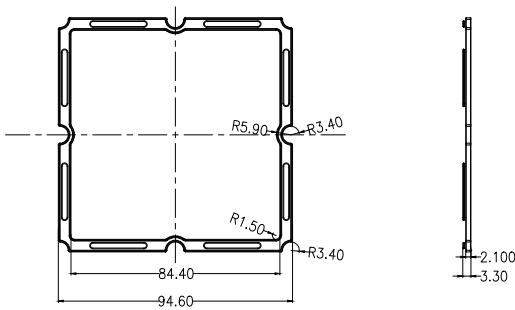

Lens Dimension

LL30SE-DFY45L52-W

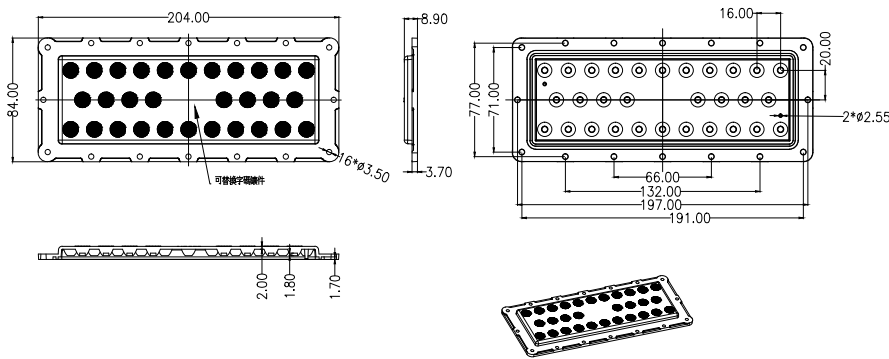



Mechanical Specification

*All dimensions are in millimeters.

Assembly Instruction

Fixing Method


Part No LL11SE-DFY40130Lxx-W
LL22SE-DFY40130Lxx-W
LL30SE-DFY45L52-W

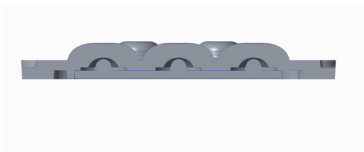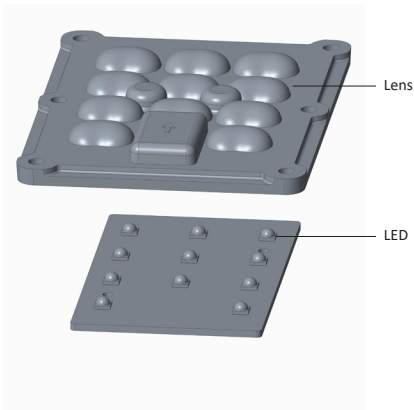








Assembly Instruction

Fixing Method

Part No LL28SE-DFY40130Lxx-W
Waterproof Gasket LL01A00SZX2

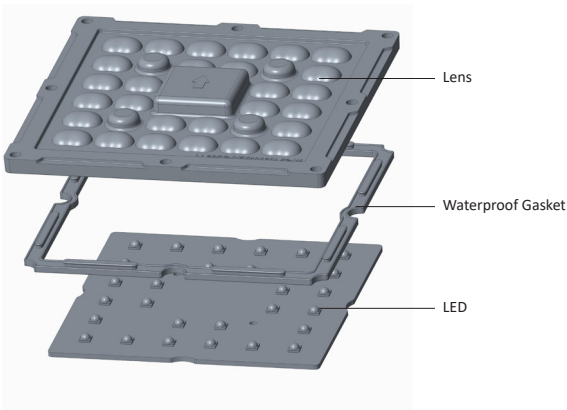

Photometric Distribution

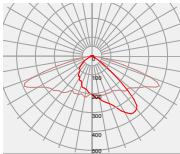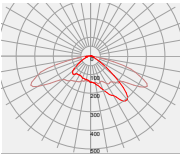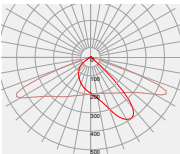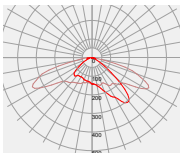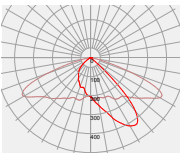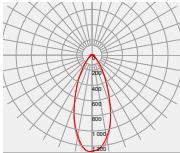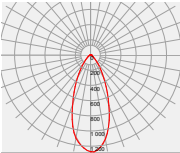LL11SE-DFY40130Lxx	 CREE XP-G3	 SAMSUNG LH351B
Distribution		
40°×130°		
LL22SE-DFY40130Lxx	 CREE XP-G3	 SAMSUNG LH351B
Distribution		
40°×130°	—	
LL28SE-DFY40130Lxx	 CREE XP-G3	 SAMSUNG LH351B
Distribution		
40°×130°		
LL30SE-DFY45L52-W	 CREE XP-G3	 SAMSUNG LH351B
Distribution		
45°		

Details by LED

Part No	Waterproof Gasket	LED Package Size	LED
LL11SE-DFY40130Lxx-W	-	3535	 CREE XP-G3
LL22SE-DFY40130Lxx-W	-		
LL30SE-DFY45L52-W	-		
			 SAMSUNG LH351B

LL28SE-DFY40130Lxx-W	
	LL01A00SZX2

LED	Part No	Type	FWHM	cd / lm	IES
 CREE XP-G3	LL11SE-DFY40130L19-W	II-Short	55°×147°	0.5	
	LL11SE-DFY40130L52-W	II-Short	55°×147°	0.5	
	LL22SE-DFY40130L19-W	-	-	-	-
	LL22SE-DFY40130L52-W	-	-	-	-
	LL28SE-DFY40130L19-W	II-Short	40°×150°	0.5	
	LL28SE-DFY40130L52-W	II-Short	40°×150°	0.5	
	LL30SE-DFY45L52-W	-	42°	1.2	
 SAMSUNG LH351B	LL11SE-DFY40130L19-W	I-Short	39°×137°	0.5	
	LL11SE-DFY40130L52-W	I-Short	39°×137°	0.5	
	LL22SE-DFY40130L19-W	II-Short	44°×139°	0.5	
	LL22SE-DFY40130L52-W	II-Short	44°×139°	0.5	
	LL28SE-DFY40130L19-W	I-Short	43°×141°	0.5	
	LL28SE-DFY40130L52-W	I-Short	43°×141°	0.5	
	LL30SE-DFY45L52-W	-	42°	1.2	

Product Nomenclature

Ledlink Led Type Lens Angle
LL 11 SE- DFY 40130 L19
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655, Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com

