



2-Way Outlet Shapes, VG style

Helashrink 200 Series

Features and Benefits


- Mechanical tension relief in cable harnesses



For Material / Adhesive information please refer to page 260, 261.



203-1 supplied / fully recovered.

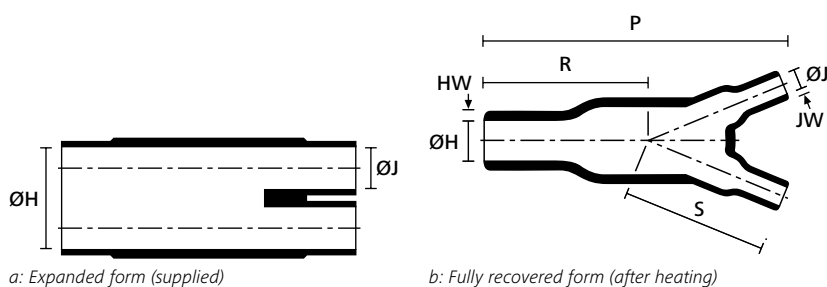

TYPE	ØH min. a	ØH max. b	ØJ min. a	ØJ max. b	P ± 10%	R ± 10%	HW ± 20%	JW ± 20%	JW ± 30%	JW nom.	S nom.	Designation as per VG-Norm	Article-No.
206-1-G	13.0	6.0	7.0	3.0	41.0	19.0	1.5	-	1.0	1.0	19.0	VG 95343 T08 C 001 A	402-06180
212-1-G	14.5	8.0	8.5	5.5	82.6	83.0	2.3	-	2.0	2.0	63.0	VG 95343 T08 C 005 A	402-12180
213-1-G	17.3	7.9	11.1	7.9	140.0	83.1	2.3	2.3	-	1.0	64.0	-	402-13180
203-1-G	27.0	12.0	13.0	6.0	80.0	43.0	2.5	-	1.5	1.5	43.0	VG 95343 T08 C 002 A	402-03180
204-1-G	39.0	18.0	27.0	12.0	66.0	81.0	3.1	-	2.5	2.0	81.0	VG 95343 T08 C 003 A	402-04180

All dimensions in mm. Subject to technical changes.