


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/3/30

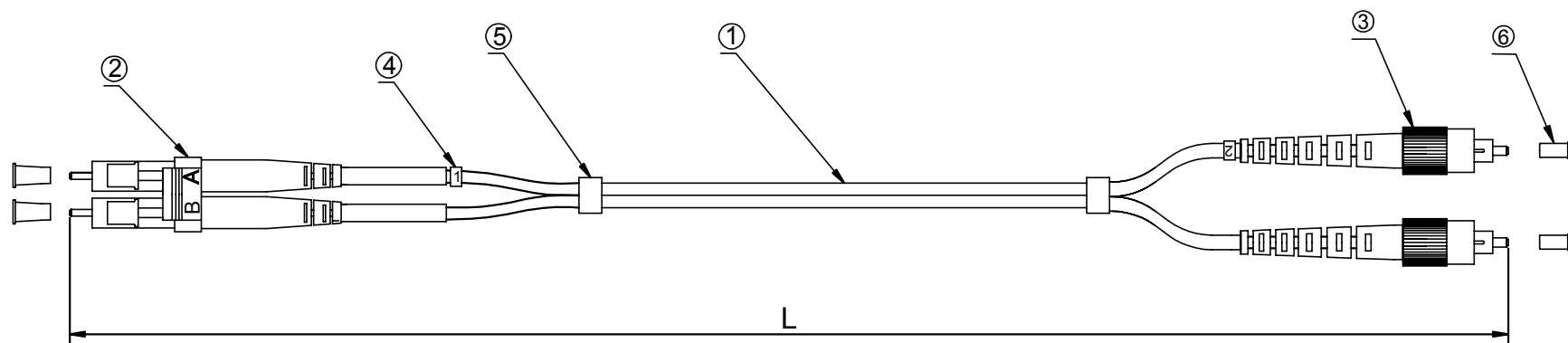

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
914S-2-5-00100-PL	671-458-A	1000±100	Yellow
914S-2-5-00200-PL	671-458-B	2000±100	Yellow
914S-2-5-00300-PL	671-458-C	3000±100	Yellow
914S-2-5-00500-PL	671-458-D	5000±100	Yellow
914S-2-5-00700-PL	671-458-E	7000±100	Yellow
914S-2-5-01000-PL	671-458-F	10000±100	Yellow
914S-2-5-01500-PL	671-458-G	15000±100	Yellow
914S-2-5-02000-PL	671-458-H	20000±100	Yellow
914S-2-5-02500-PL	671-458-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB

Return loss > 50 dB

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	FC SM Connector (Metal housing Blue boot)
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, OFNP, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC
Industrial Cable and Connector Technology

		TITLE	Patch Cord, LC-FC,SM-9/125 G652D, Duplex, OFNP, yellow, 2.0mm, xxM			
UNIT	mm	P/N	above	DRAWN BY		
unless otherwise stated Tolerances mm XXX.XX ±0.3 XX.XX ±0.2 X.XX ±0.1 angular ±2°		Customer P/N	914S-2-5-0XXXX-PL	CHECK BY		
SIZE A4		SCALE Free	PAGE	1/1	APPROVAL BY	