




Part Number : [734036290](#)

Product Description : FAKRA Jack, Straight, Crimp, RG-316 / RG-174 Cable, Brass Body, Nickel (Ni) Plated, Keying Code Z, Water Blue, 50 Ohms

Series Number : 73403

Status : Active

Product Category : RF / Coaxial Connectors

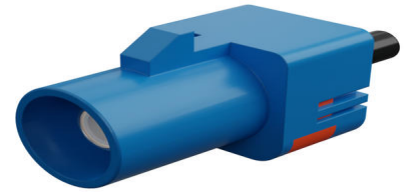

Documents and Resources

Drawings

[734036290 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[AS-73597-046-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2025)4165-DC (25 June 2025) SCIP:811da762-3c0b-47db-895c-1676b16b6792
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73403
Description	FAKRA Jack, Straight, Crimp, RG-316 / RG-174 Cable, Brass Body, Nickel (Ni) Plated, Keying Code Z, Water Blue, 50 Ohms
Application	Automotive, RF
Product Name	FAKRA,SMB
Style	Cable
Type	Subminiature
UPC	887191452661

Electrical

Frequency	6 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 335 Vrms@Sea Level

Physical

Cable Attachment	Crimp
Gender	Jack

Keying to Mating Part	Yes
Net Weight	3.156/g
Orientation	Straight
Packaging Type	Bag
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	N/A
Reverse Polar	No
Wire/Cable Type	LMR-100, RG-174, RG-188, RG-316

This document was generated on Apr 13, 2026