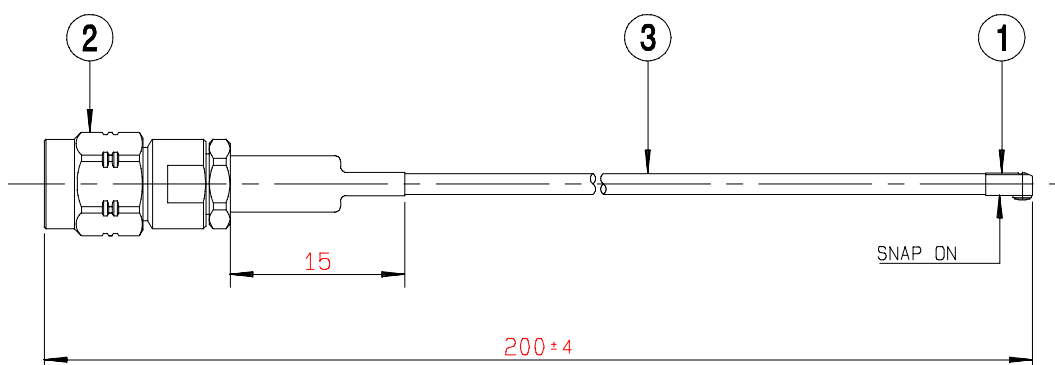


MALE SMA-UMP HIGHT 2.6 SNAP**R285.025.311****20 CM CABLE 2/50 S-BR**Series : **CORD-STD****PACKAGING**

Standard	Unit	Other
20	'W' option	Contact us

* 1 * Connector A : **R107.111.200**
 * 2 * Connector B : **R124.069.123**
 * 3 * Cable : **C291.140.087**
 Type : **CAB HF 2/50 S - FTX 111258 MARRON**

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 °C
VSWR	1.30 + 0.000 x F(GHz) Maxi
Insertion loss	0.41 $\sqrt{F}$(GHz) dB Maxi
Voltage rating	100 Veff Maxi
Dielectric withstanding voltage	350 Veff mini
Insulation resistance	1000 MΩ mini

SPECIFICATION

Weight	6.100 g
Cable retention	71 N mini
Others :	

**Edition : 0145 A**

Design changes may be in order to improve the product.