

You are here: [Home](#) ▶ [Piezo Buzzer](#) ▶ [Piezo Transducer](#) ▶ [Pin](#) ▶ KPEG169

All in one search

Tag

Title

Category

-- Select category --

[Piezo Buzzer](#)

[Piezo Indicator](#)

[Piezo Siren](#)

[Piezo Sounder](#)

[Piezo Transducer](#)

[Annunciator Alarm](#)

[Pin](#)

[Pin Type-Self Drive](#)

[SMD](#)

[Vertical Mounting](#)

[Wire](#)

[Wire Type-Self Drive](#)

[Piezo Speaker](#)

[Piezo Tweeter](#)

[Magnetic Buzzer](#)

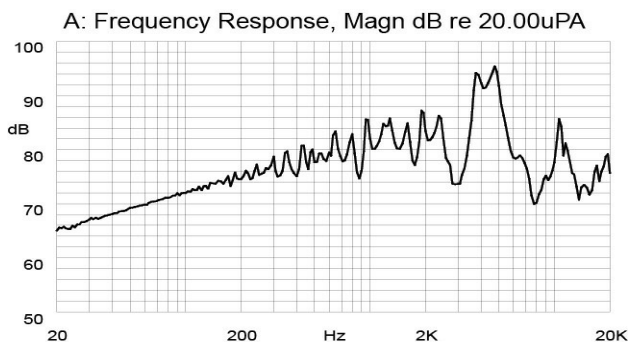
[Micro Speaker](#)

[Dynamic Receiver](#)

[ECM](#)

[Audio Products](#)

KPEG169

[Print](#)


Additional Info

Rated Frequency (Hz):	4000
Rated Voltage (Vp-p / VDC):	Max. 30
Current Consumption (mA):	Max.7@19Vp-p, Square Wave, 4.0KHz
Sound Pressure Level (dB):	Min 80dB@10cm/10vpp, Square Wave, 4.0KHz
Electrostatic Capacity (pF):	8,500 +/- 30% @ 120Hz/1V
Operating Temperature (°C):	-30 ~ + 85
Storage Temperature (°C):	-40 ~ + 90
Dimension (mm):	Φ14.0x6.7



Like Sign Up to see what your friends like.

Tagged under

10Vpp Φ130x67mm

More in this category: [« KPEG169-P32](#) [KPEG159 »](#)

[back to top](#)

