

**Product number F13659_ANGELINA-S-B**

Family	Angelina	FWHM	(simulated) 22
Type	Reflector	Efficiency	(simulated) 95 %
LED	CLL04x/CLU04x	cd/Im	(simulated) 3.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13660_ANGELINA-M-B**

Family	Angelina	FWHM	(simulated) 37
Type	Reflector	Efficiency	(simulated) 95 %
LED	CLL04x/CLU04x	cd/Im	(simulated) 1.600
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13661_ANGELINA-W-B**


Family	Angelina	FWHM	(simulated) 52
Type	Reflector	Efficiency	(simulated) 95 %
LED	CLL04x/CLU04x	cd/Im	(simulated) 1.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13661_ANGELINA-W-B**

Family	Angelina	FWHM	(simulated) 55
Type	Reflector	Efficiency	(simulated) 90 %
LED	CLL04x/CLU04x	cd/Im	(simulated) 0.940
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13325_ANGELINA-S**

Family	Angelina	FWHM	29 degrees
Type	Reflector	Efficiency	93 %
LED	CLL04x/CLU04x	cd/Im	1.700
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

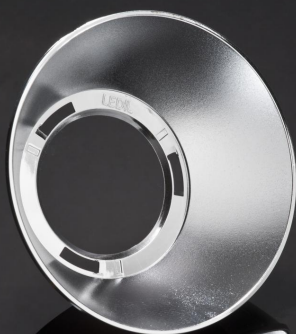**Product number FCN13691_ANGELINA-S**

Family	Angelina	FWHM	29 degrees
Type	RefPack	Efficiency	93 %
LED	CLL04x/CLU04x	cd/Im	1.700
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	36.04 mm		
Style	Round		
Optic Material	-		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13325_ANGELINA-S**

Family	Angelina	FWHM	30 degrees
Type	Reflector	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	1.600
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13659_ANGELINA-S-B**

Family	Angelina	FWHM	30 degrees
Type	Reflector	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	1.600
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13659_ANGELINA-S-B**

Family	Angelina	FWHM	33 degrees
Type	Reflector	Efficiency	88 %
LED	CLL04x/CLU04x	cd/Im	1.390
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number FC13977_ANGELINA-RZ-S-B**

Family	Angelina	FWHM	33 degrees
Type	RefPack	Efficiency	88 %
LED	CLL04x/CLU04x	cd/Im	1.390
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	["screw", "socket"]		
Status	Production ready		

For BJB connectors

**Product number F13660_ANGELINA-M-B**

Family	Angelina	FWHM	39 degrees
Type	Reflector	Efficiency	94 %
LED	CLL04x/CLU04x	cd/Im	1.200
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number F13401_ANGELINA-M**

Family	Angelina	FWHM	42 degrees
Type	Reflector	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	1.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number FCN13692_ANGELINA-M**

Family	Angelina	FWHM	42 degrees
Type	RefPack	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	1.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	36.04 mm		
Style	Round		
Optic Material	-		
Holder Material	-		
Fastening	""		
Status	Production ready		

Product number F13401_ANGELINA-M

Family	Angelina	FWHM	43 degrees
Type	Reflector	Efficiency	91 %
LED	CLL04x/CLU04x	cd/Im	1.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

Product number F13402_ANGELINA-W

Family	Angelina	FWHM	43 degrees
Type	Reflector	Efficiency	91 %
LED	CLL04x/CLU04x	cd/Im	1.100
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

Product number F13660_ANGELINA-M-B

Family	Angelina	FWHM	50 degrees
Type	Reflector	Efficiency	87 %
LED	CLL04x/CLU04x	cd/Im	0.920
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number FC13978_ANGELINA-RZ-M-B**

Family	Angelina	FWHM	50 degrees
Type	RefPack	Efficiency	87 %
LED	CLL04x/CLU04x	cd/Im	0.920
Color	Metal	Gerber File	Available
Diameter	82 mm	For BJB connectors	
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	["screw", "socket"]		
Status	Production ready		

Product number F13402_ANGELINA-W

Family	Angelina	FWHM	54 degrees
Type	Reflector	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	0.960
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

Product number FCN13693_ANGELINA-W

Family	Angelina	FWHM	54 degrees
Type	RefPack	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	0.960
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	36 mm		
Style	Round		
Optic Material	-		
Holder Material	-		
Fastening	""		
Status	Production ready		

Product number F13661_ANGELINA-W-B

Family	Angelina	FWHM	62 degrees
Type	Reflector	Efficiency	92 %
LED	CLL04x/CLU04x	cd/Im	0.820
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		



**Product number F13661_ANGELINA-W-B**

Family	Angelina	FWHM	66 degrees
Type	Reflector	Efficiency	87 %
LED	CLL04x/CLU04x	cd/Im	0.730
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number FC13979_ANGELINA-RZ-W-B**

Family	Angelina	FWHM	66 degrees
Type	RefPack	Efficiency	87 %
LED	CLL04x/CLU04x	cd/Im	0.730
Color	Metal	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	PC		
Holder Material	-		
Fastening	["socket", "screw"]		
Status	Production ready		

For BJB connectors

**Product number F13838_ANGELINA-XW**

Family	Angelina	FWHM	88 degrees
Type	Reflector	Efficiency	95 %
LED	CLL04x/CLU04x	cd/Im	0.510
Color	White	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	HRPC		
Holder Material	-		
Fastening	""		
Status	Production ready		

**Product number FCN13912_ANGELINA-XW**

Family	Angelina	FWHM	88 degrees
Type	RefPack	Efficiency	95 %
LED	CLL04x/CLU04x	cd/Im	0.510
Color	White	Gerber File	Available
Diameter	-		
Height	-		
Style	Round		
Optic Material	-		
Holder Material	-		
Fastening	["screw"]		
Status	Production ready		

**Product number F13839_ANGELINA-XW-B**

Family	Angelina	FWHM	91 degrees
Type	Reflector	Efficiency	94 %
LED	CLL04x/CLU04x	cd/Im	0.500
Color	White	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	HRPC		
Holder Material	-		
Fastening	-		
Status	Production ready		

Product number F13839_ANGELINA-XW-B

Family	Angelina	FWHM	91 degrees
Type	Reflector	Efficiency	88 %
LED	CLL04x/CLU04x	cd/Im	0.450
Color	White	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	HRPC		
Holder Material	-		
Fastening	-		
Status	Production ready		

Product number FC13982_ANGELINA-RZ-XW-B

Family	Angelina	FWHM	91 degrees
Type	RefPack	Efficiency	88 %
LED	CLL04x/CLU04x	cd/Im	0.450
Color	White	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	HRPC		
Holder Material	-		
Fastening	["screw", "socket"]		
Status	Production ready		

For BJB connector 47.319.2030


Product number F13839_ANGELINA-XW-B

Family	Angelina	FWHM	92 degrees
Type	Reflector	Efficiency	94 %
LED	CLL04x/CLU04x	cd/Im	0.480
Color	White	Gerber File	Available
Diameter	82 mm		
Height	31 mm		
Style	Round		
Optic Material	HRPC		
Holder Material	-		
Fastening	-		
Status	Production ready		



PRODUCT DATASHEET
Angelina series
last update 16/1/2015

NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.

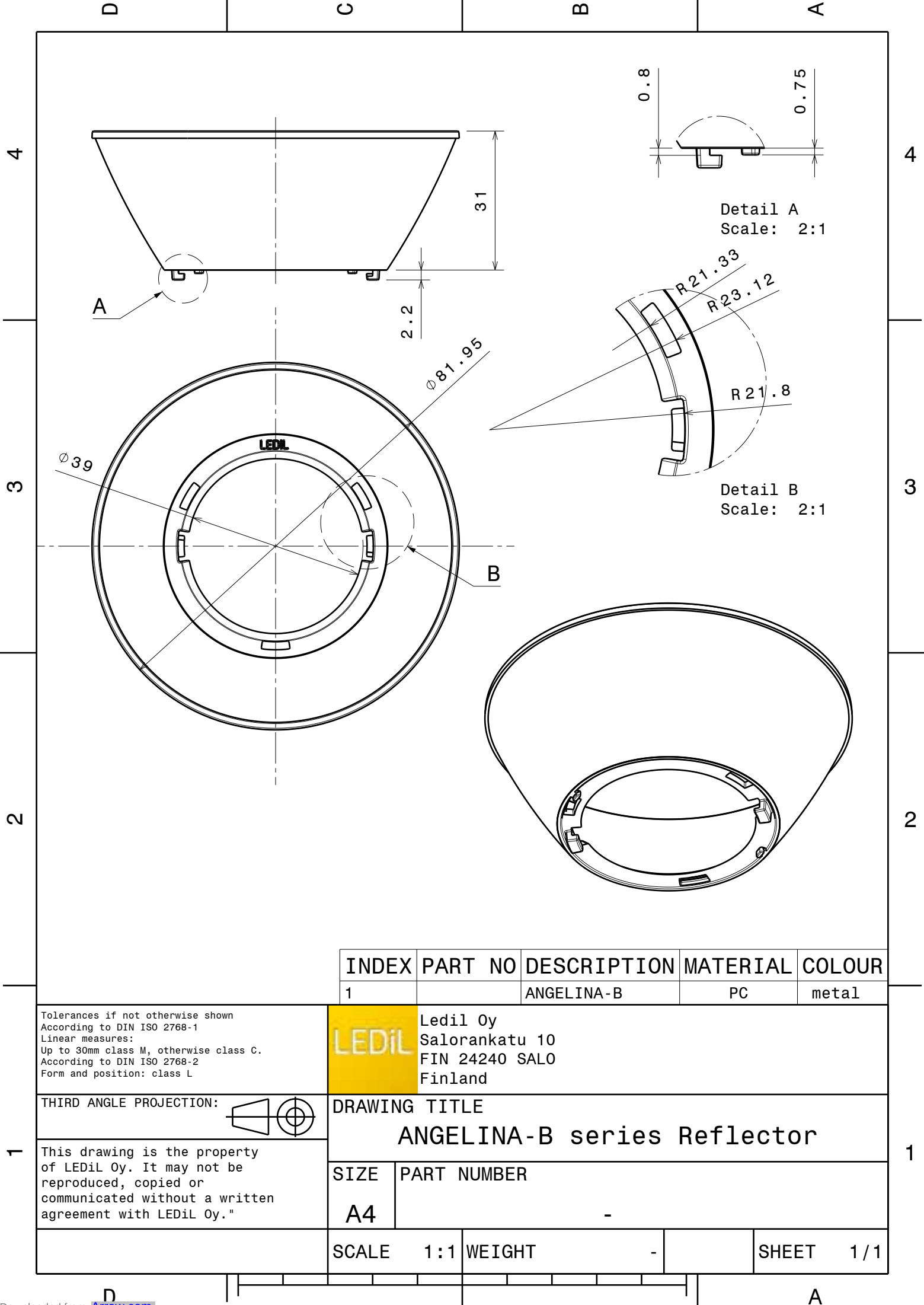


INDEX	PART NO	DESCRIPTION	MATERIAL	COLOUR
1		ANGELINA-B	PC	metal

Tolerances if not otherwise shown
According to DIN ISO 2768-1
Linear measures:
Up to 30mm class M, otherwise class C.
According to DIN ISO 2768-2
Form and position: class L

LEDiL

Ledil Oy
Salorankatu 10
FIN 24240 SALO
Finland

 THIRD ANGLE PROJECTION:



DRAWING TITLE

ANGELINA-B series Reflector

This drawing is the property
of LEDiL Oy. It may not be
reproduced, copied or
communicated without a written
agreement with LEDiL Oy."

SIZE

A4

PART NUMBER

-

SCALE

1:1


WEIGHT

-

SHEET


1/1

Luminaire: Ledil Oy F13661_ANGELINA-W-B_(CLU048)_(47_319_2030)_SIMULATED
Lamps: 1 x Citizen CLU048 (CLU048-1212C4-303M2K1) + BJB connector 47.319.2030

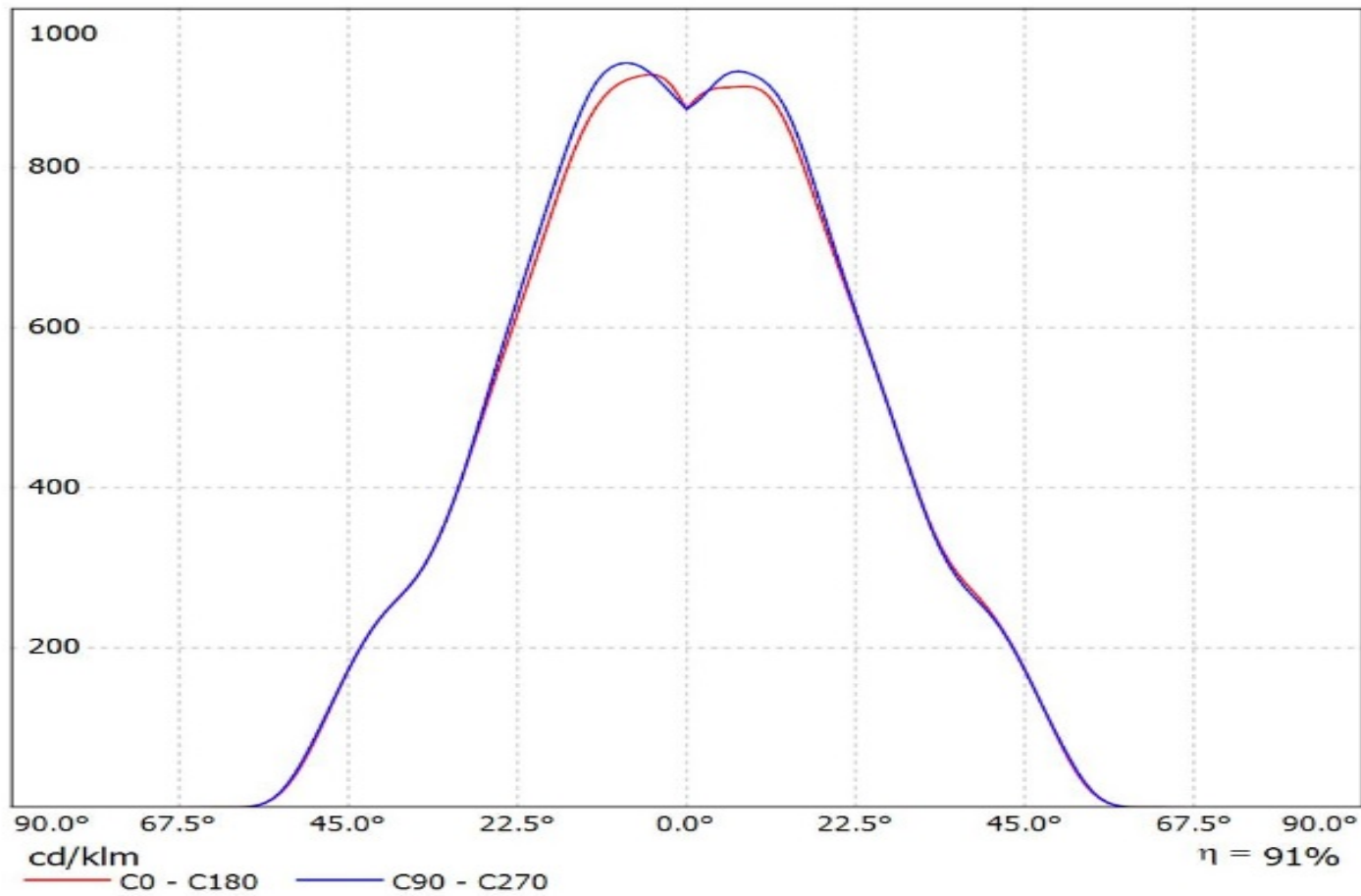


Luminaire: Ledil FCN13691_ANGELINA-S_(CLU044)_(431_Typ_L3)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

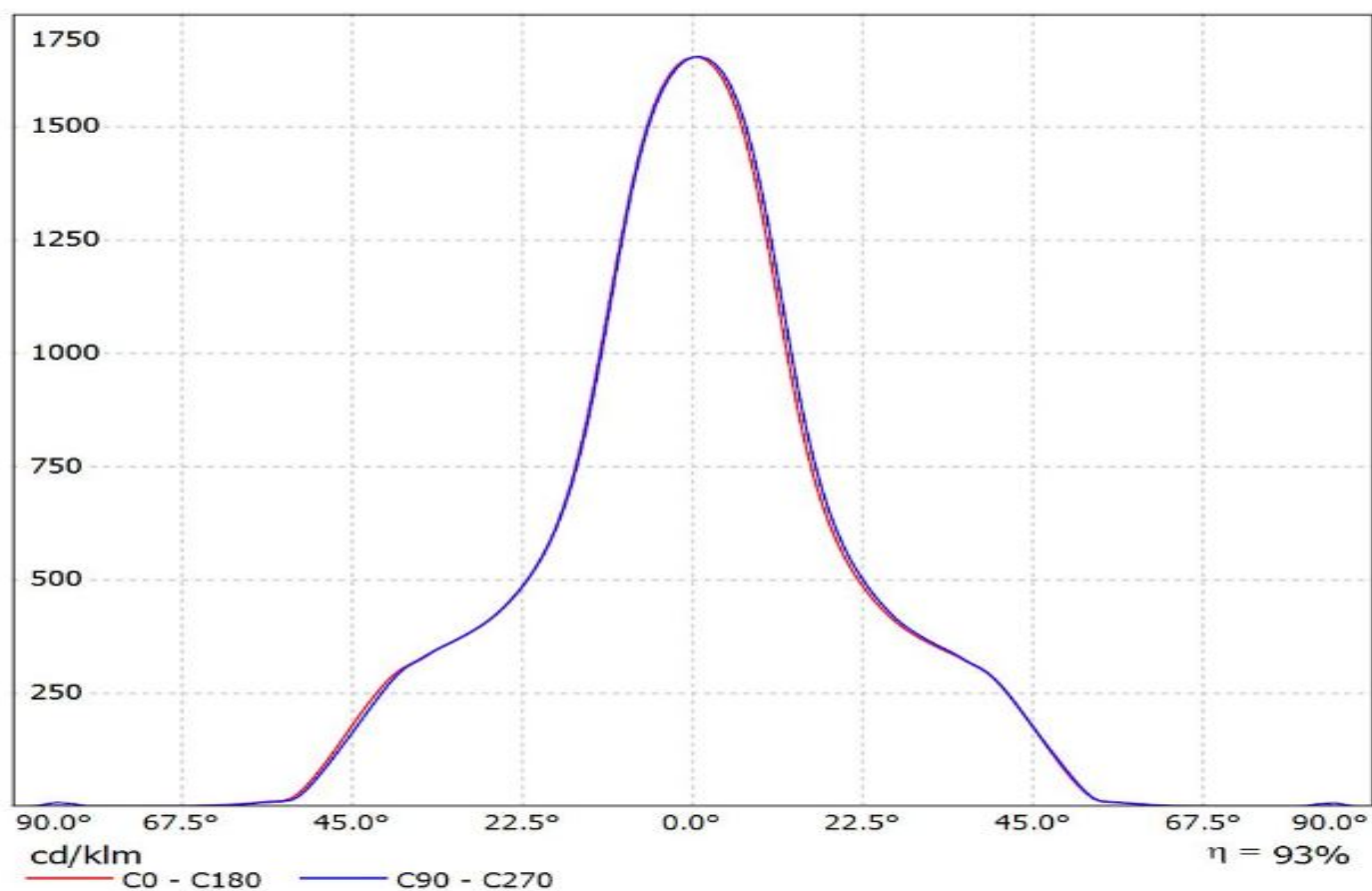


Luminaire: Ledil F13325_ANGELINA-S_(CLU046+IDEAL)
Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

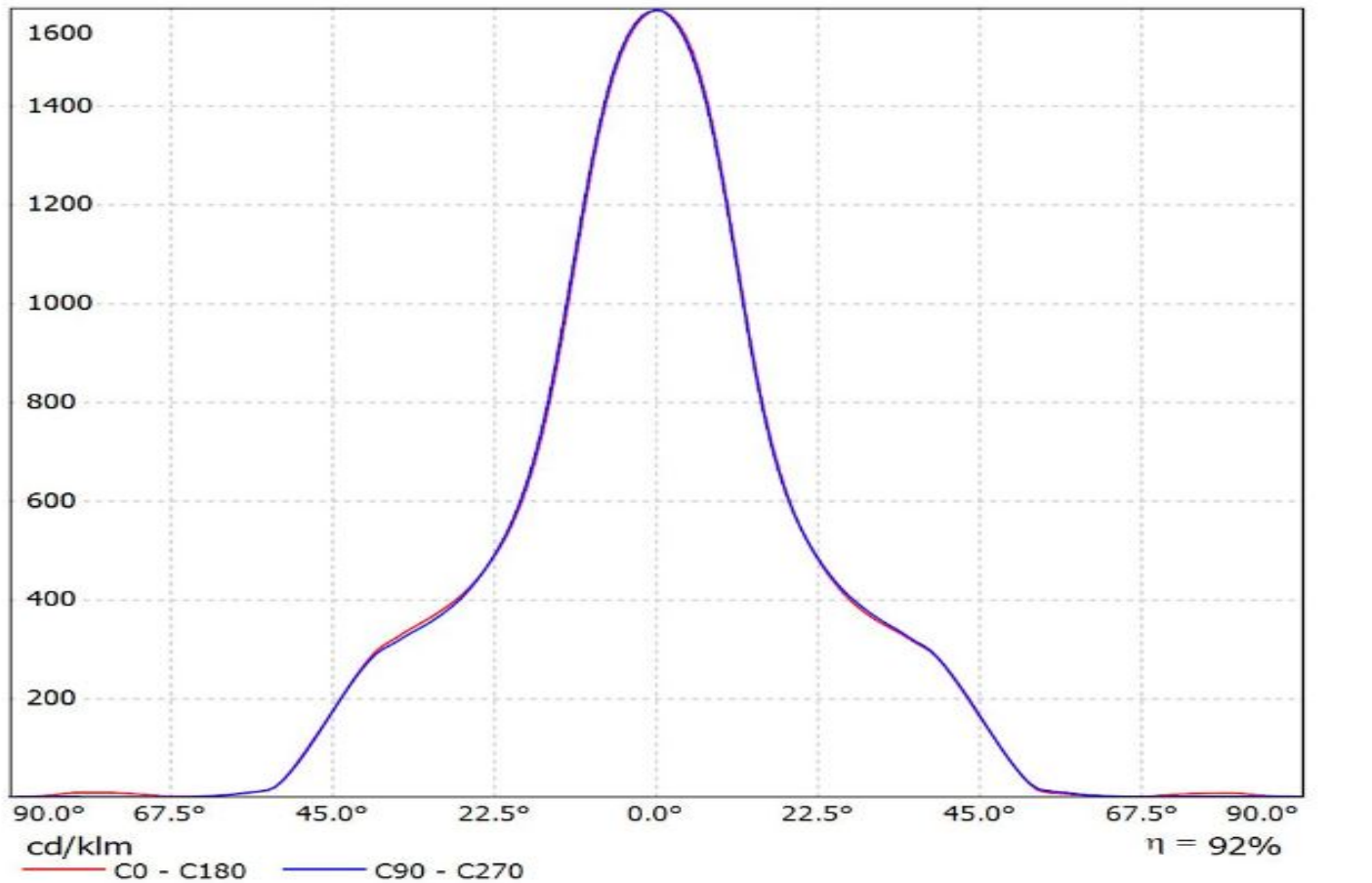


Luminaire: LEDiL Oy F13659_ANGELINA-S-B_(CLU044)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

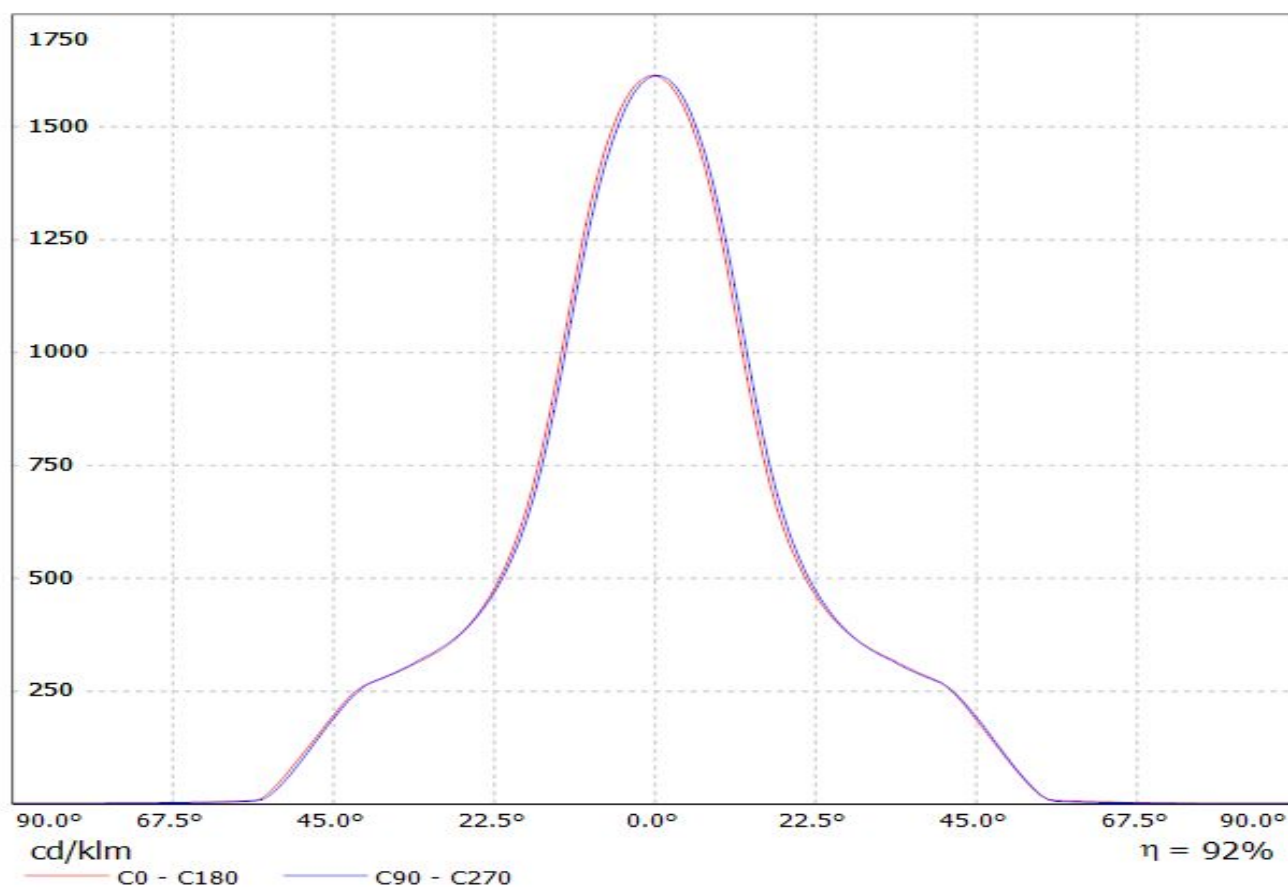


Luminaire: LEDiL Oy FC13977_ANGELINA-RZ-S-B_(CLU044)_+_ (Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

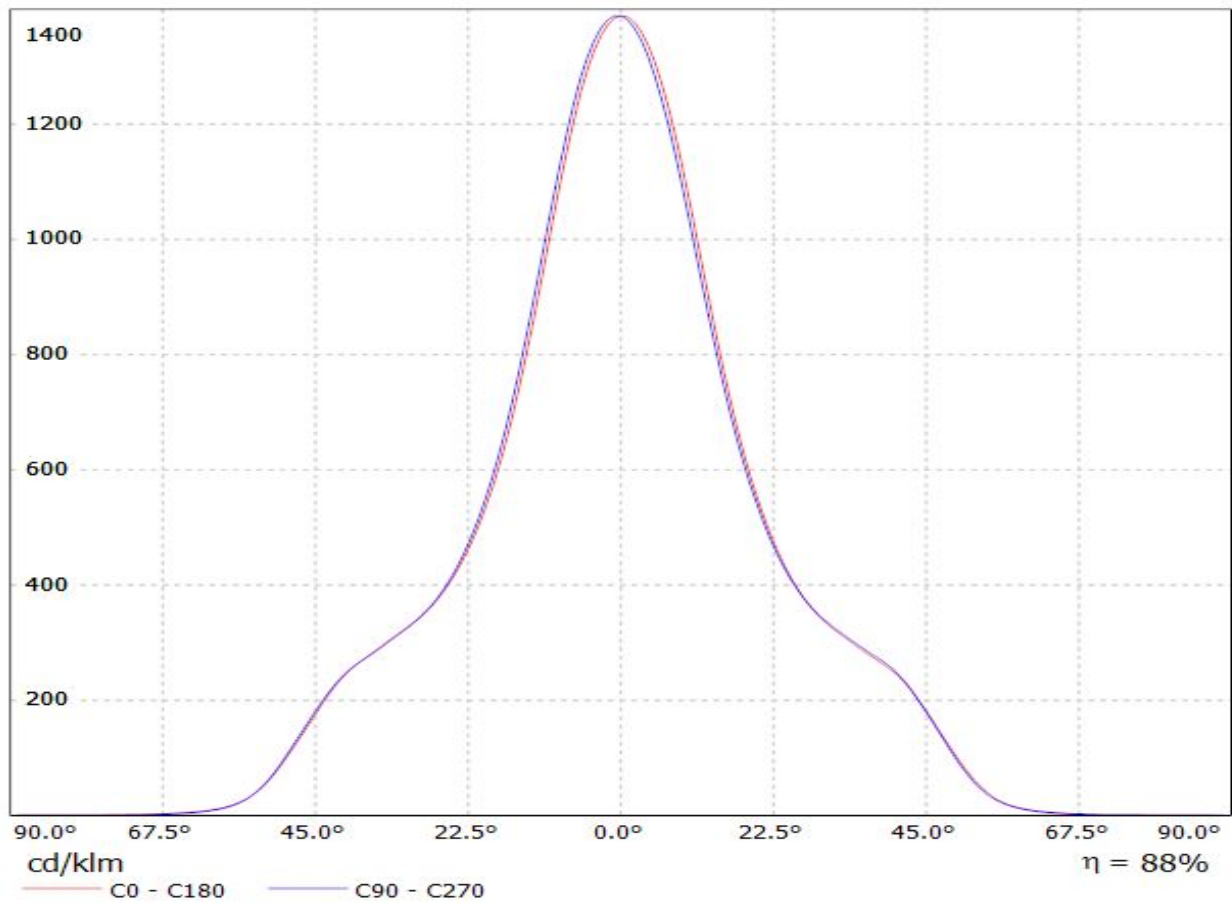


Luminaire: LEDiL Oy F13660_ANGELINA-M-B_(CLU044)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

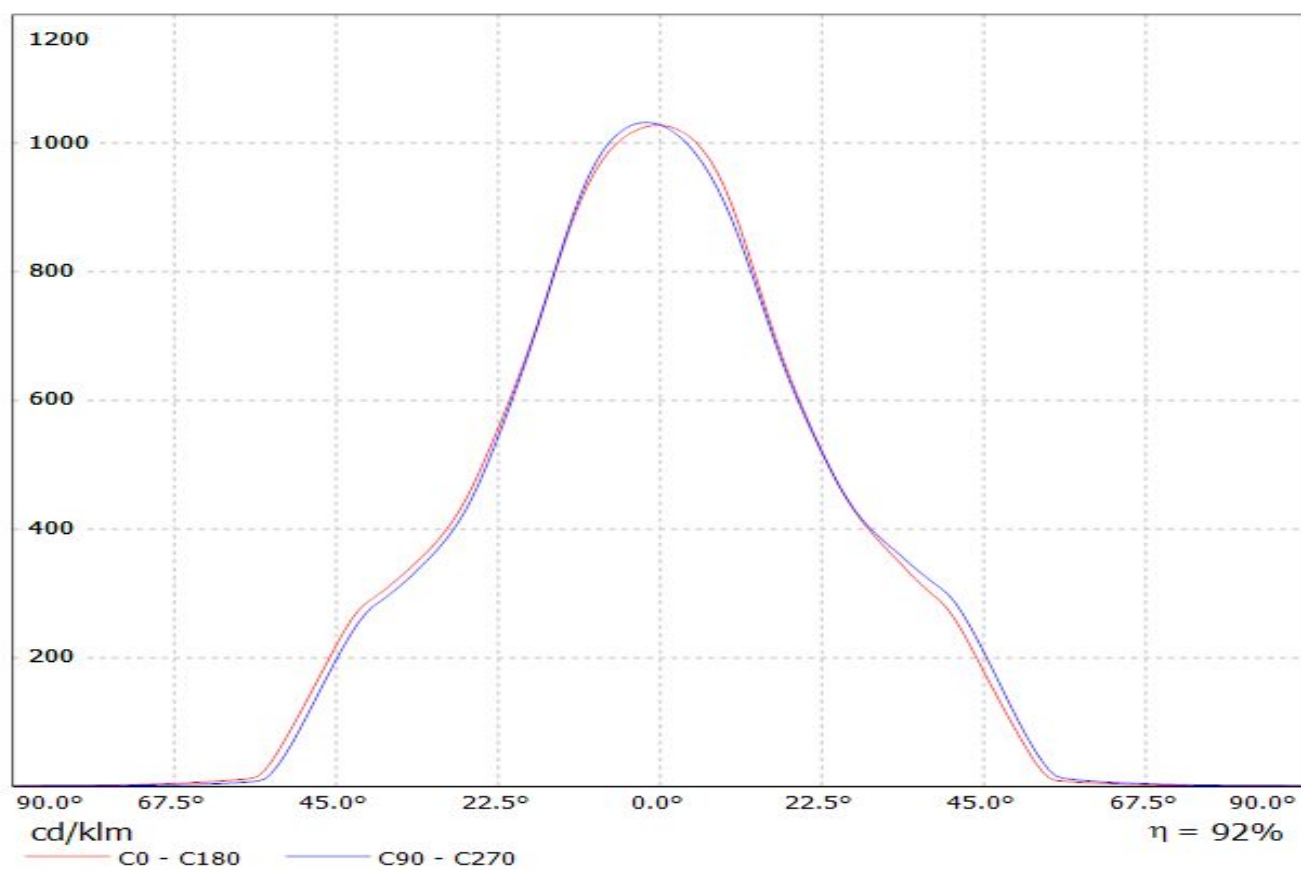


Luminaire: Ledil FCN13692_ANGELINA-M (CLU044)_ (431_Typ_L3)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

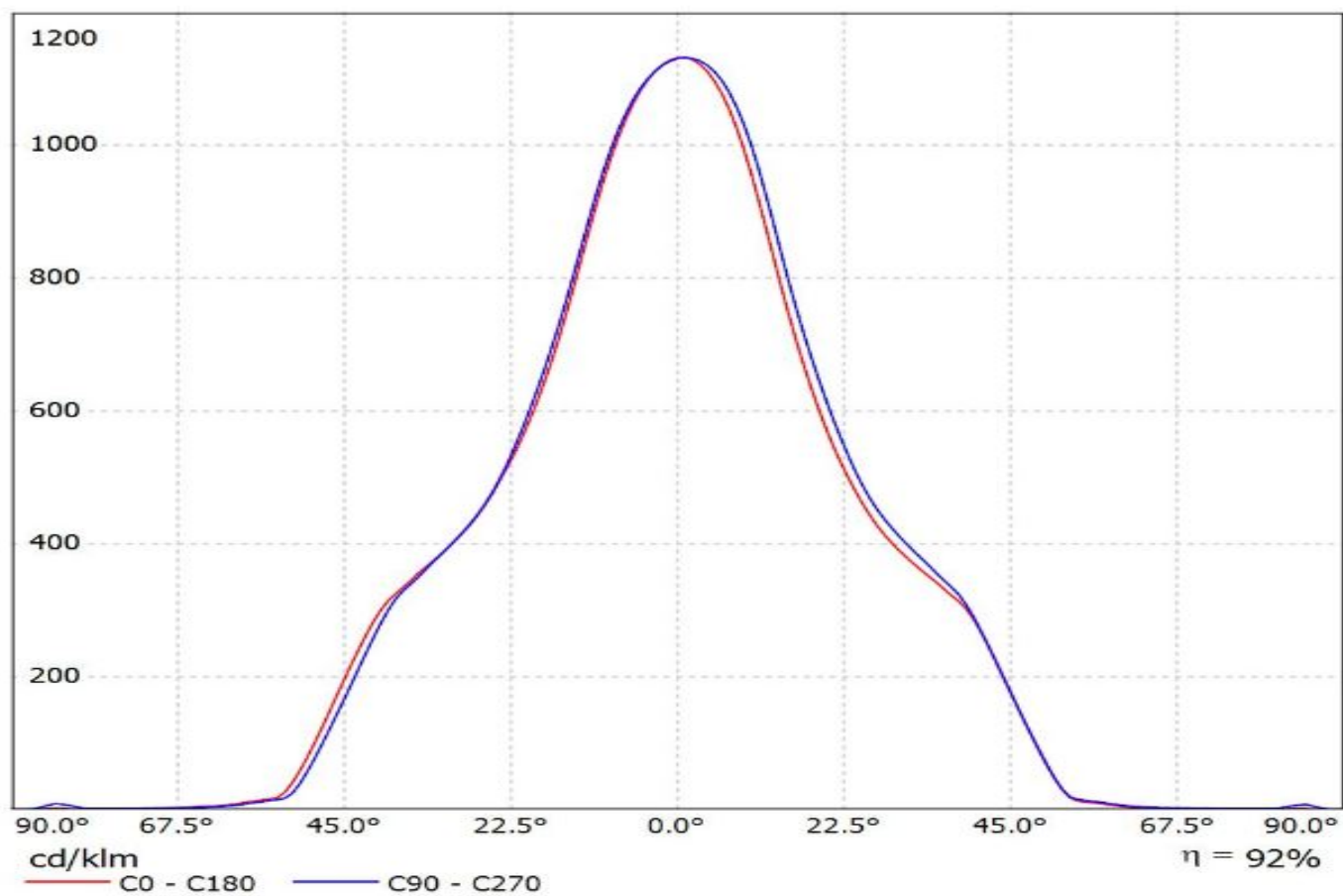


Luminaire: Ledil F13401_ANGELINA-M_(CLU046+IDEAL)

Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

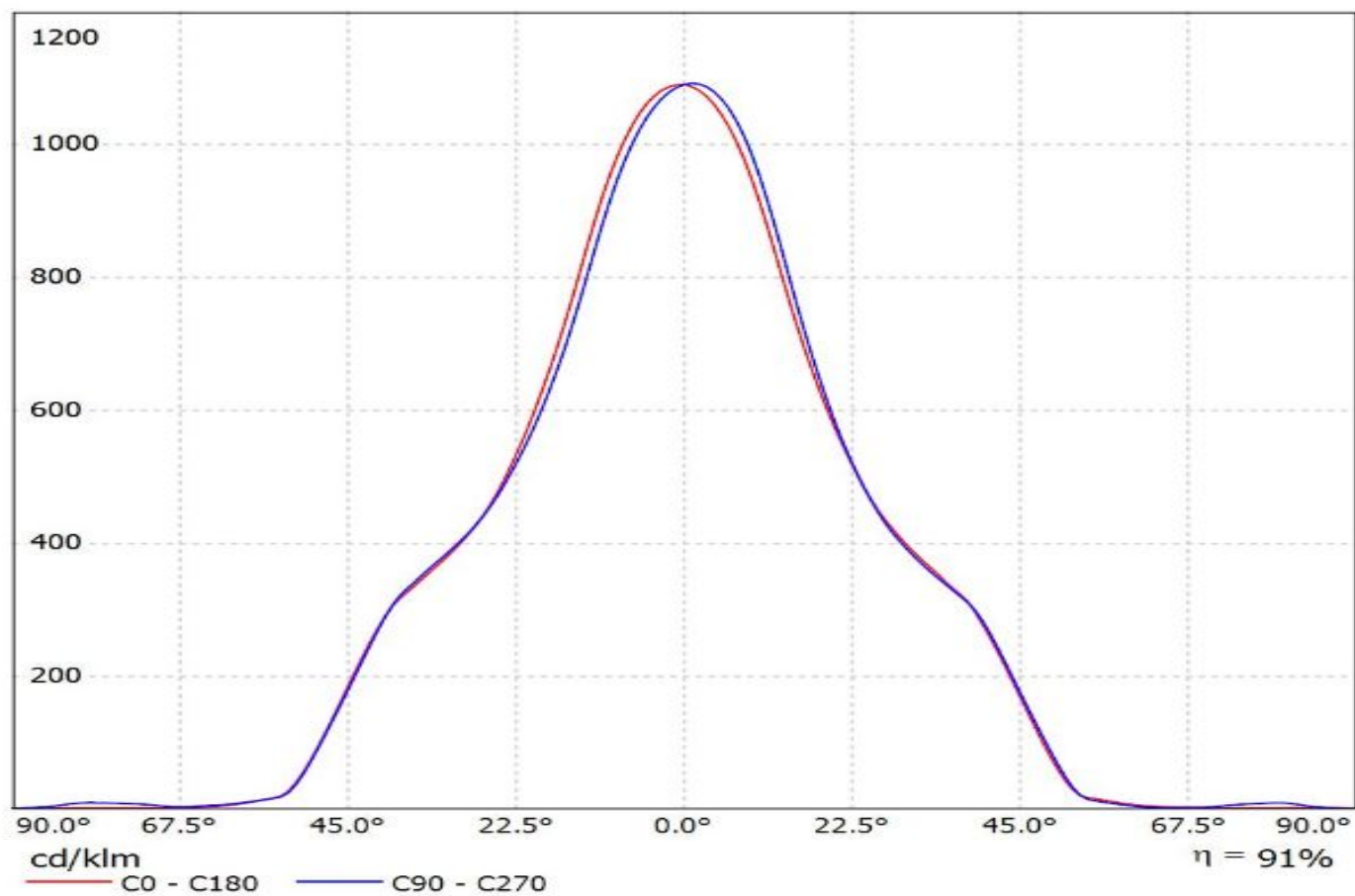


Luminaire: Ledil F13402_ANGELINA-W_(CLU046+IDEAL)

Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

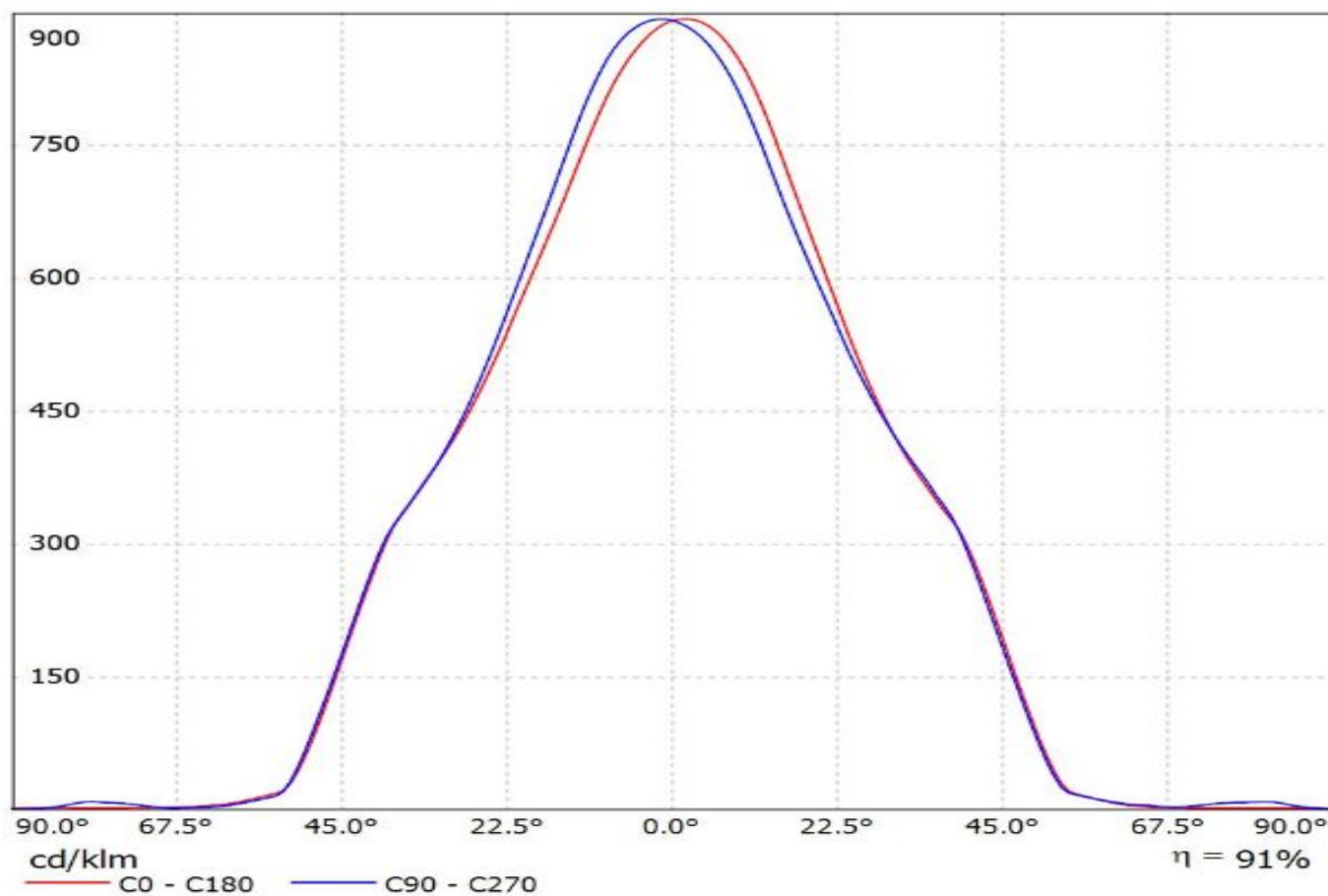


Luminaire: LEDiL Oy FC13978_ANGELINA-RZ-M-B (CLU044) + (Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

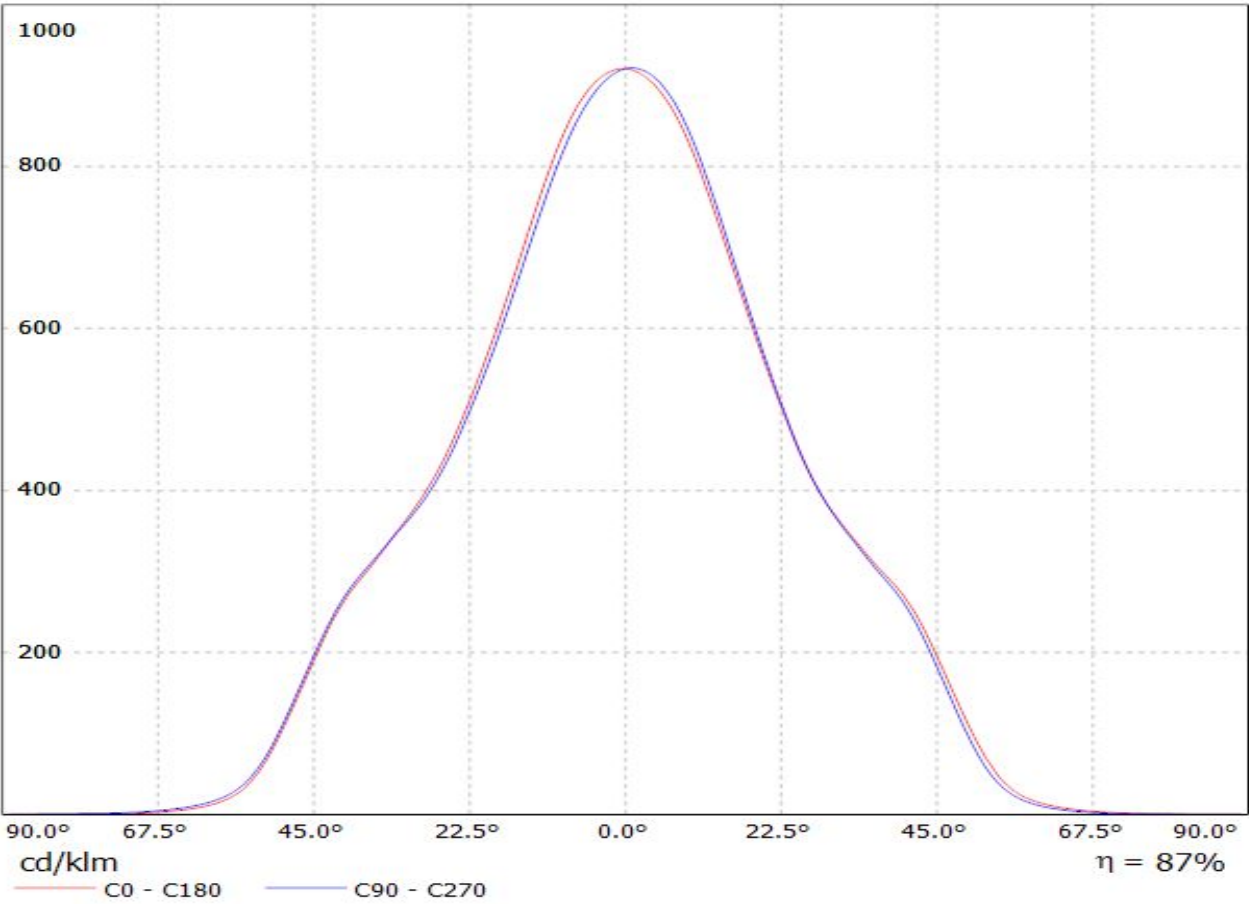


Luminaire: Ledil FCN13693_ANGELINA-W_(CLU044)_(431_Typ_L3)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

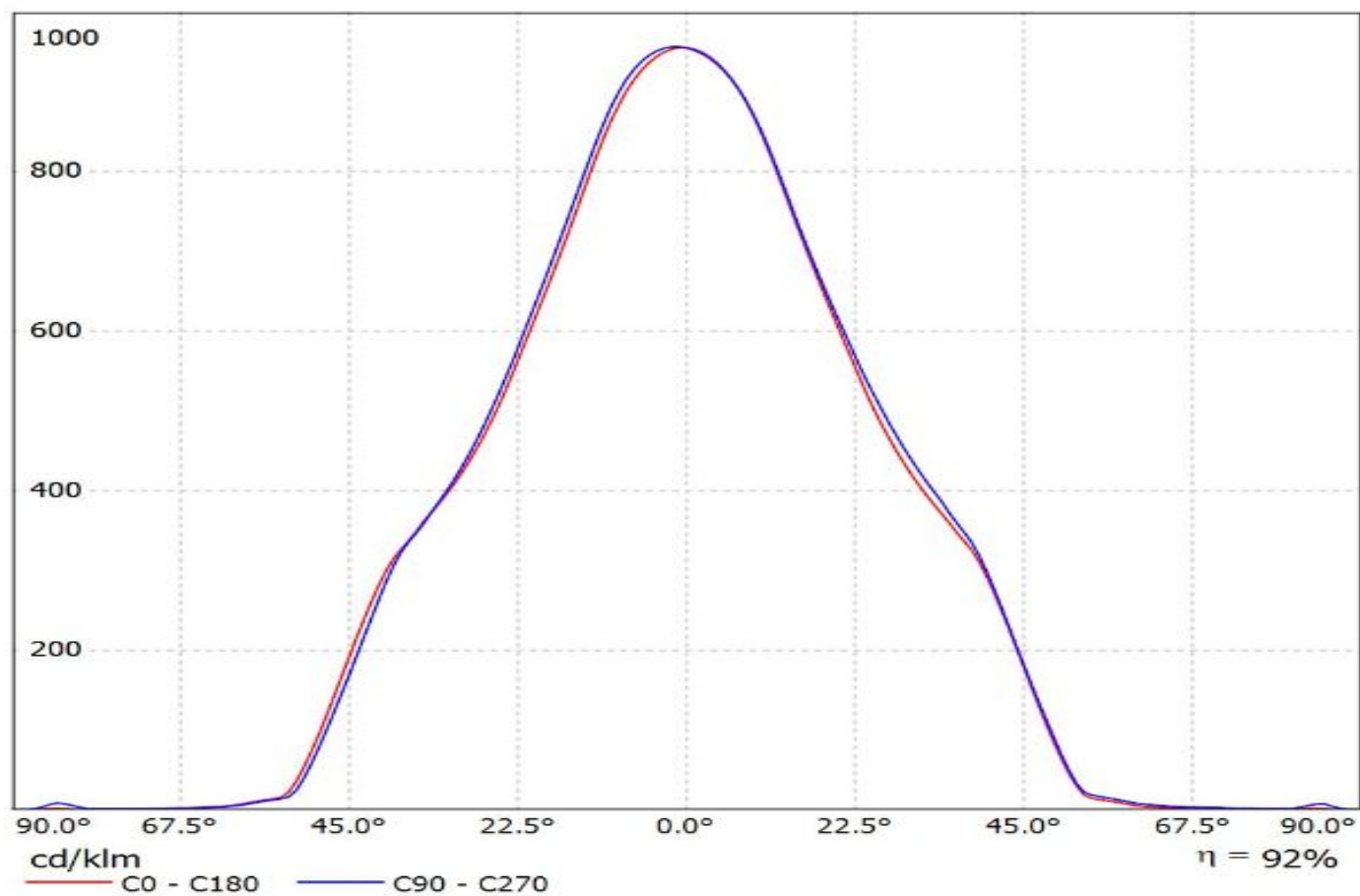


Luminaire: LEDiL Oy F13661_ANGELINA-W-B_(CLU044)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

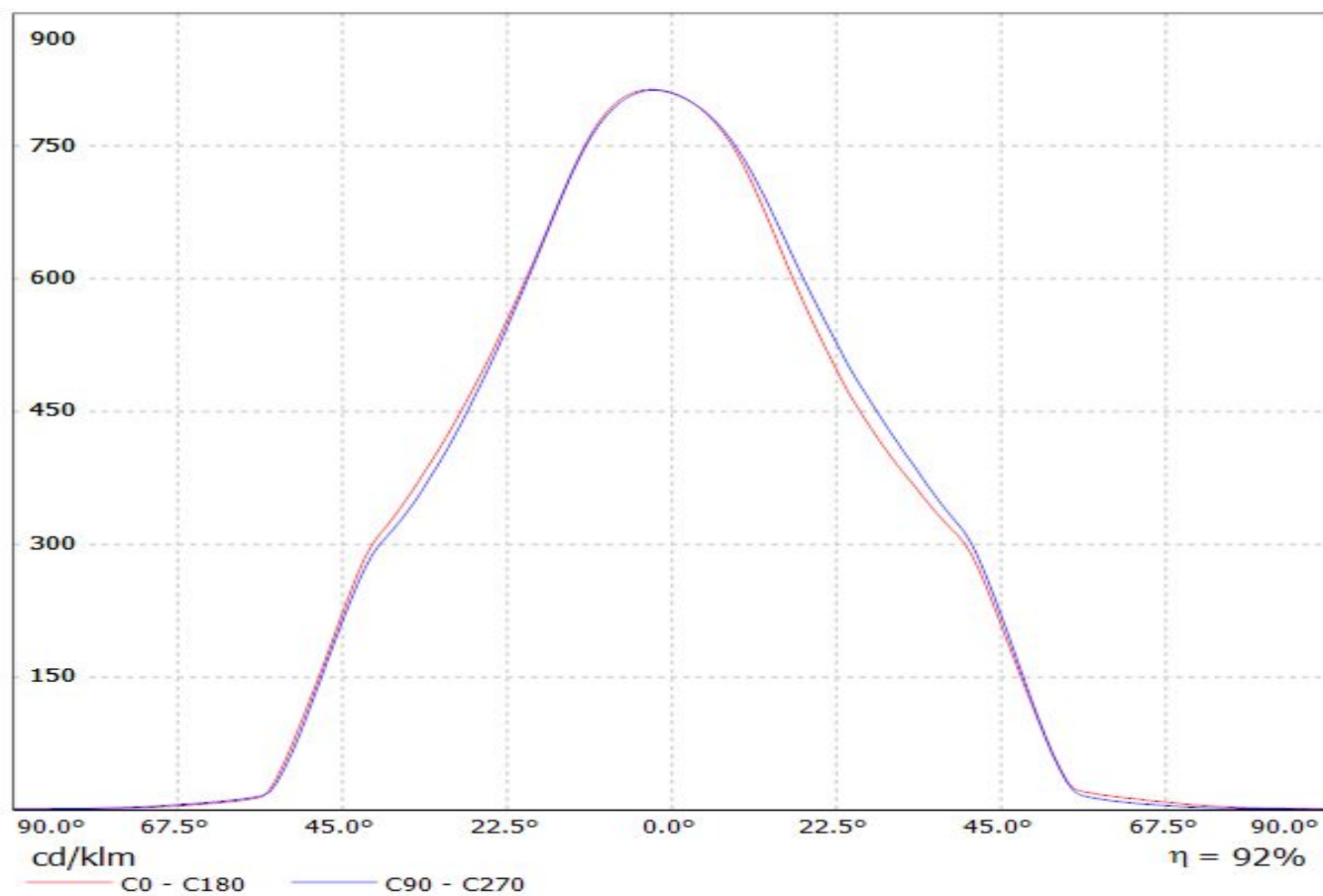


Luminaire: LEDiL Oy FC13979_ANGELINA-RZ-W-B_(CLU044)_+_ (Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

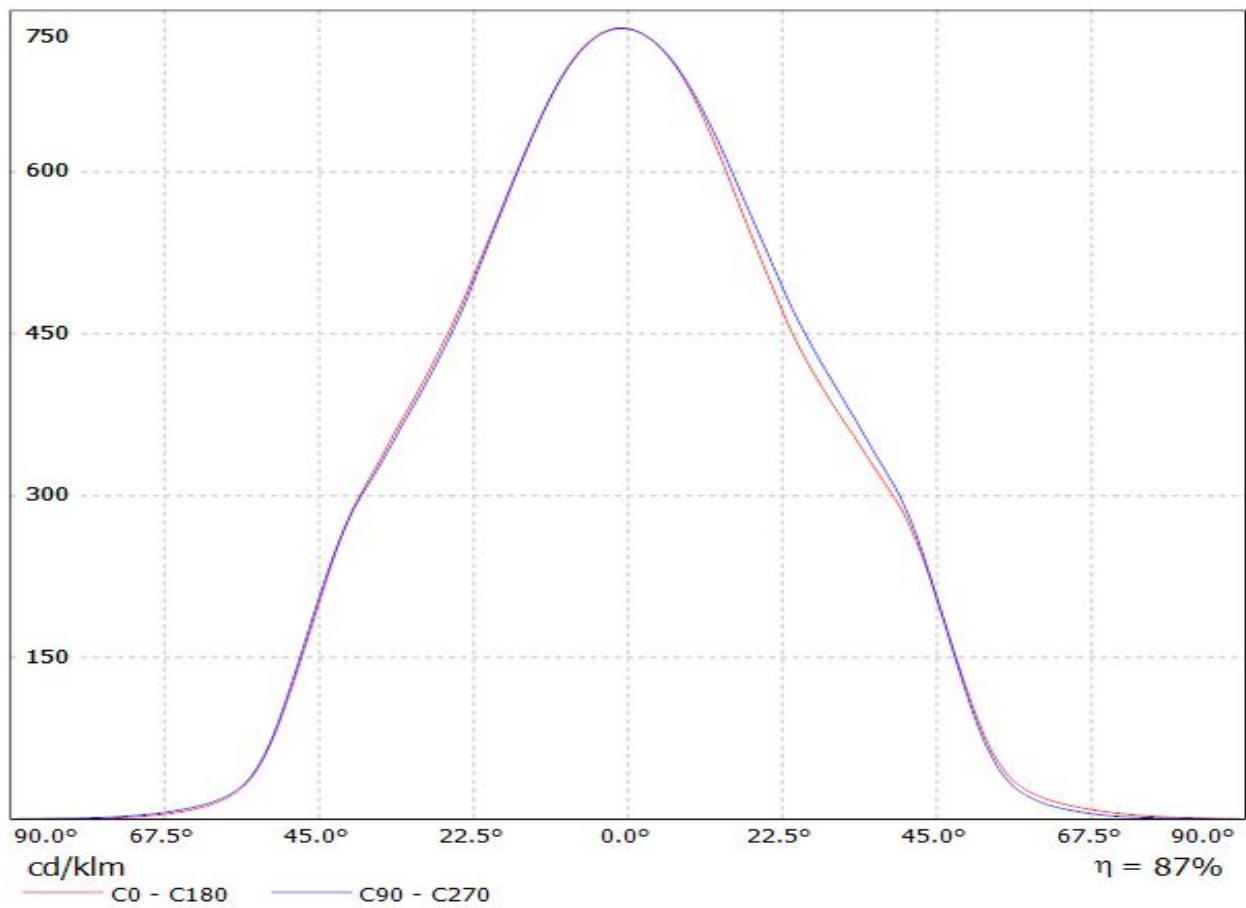


Luminaire: Ledil FCN13912_ANGELINA-XW (CLU044)_ (431_Typ_L3)


Lamps: 1 x Citizen_CLU044_ (CLU044-1212B8-303M1A2)_ 1272.54lm@250mA_P=8.16W_I=0.25A

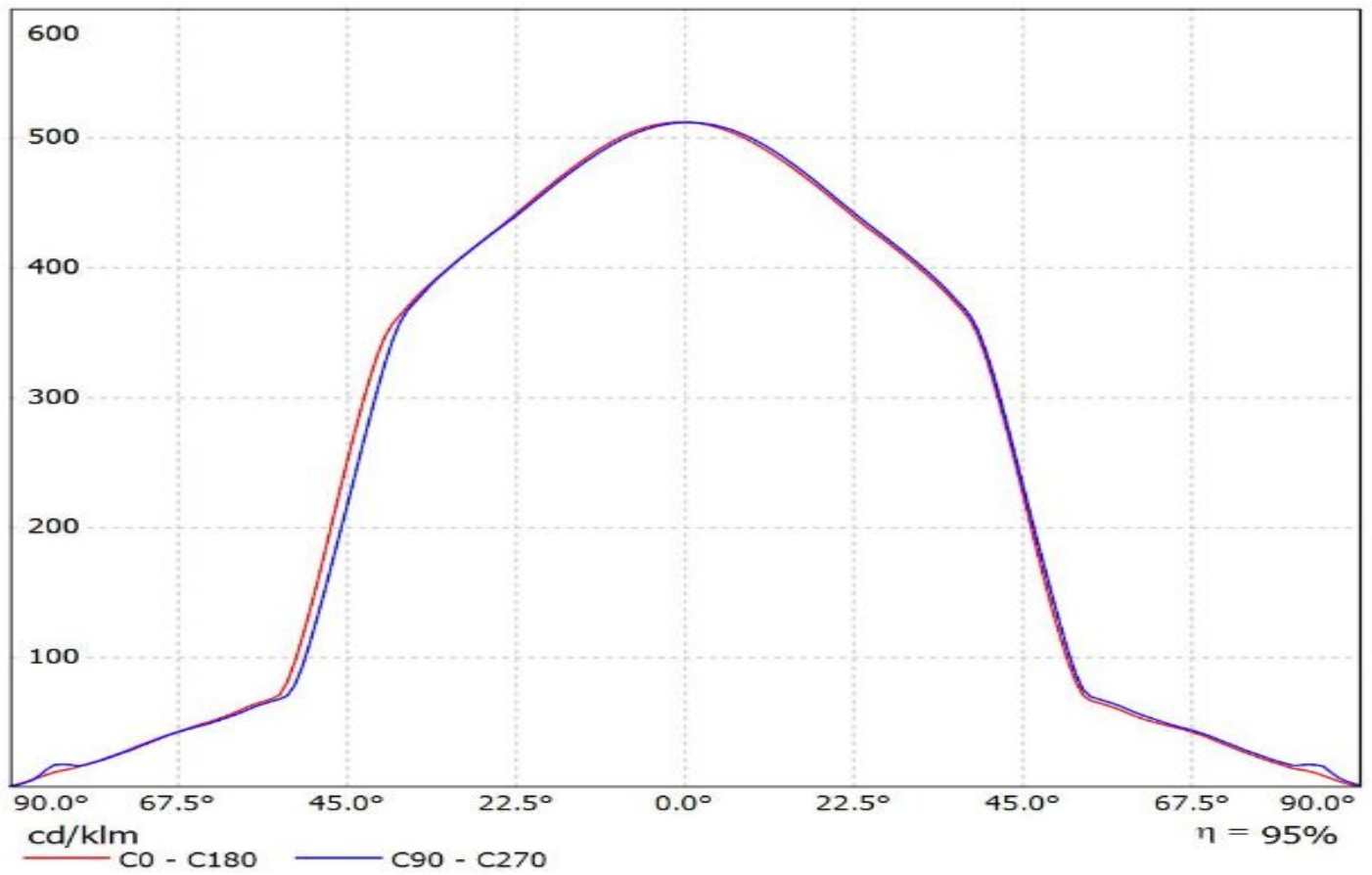


Luminaire: LEDiL Oy F13839_ANGELINA-XW-B_(CLL042) Eff: 94%
Lamps: 1 x Citizen_CLL042_(CLL042-1218A5-303H3-D2)_959.2lm@250mA_P=8.04978W_I=0.2499A

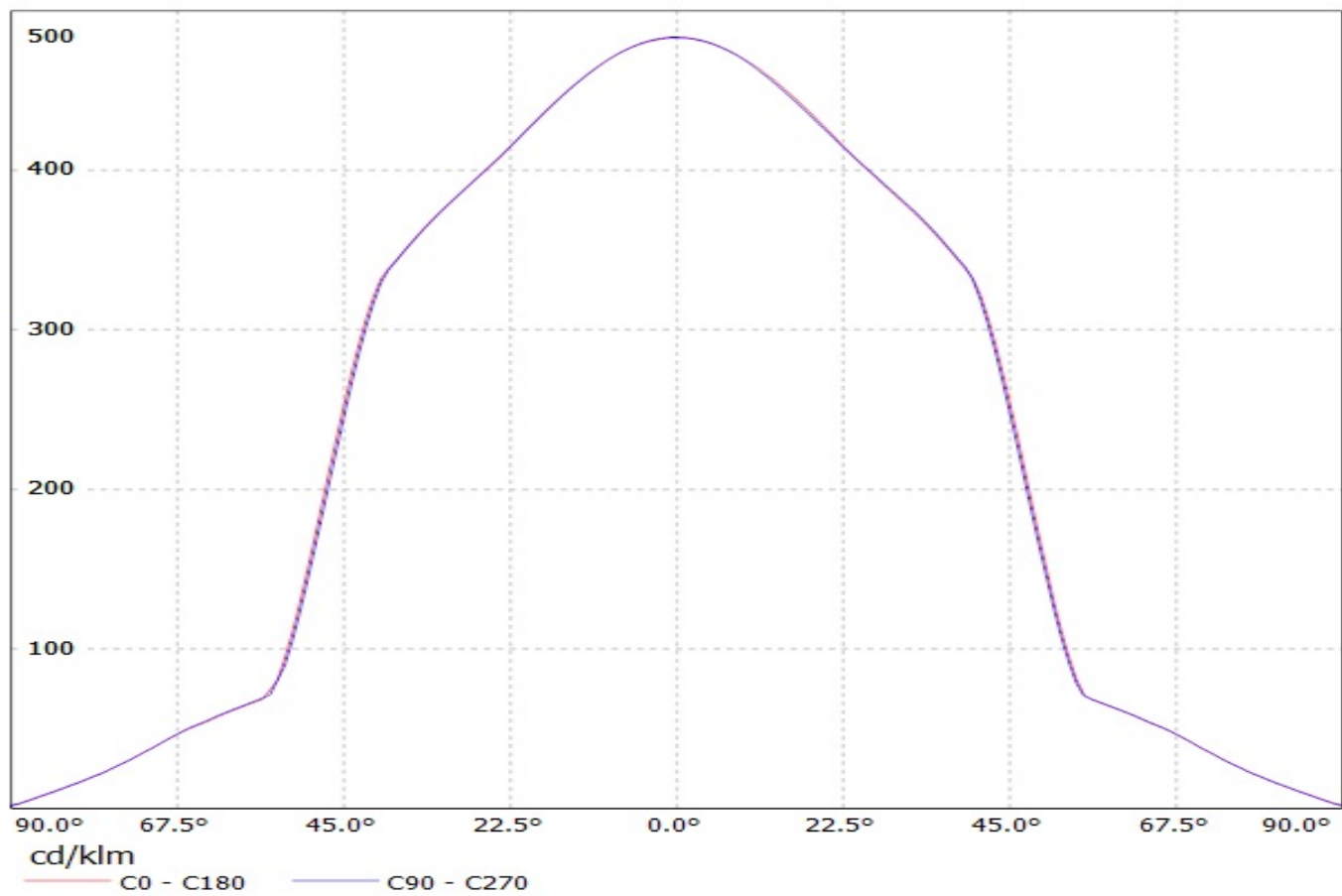


Luminaire: LEDiL Oy FC13982_ANGELINA-RZ-XW-B_(CLU044)_(Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

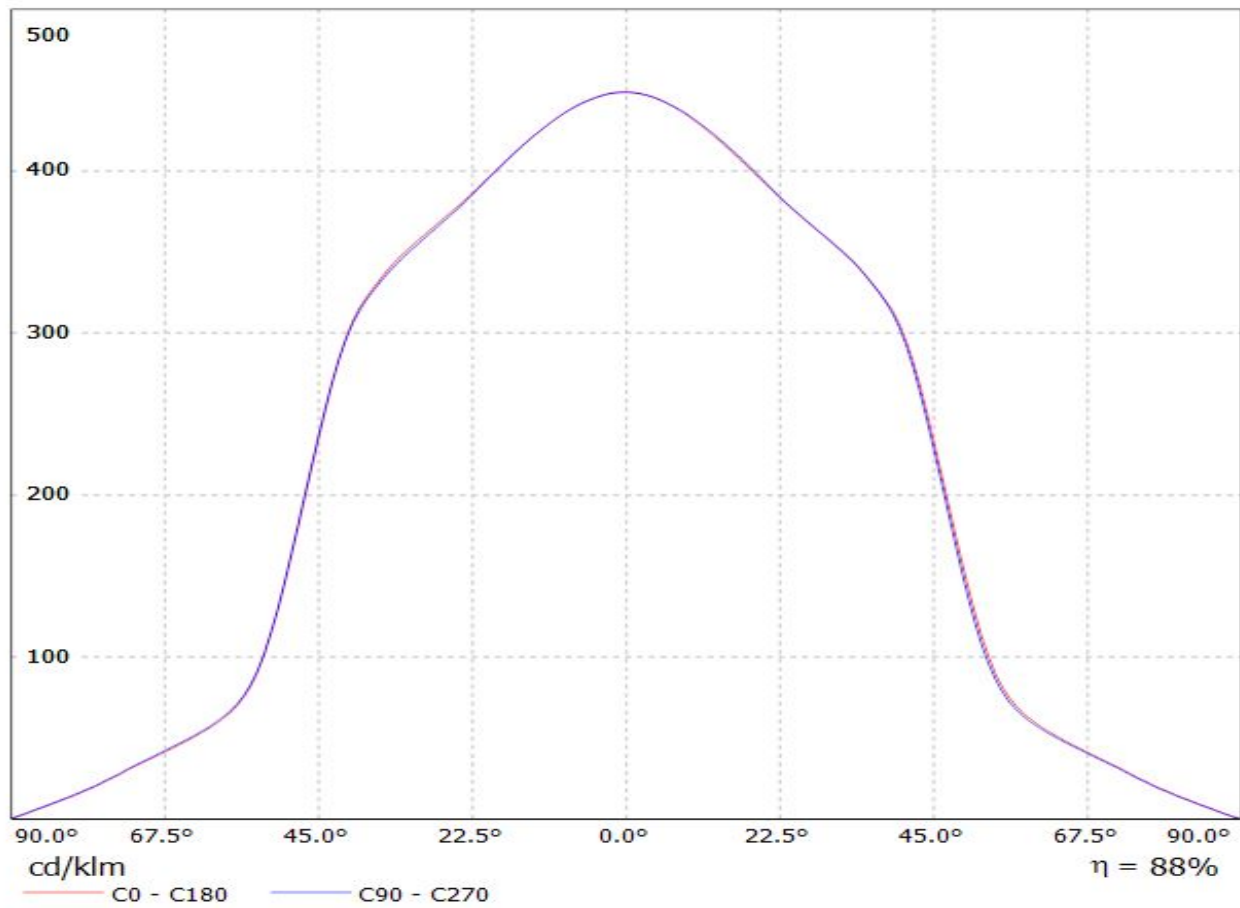

Luminaire: LEDiL Oy F13839_ANGELINA-XW-B_(CLU044)
Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

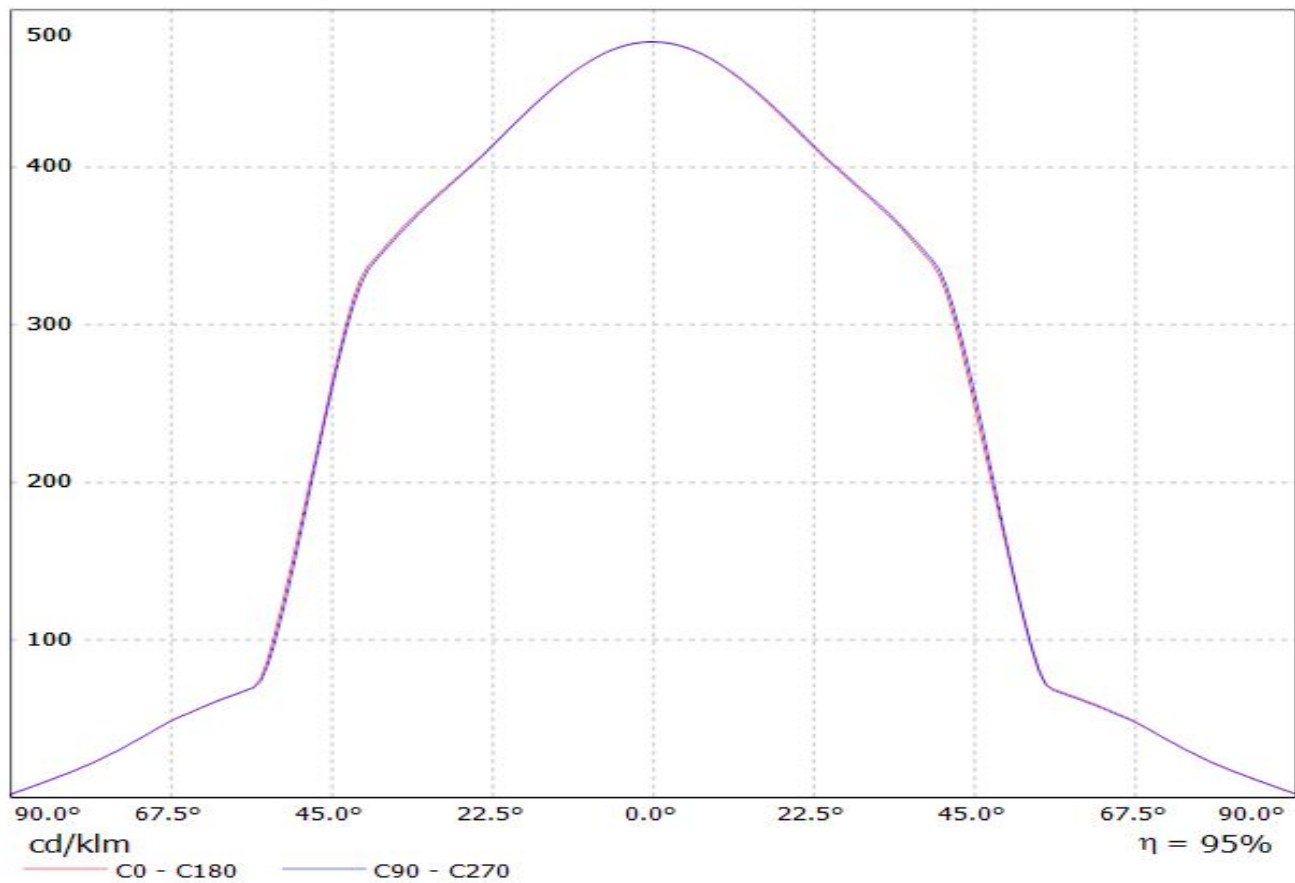


Luminaire: Ledil Oy F13661_ANGELINA-W-B_(CLU048)_(47_319_2030)_SIMULATED
Lamps: 1 x Citizen CLU048 (CLU048-1212C4-303M2K1) + BJB connector 47.319.2030

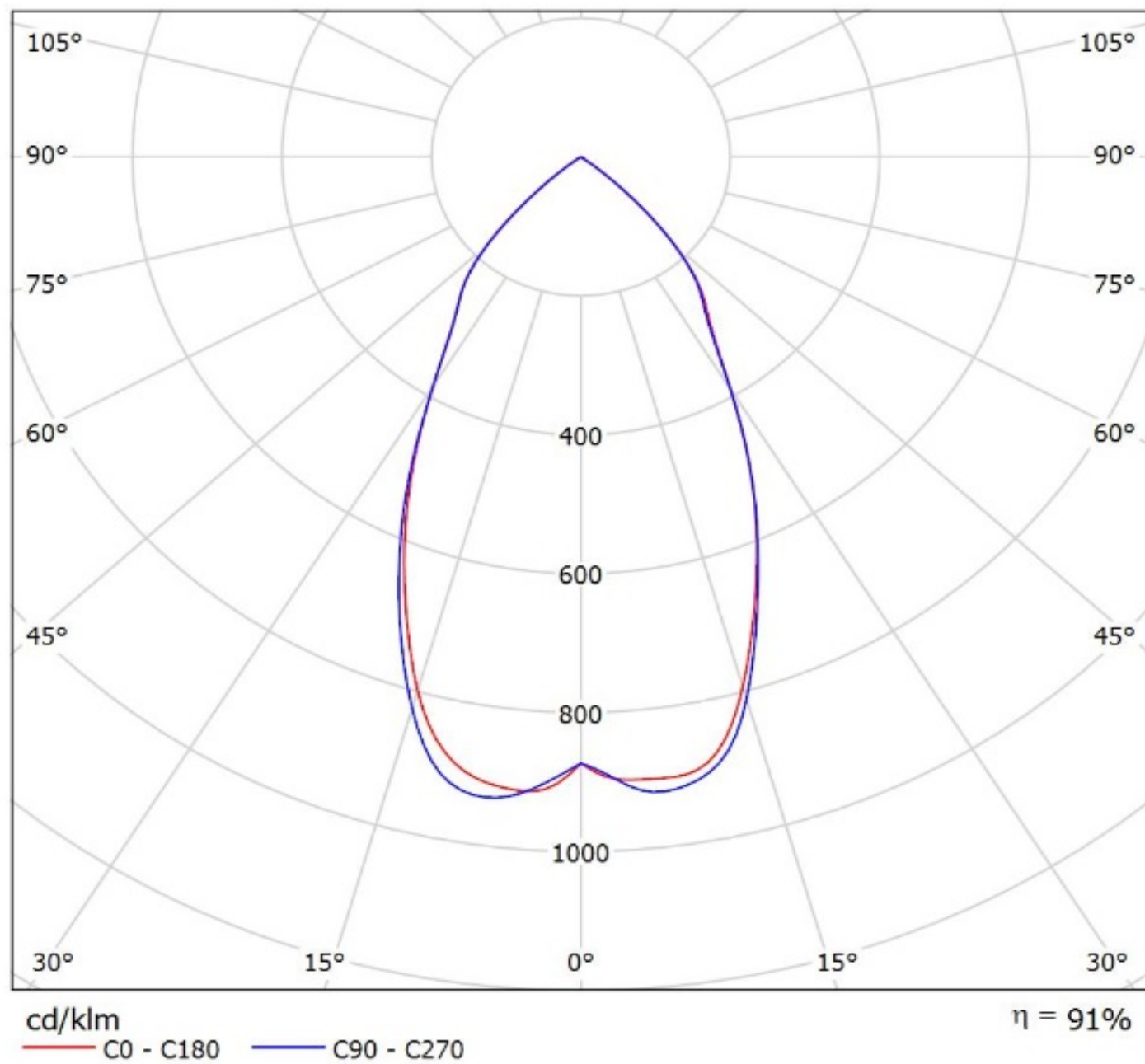


Luminaire: Ledil FCN13691_ANGELINA-S_(CLU044)_(431_Typ_L3)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

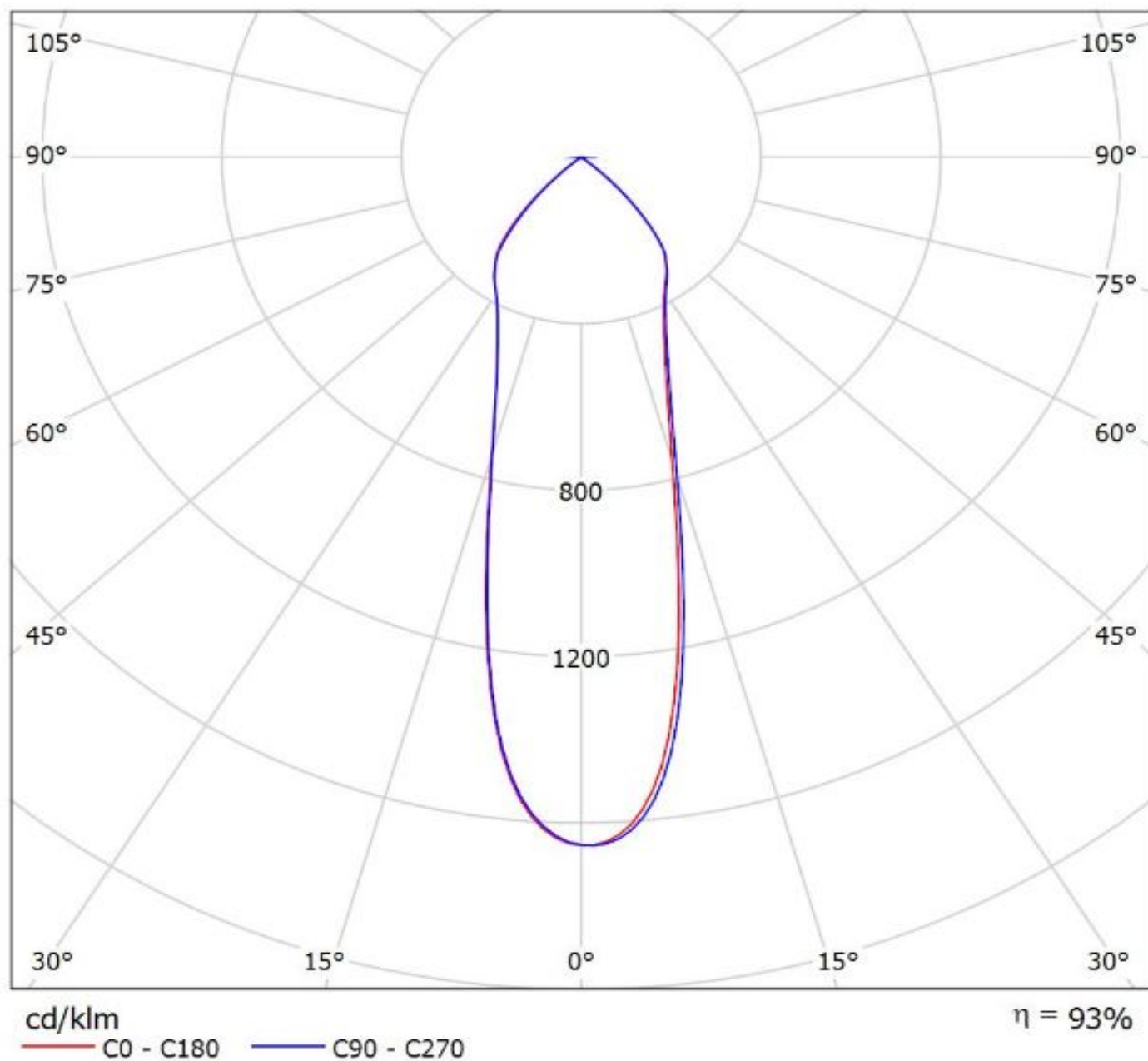


Luminaire: Ledil F13325_ANGELINA-S_(CLU046+IDEAL)
Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

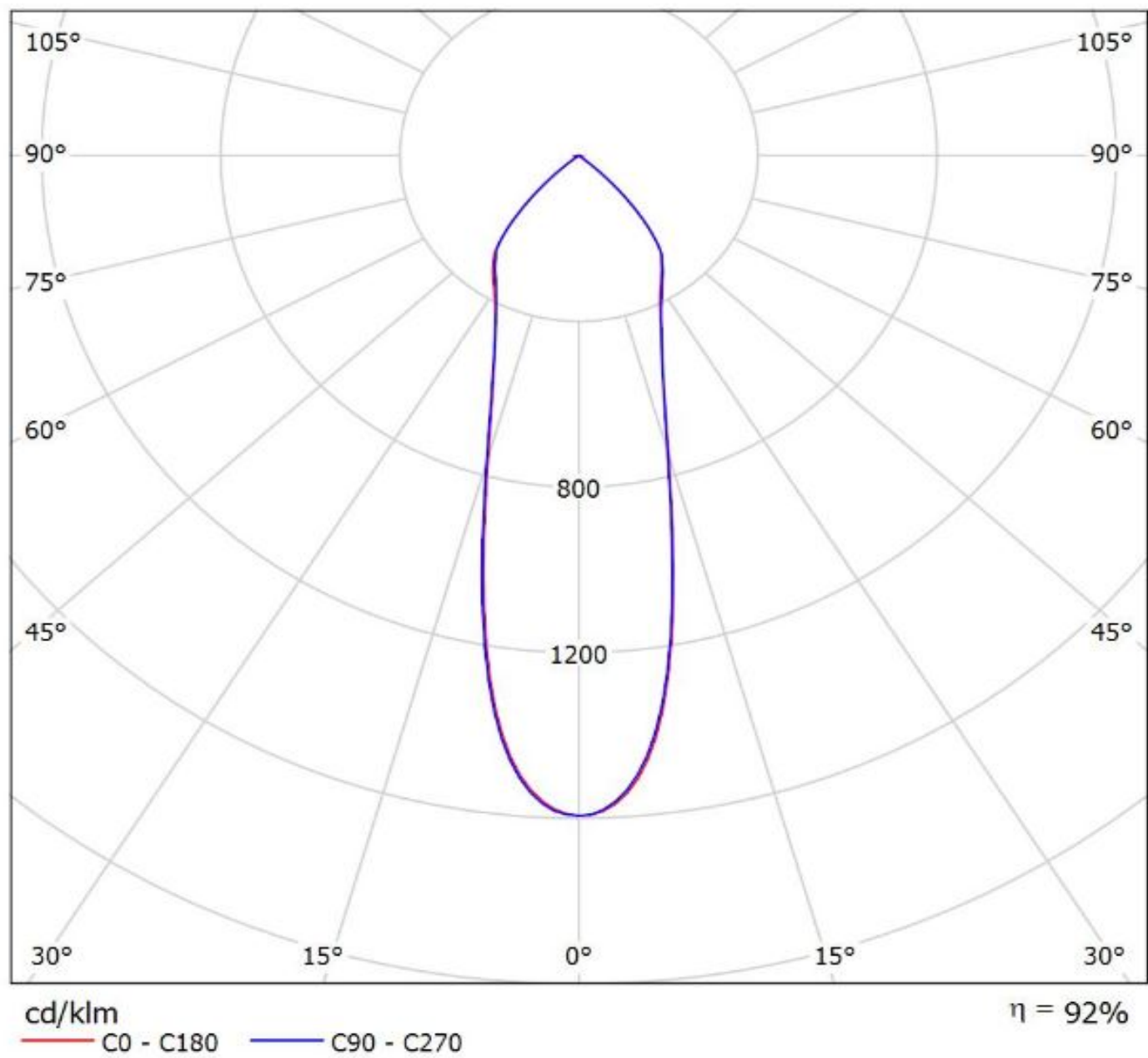


Luminaire: LEDiL Oy F13659_ANGELINA-S-B_(CLU044)


Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

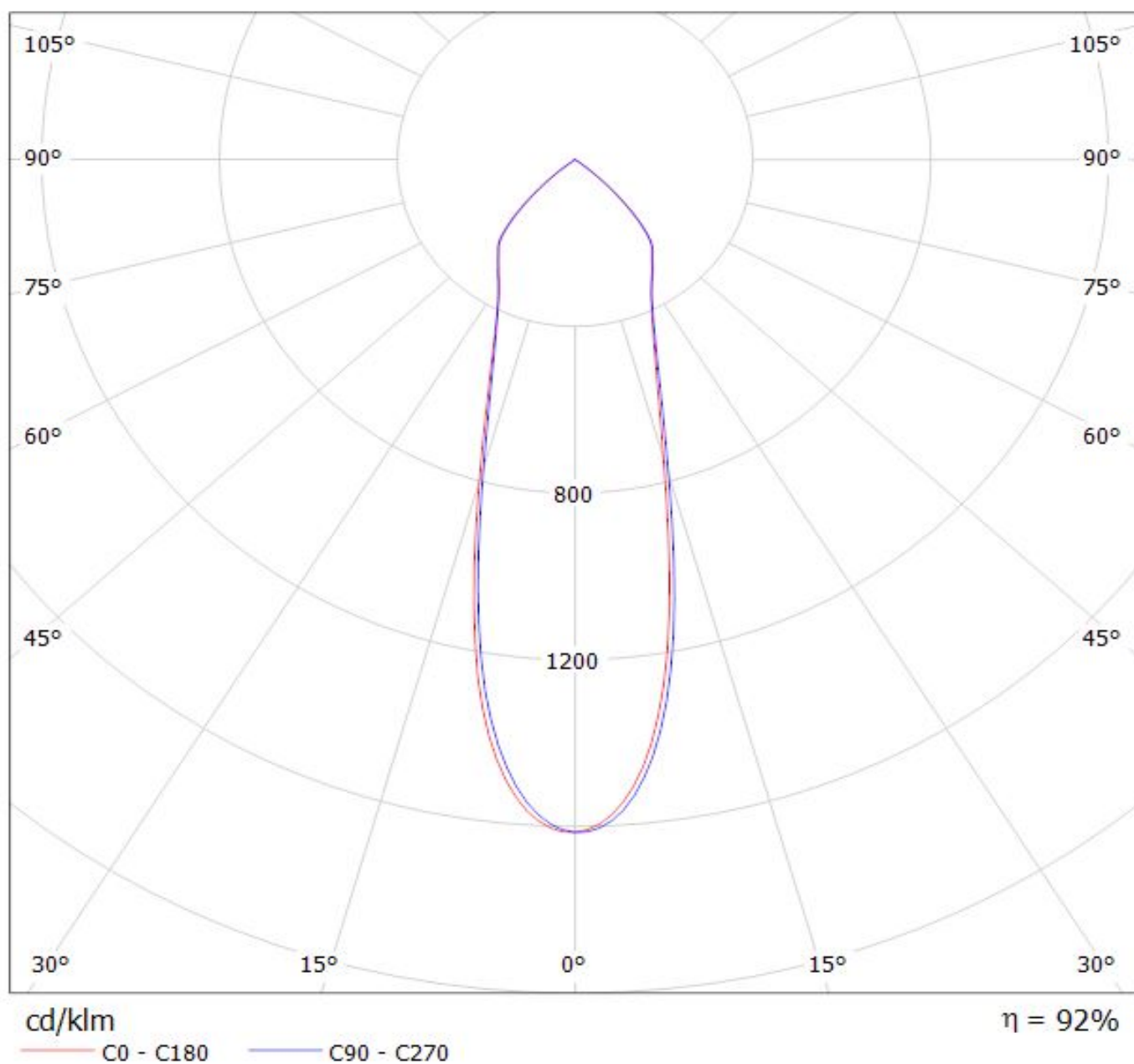


Luminaire: LEDiL Oy FC13977_ANGELINA-RZ-S-B_(CLU044)_+_ (Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

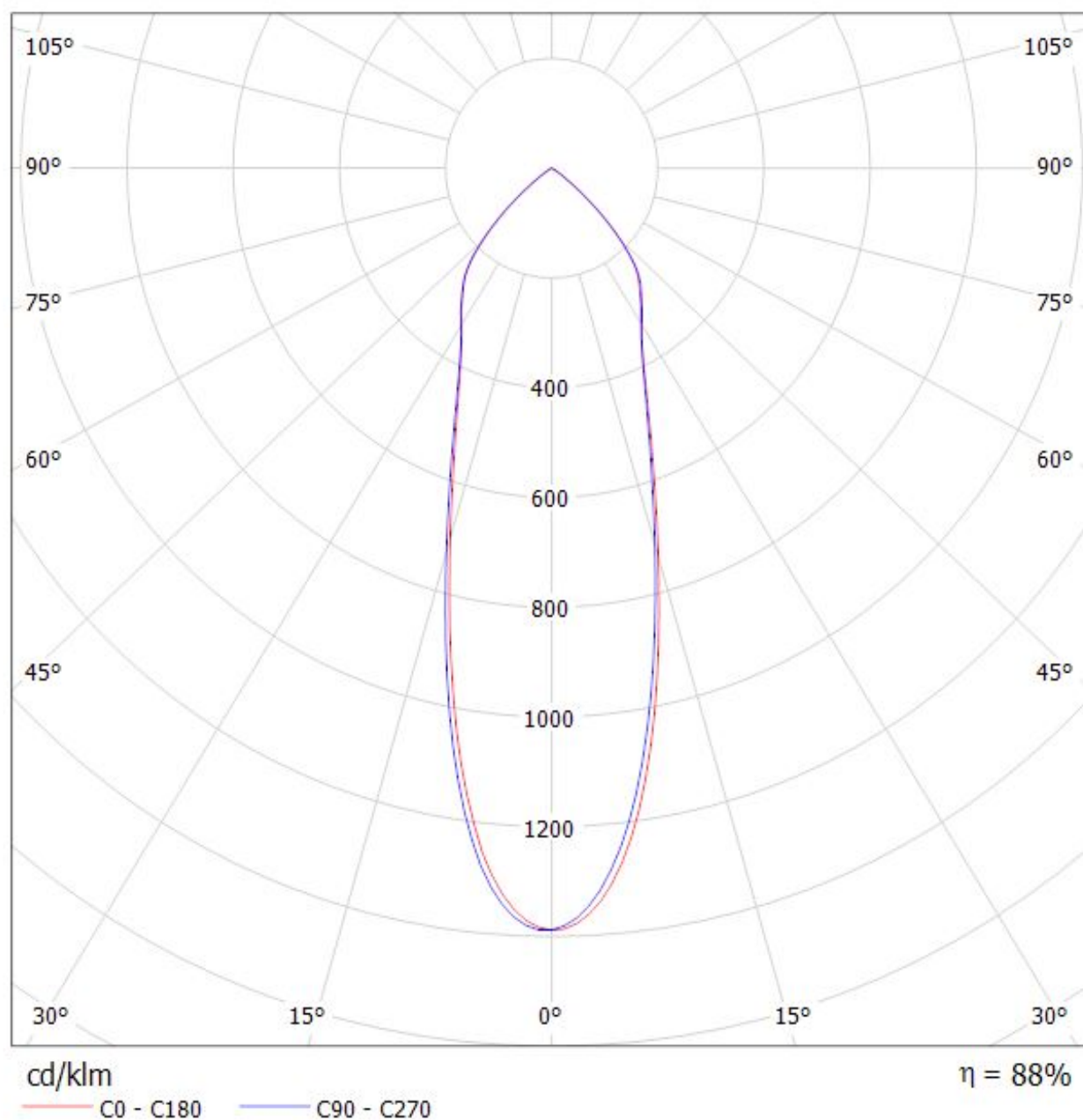

Luminaire: LEDiL Oy F13660_ANGELINA-M-B_(CLU044)
Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

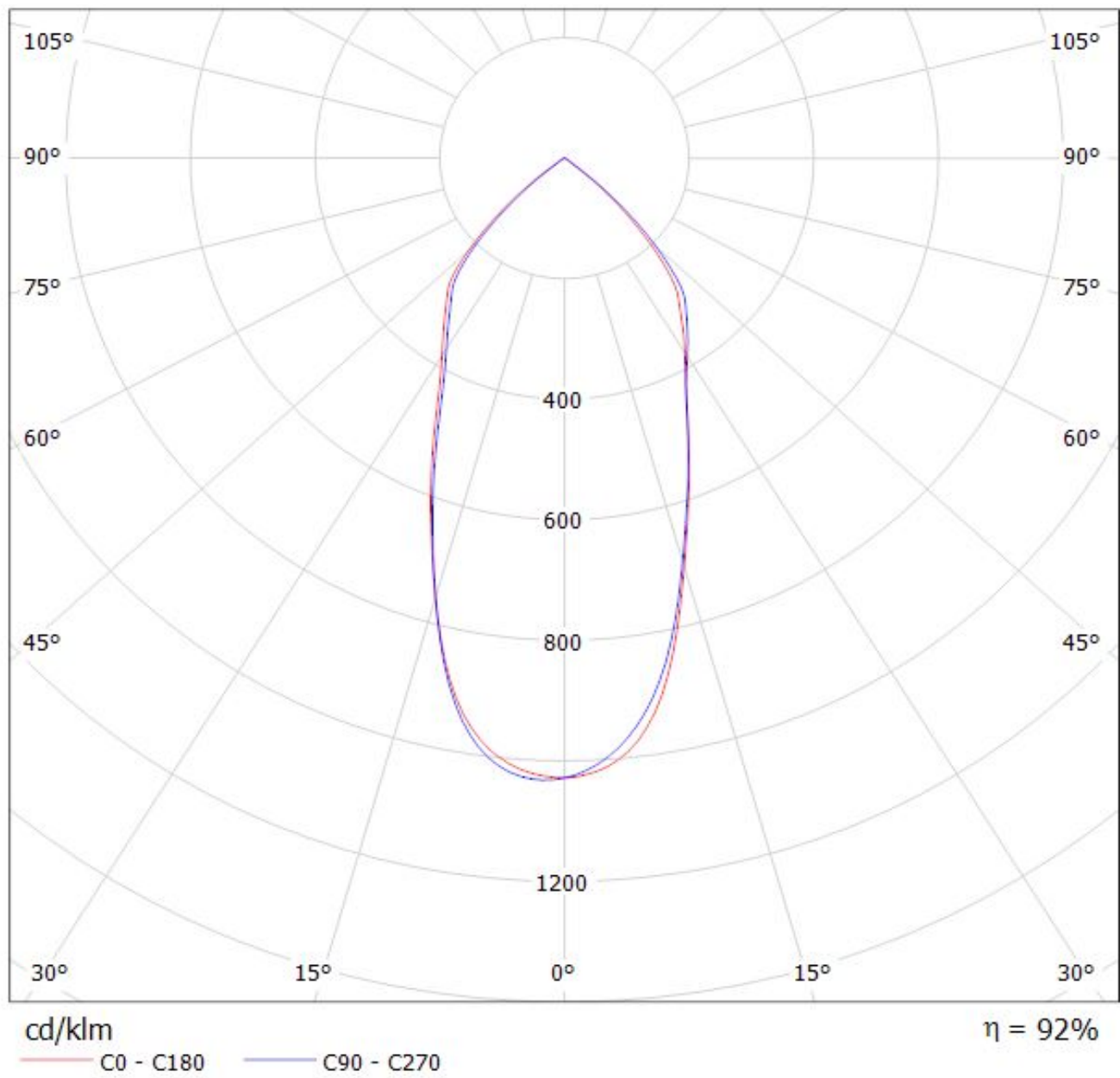


Luminaire: Ledil FCN13692_ANGELINA-M_(CLU044)_(431_Typ_L3)
Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

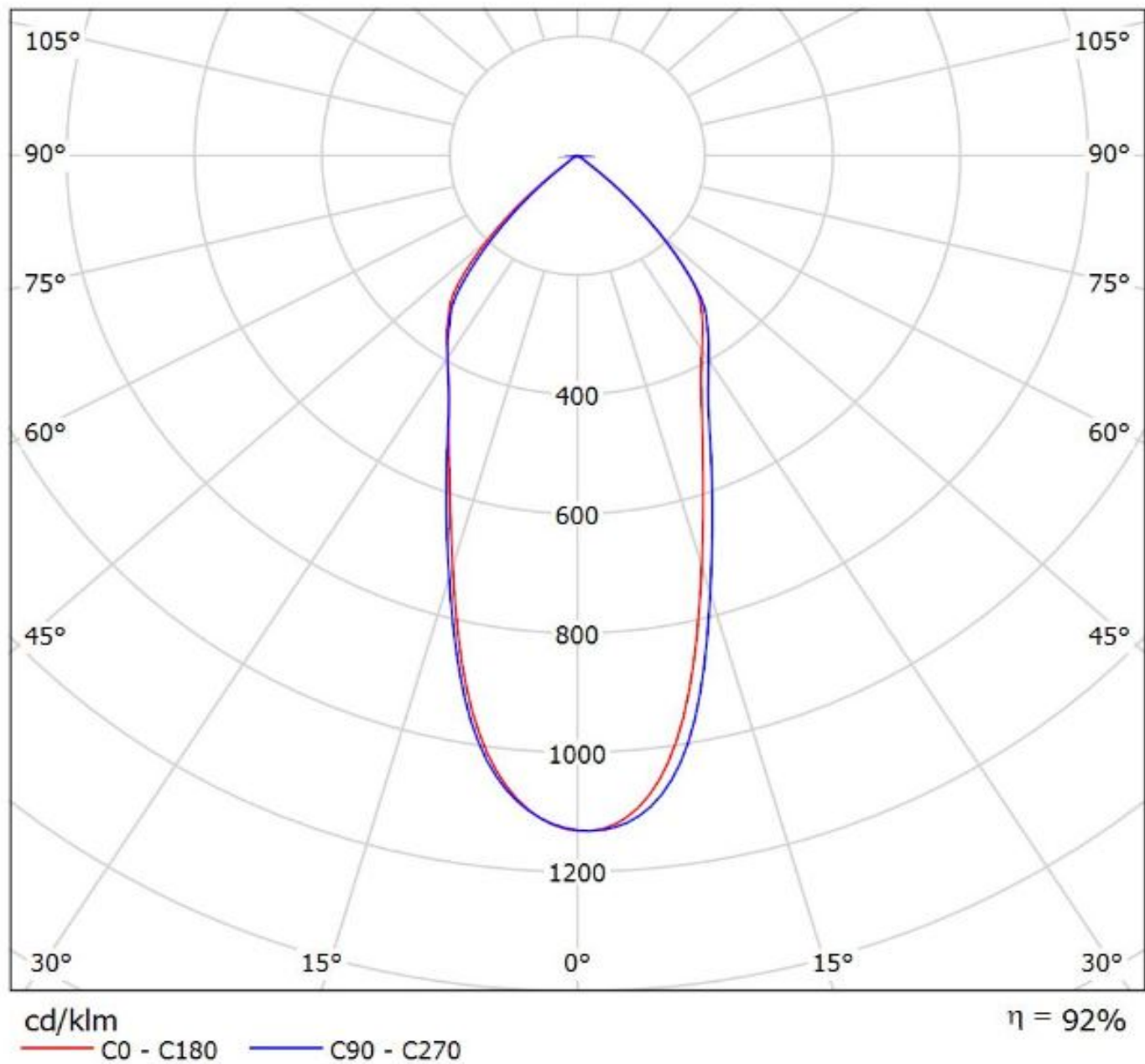


Luminaire: Ledil F13401_ANGELINA-M_(CLU046+IDEAL)

Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

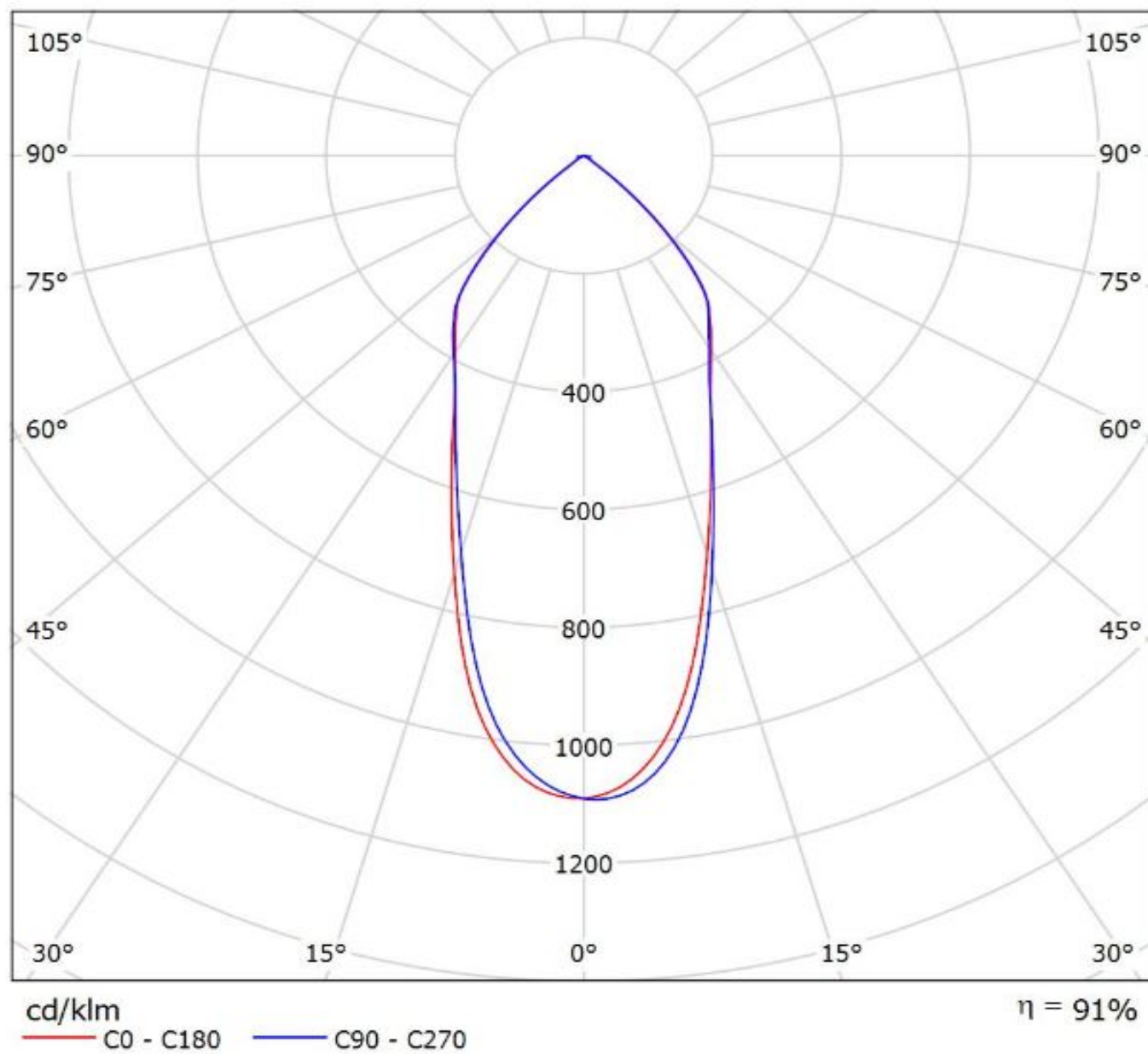


Luminaire: Ledil F13402_ANGELINA-W_(CLU046+IDEAL)
Lamps: 1 x Citizen_CLU046_(-1212C1-303M2G2)_1383.92lm@250mA_CCT=3000K_P=8.122W_I=0.25A

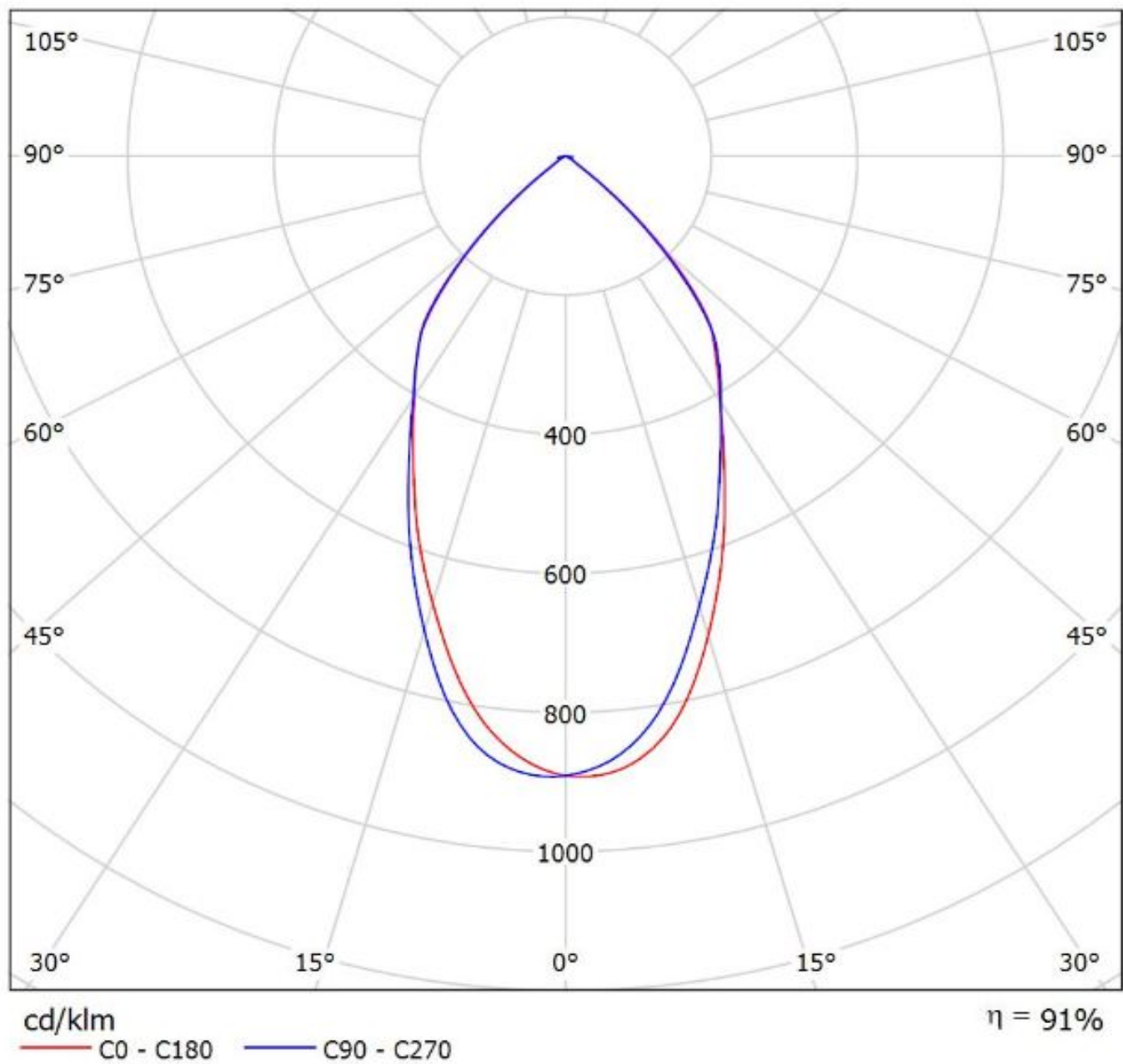


Luminaire: LEDiL Oy FC13978_ANGELINA-RZ-M-B_(CLU044)_+_ (Stucchi_8102-G2)

Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

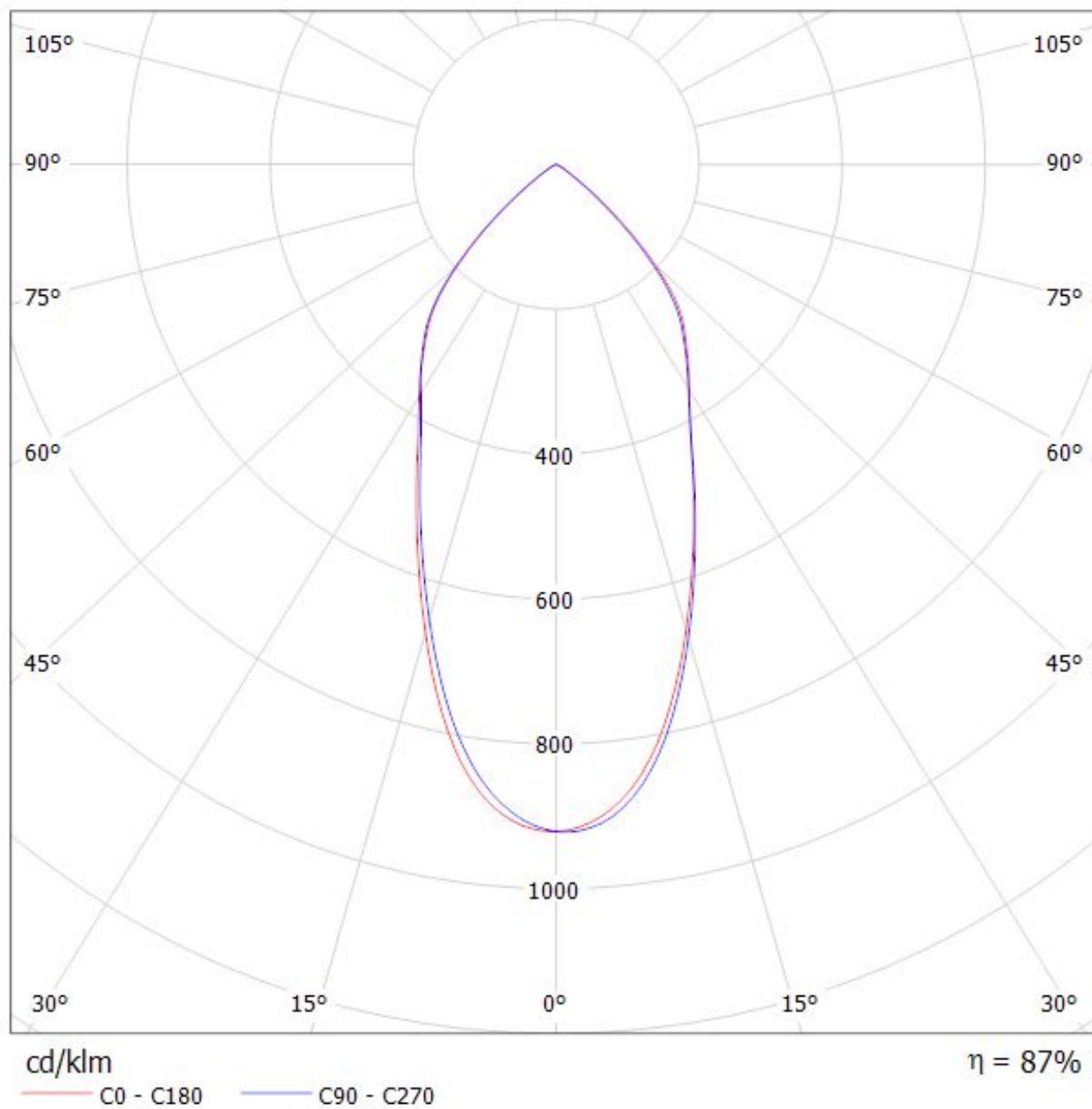


Luminaire: Ledil FCN13693_ANGELINA-W_(CLU044)_(431_Typ_L3)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

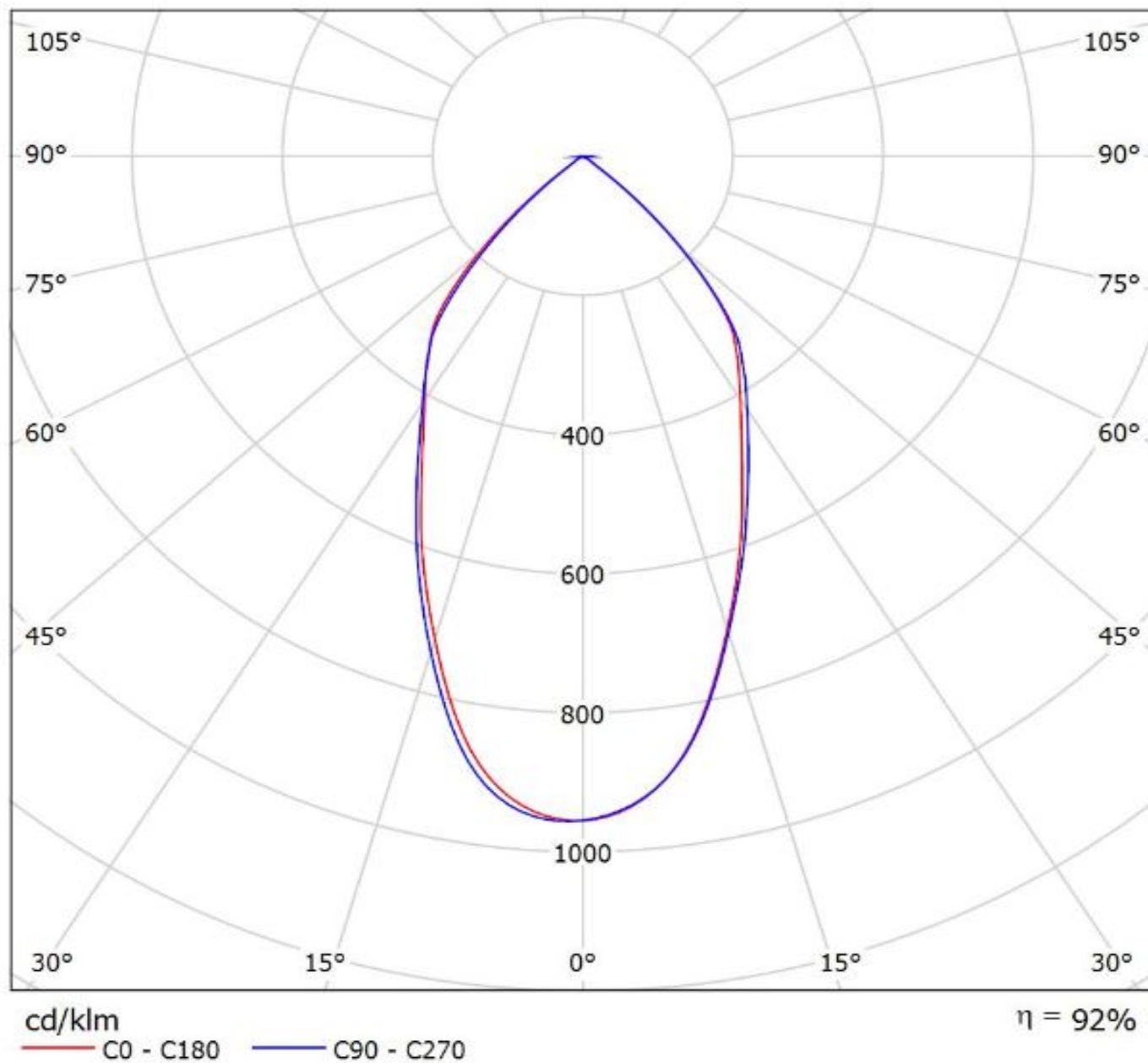


Luminaire: LEDiL Oy F13661_ANGELINA-W-B_(CLU044)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

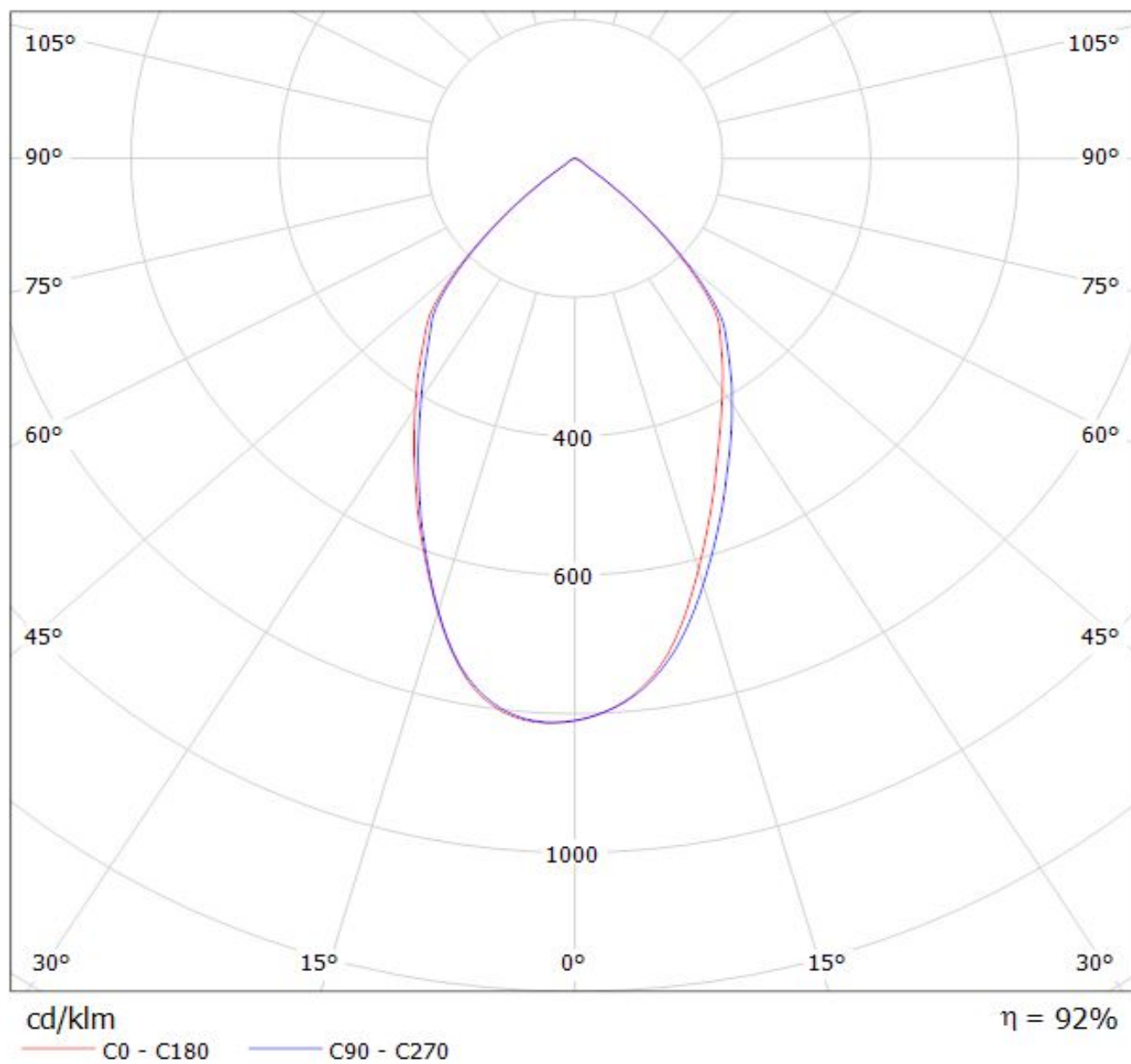


Luminaire: LEDiL Oy FC13979_ANGELINA-RZ-W-B_(CLU044)_+_ (Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

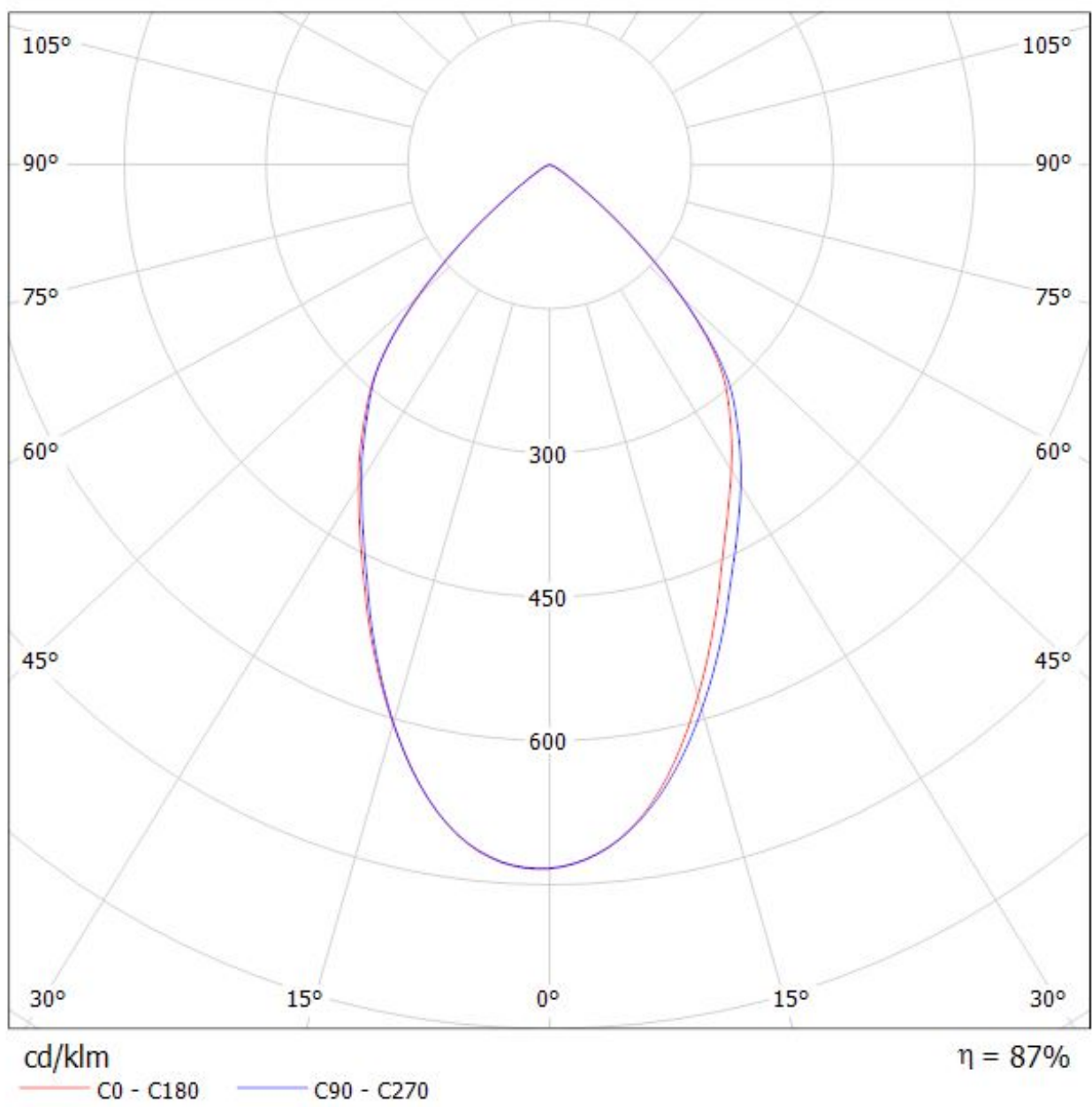


Luminaire: Ledil FCN13912_ANGELINA-XW_(CLU044)_(431_Typ_L3)


Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1272.54lm@250mA_P=8.16W_I=0.25A

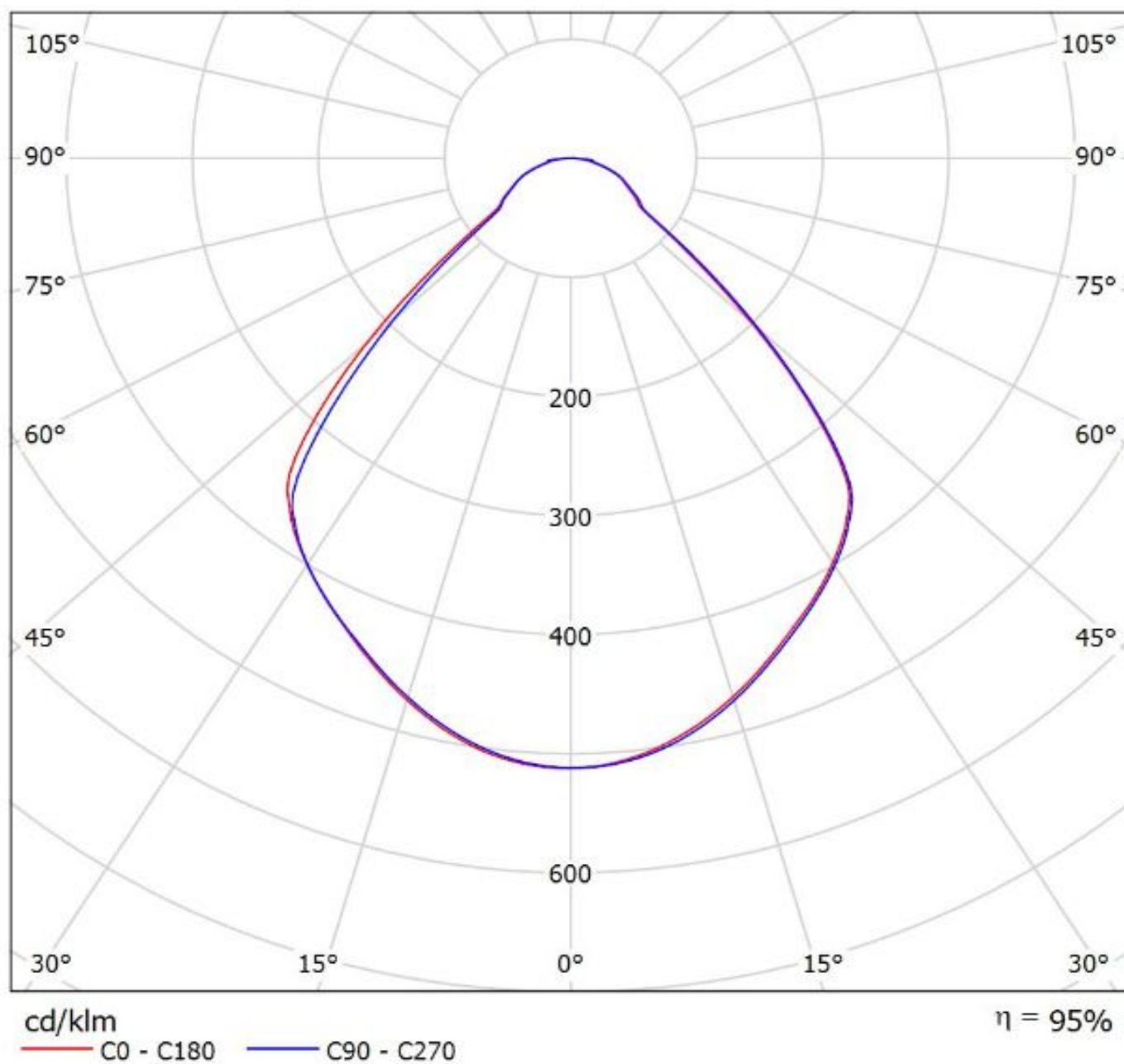

Luminaire: LEDiL Oy F13839_ANGELINA-XW-B_(CLL042) Eff: 94%
Lamps: 1 x Citizen_CLL042_(CLL042-1218A5-303H3-D2)_959.2lm@250mA_P=8.04978W_I=0.2499A

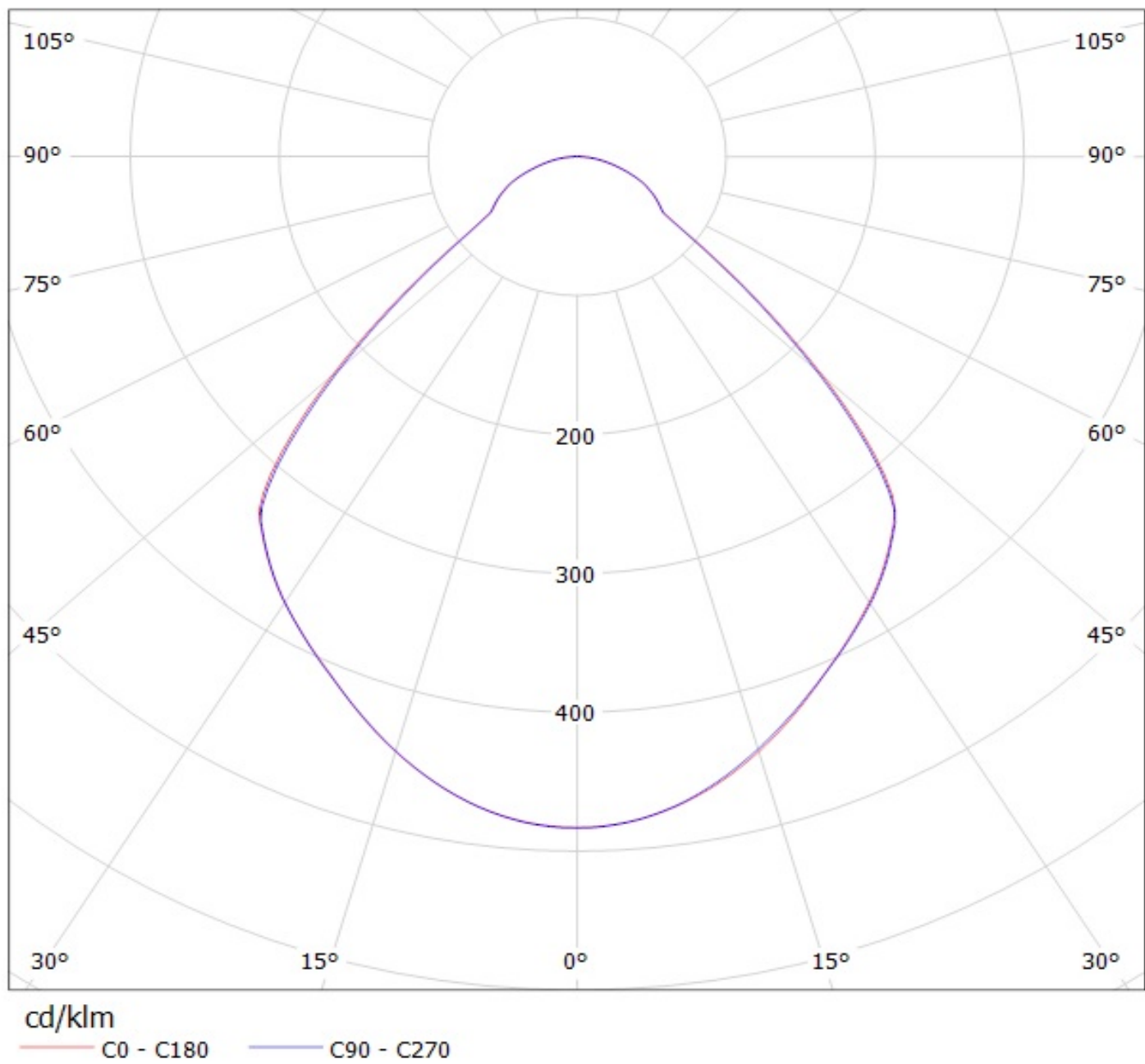

Luminaire: LEDiL Oy FC13982_ANGELINA-RZ-XW-B_(CLU044)_(Stucchi_8102-G2)
Lamps: 1 x Citizen_CLU044_(1212B8-303M1A2)_+_ (Stucchi_8102/G2)_1291.68lm@250mA_P=8.13748W_I=0.250A

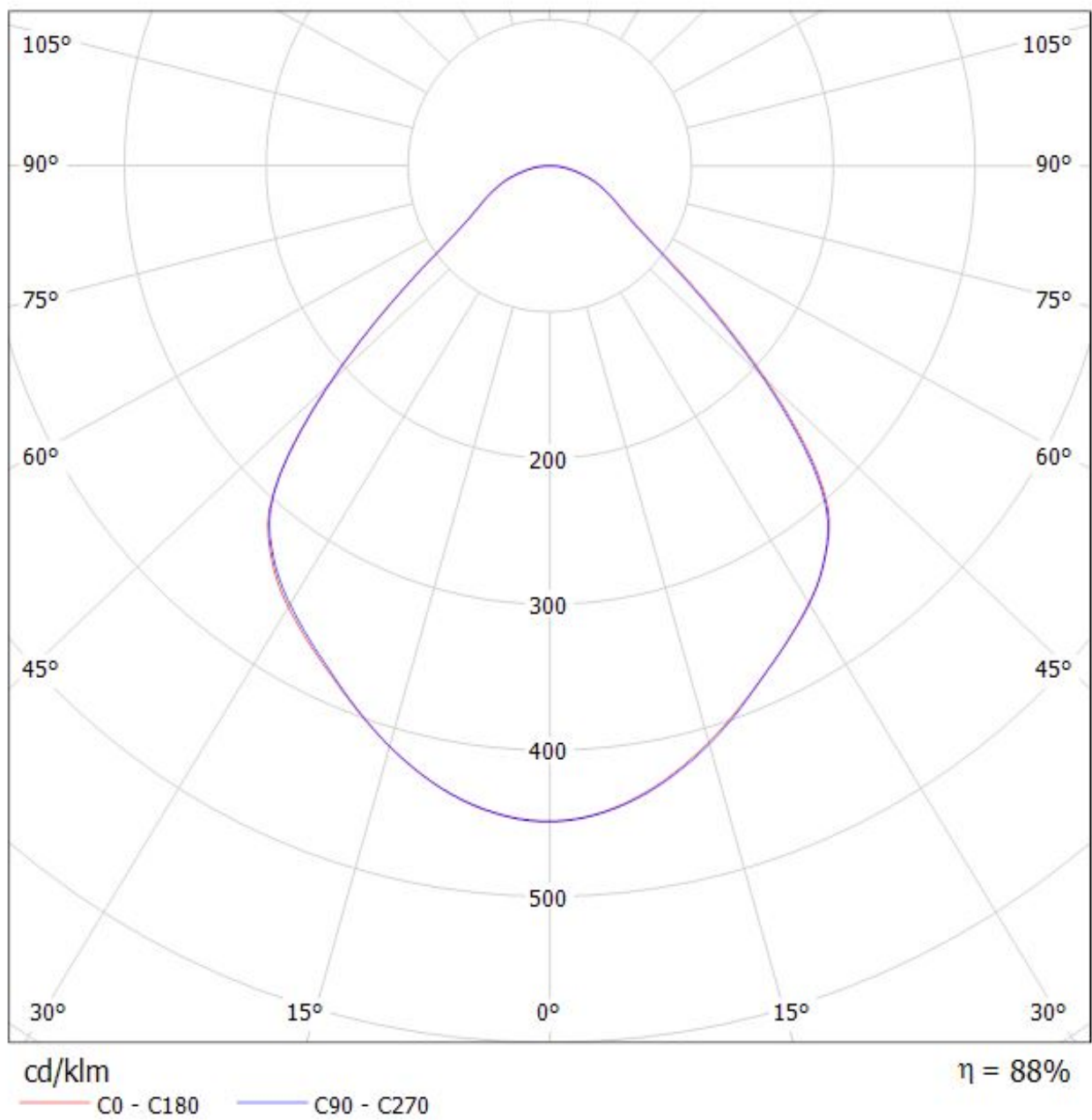

Luminaire: LEDiL Oy F13839_ANGELINA-XW-B_(CLU044)

Lamps: 1 x Citizen_CLU044_(CLU044-1212B8-303M1A2)_1300.9lm@250mA_P=8.14849W_I=249.9mA

