



Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
- Favorite Products List
- Locate Distributor


[Home](#) > [Products Overview](#) > [Search Results](#) >

Current refinements (click to remove) [Search Tips](#) Within Results

Text Search: 'GEE71NC'

Your search criteria matched only one product, shown below

GEE71N-C

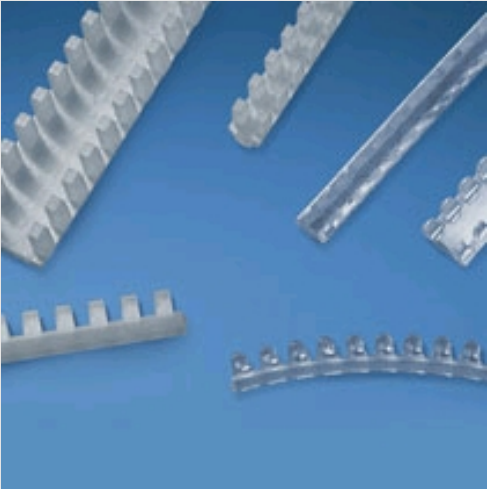

- Protects and insulates wires and cables from chafing against sharp edges
- Highly flexible self extinguishing Nylon material for indoor use up to 149°F (65°C)
 - Use in round panel holes

	Part Number	GEE71NC
	RoHS Compliancy Status	Compliant
	Part Description	Slotted Wall Nylon Grommet Edging for use in cut outs up to 149°F (65°C)
	Material	Nylon 6.6
	Color	Natural
	Height (In.)	.14
	Height (mm)	3.5
	Length (ft.)	100
	Length (m)	30.5
	Width (In.)	.15
	Width (mm)	3.8
	Flammability Rating	UL94 V-2
	Outside Depth (In.)	.140
	Outside Depth (mm)	3.5
	Outside Width (In.)	.150
	Outside Width (mm)	3.8
	Panel Thickness Range (In.)	.063 – .079
	Panel Thickness Range (mm)	1.6 – 2.0
	Pricing Description	Grommet Edging, Slot 100', Nylon, Natural
	Temperature Range	-40°F to 149°F (40°C to 65°C)
	Min. Order UOM	RL
	Min. Order Qty.	1
	BOM Qty. (# of Pkgs.)	0
	Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.