


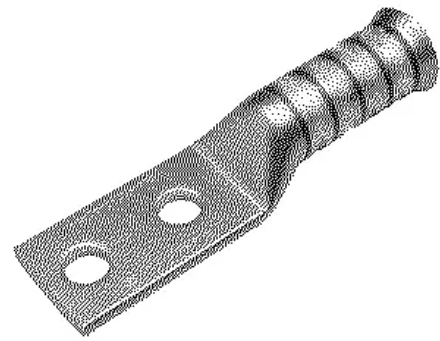

YAV282TC38FXB, Compression Terminal, 4/0 Flex G,H,I,K,M, DLO, 4/0 Cu, 2-Hole, 3/8" Stud, 1" Spacing, Long Barrel

By Burndy

Catalog # [YAV282TC38FXB](#)



4/0 Flex G,H,I,K,M,DLO, 4/0 AWG CU, Two Hole, 3/8 Stud Size, 1 Hole Spacing, Long Barrel, Bell End, Tin Plated, UL/CSA, 90°C, Up to 35kV, Purple Color Code, 15 Die Index.

Features

- Barrel is designed with a "belled" end opening at the wire entry to ensure smooth insertion of highly flexible stranded wire, preventing possible damaging of the wire strands during insertion
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions

Application

Wire Termination

General

Catalog Number	YAV282TC38FXB
Color Code	Purple
Connector Type	LONG BARREL
Die Index	15
EU RoHS Indicator	Yes
Feature - Barrel Style	Belled
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Temperature Rating	194
Trade Name	HYLUG™
Type	Long Barrel, Tin Plated
UPC	781810070574
UPC 14 Digit GTIN	00781810070574

Dimensions

Dimension - B Length fraction	1-3/4 in
Dimension - B Length inch	1.77 in
Dimension - Bolt Hole Size inch	0.39 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - D inch	1.83 in
Dimension - Hole Size fraction	3/8
Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm
Dimension - L Length Overall mm	107 mm
Dimension - Length Overall inch	4.20 in
Dimension - N inch	0.41 in
Dimension - Outside Diameter inch	0.77 in
Dimension - Pad Width inch	1.14 in
Dimension - Strip Length inch	1-7/8
Dimension - Stud Size fraction	3/8
Dimension - Stud Size inch	3/8
Dimension - Thread Size	3/8
Dimension - Z (inch)	0.42 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper DLO Size	4/0 AWG
Conductor - Copper DLO Size Range	4/0 AWG
Conductor - Copper Flex G Size	"4/0 AWG"
Conductor - Copper Flex G Size Range	4/0 AWG
Conductor - Copper Flex H Size	"4/0 AWG"
Conductor - Copper Flex H Size Range	4/0 AWG
Conductor - Copper Flex I Size	"4/0 AWG"

Conductor - Copper Flex I Size Range	4/0 AWG
Conductor - Copper Flex K Size	"4/0 AWG"
Conductor - Copper Flex K Size Range	4/0 AWG
Conductor - Copper Flex M Size	"4/0 AWG"
Conductor - Copper Flex M Size Range	4/0 AWG
Conductor - Copper Str Compact Size	"4/0 AWG"
Conductor - Copper Str Navy Size	200
Conductor - Copper Str Size	"4/0 AWG"
Conductor - Copper Str Size Range	4/0 AWG
Conductor - Material	COPPER
Conductor Size	4/0 AWG
Conductor Type	CODE/FLEX
Wire Size	4/0 AWG

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No

Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	9600

Product Assets

- 3D Models - [YAV282TC38FXB_MODEL-PDF](#)
- 3D Models - [YAV282TC38FXB_MODEL-STEP](#)
- 3D Models - [YAV282TC38FXB_MODEL-IGES](#)
- Catalogs - [BURNDY Master Catalog - Section C - Compression Connections](#)
- Catalogs - [BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- Customer Notices - [Prop 65 Notice](#)
- Installation Manuals - [Copper Flex Long Terminals Tooling and Installation Instructions](#)
- Installation Manuals - [Medium & Large HYDENT Copper & Aluminum Terminal Crimp Instructions with 750 Series 12-Ton Tool](#)
- Interactive Catalog - [BURNDY Full-Line Digital Catalog](#)
- Sales Drawings - [SE..208074-01](#)
- Specifications - [YAV282TC38FXB](#)
- Video - [HYDENT Compression Terminal Overview Video](#)

