

## Han RJ45 module, for patch cables & RJ-I

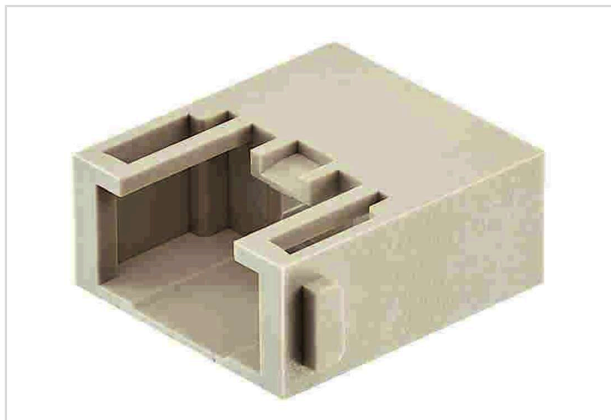


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 4623
Specification	Han RJ45 module, for patch cables & RJ-I
HARTING eCatalogue	<a href="https://harting.com/09140014623">https://harting.com/09140014623</a>

### Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® RJ45 module
Size of the module	Single module
Description of the module	Single module

### Version

Gender	Male
--------	------

### Technical characteristics

Insulation resistance	$>10^{10} \Omega$
Mating cycles	$\geq 500$

### Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	2
Net weight	2 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140019447
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)
ETIM	EC002312
UNSPSC 24.0	39121469