


**Dialight**  
**561-4x01-xxx**

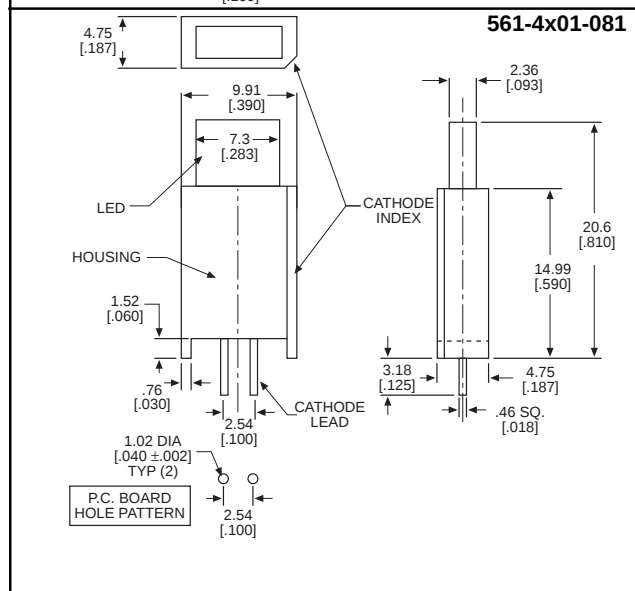

561-4101-xxx  
561-4201-xxx  
561-4301-xxx

Red  
Green  
Yellow

- Available with a variety of LEDs
- Housing material meets UL94 V-0
- Rectangular shaped LED
- Black housing enhances contrast
- High reliability - life measured in years
- Vibration and shock resistant
- Standoffs on housing facilitate PC board cleaning

- For absolute maximum ratings and other electrical/optical data refer to LED data sheet.

Dimensions in mm [inches]

**PART NUMBER ORDERING CODE**

Series      LED Type      Overall Height

**5 6 1 - 4 x 0 1 - x x x**

055 = 14.0 [.550]  
081 = 20.6 [.810]

See LED data sheet for additional information

| Part Number  | Color  | Peak Wavelength nm | I <sub>V</sub> mcd | V <sub>F</sub> Volts | Test Current (mA) | Viewing Angle 2Θ° | LED Data sheet | Page # |
|--------------|--------|--------------------|--------------------|----------------------|-------------------|-------------------|----------------|--------|
| 561-4101-xxx | Red    | 635                | 5                  | 1.9                  | 20                | 100°              | 521-9264       | 5-17   |
| 561-4201-xxx | Green  | 565                | 2.5                | 2.3                  | 20                | 100°              | 521-9266       | 5-17   |
| 561-4301-xxx | Yellow | 583                | 5                  | 2.1                  | 20                | 100°              | 521-9265       | 5-17   |