


TECHNICAL DATA

Product number	0132.0101
Actuator color / printing	
Product family	Toggle switches
Weight	23.300 g
ROHS conform	yes
Distributor	EVG / REPRO
Switching function	ON / OFF switch (DPST)
Material fixed contact	CuZn silver-plated
Number of poles	2 - pole
connections	Solder terminal
Mechanical life endurance	5E4
Rating IEC	2 A 250 V 1E4
Actuators and additional actuators	lever: PA, black
Housing description	base plate: Type 31, black bracket plate: CuZn nickel-plated, with labelling 0 - I threaded socket: CuZn nickel-plated, with knurled nut and hexagonal nut of nickel-plated CuZn
Connection surface	→ bearing connection silver plated → external connection silver plated
Contact material	CuZn silver plated
Contact type	jump contact (roll contact)
Miscellaneous	actuating torque 90.0 Nmm ± 27.0
Type of fastening	central fastening M12 x 0.75
Stock version	•

PRODUCT IMAGE



DRAWINGS

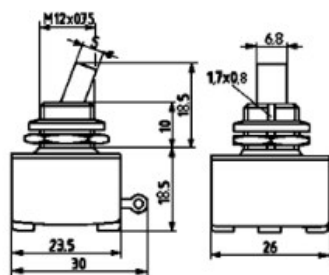

Technical changes reserved. Dimensions are not binding.
Detailed specifications available on request.