

MLK1005S15NJT000



| | |
|----------------------|---|
| Applications | Commercial Grade |
| Feature | <p>No Directivity No Directivity</p> <p>Multilayer Multilayer</p> <p>Non-Mag Core Non-Magnetic Core (Dielectric Ceramic)</p> <p>High Self Resonant Frequency</p> |
| Series Type | MLK |
| Status | <p> EOL announced</p> <p>Recommended Alternate Part No. : MLG1005S15NJT000 (Interchangeability is not guaranteed.)</p> <p>Discontinue Issue Date : May.24, 2021</p> <p>Last Purchase Order Date : Mar.31, 2026</p> <p>Last Shipment Date : Jun.30, 2026</p> |
| Brand | TDK |



| Size | |
|------------------------------|----------------|
| Length(L) | 1.00mm ±0.10mm |
| Width(W) | 0.50mm ±0.10mm |
| Thickness Height | 0.50mm ±0.10mm |
| Recommended Land Pattern (A) | 0.50mm Nom. |
| Recommended Land Pattern (B) | 0.40mm Nom. |
| Recommended Land Pattern (C) | 0.50mm Nom. |

| Electrical Characteristics | |
|--------------------------------|--------------------|
| Inductance | 15nH ±5% at 100MHz |
| Rated Current | 300mA |
| DC Resistance [Typ.] | 330mΩ |
| DC Resistance [Max.] | 500mΩ |
| Self Resonant Frequency [Min.] | 4GHz |
| Self Resonant Frequency [Typ.] | 4.8GHz |
| Q [Min.] | 7 at 100MHz |
| Q [Typ.] | 9 at 100MHz |

| Other | |
|---|--|
| Operating Temp. Range (Including Self-Temp. Rise) | -55 to 125°C |
| Soldering Method | Reflow Iron Soldering |
| AEC-Q200 | NO |
| Packing | Punched (Paper)Taping [180mm Reel, Tape width 8mm] |

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

MLK1005S15NJT000







| | |
|------------------|----------|
| Package Quantity | 10000pcs |
| Weight | 0.001g |

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

MLK1005S15NJT000



Characteristic Graphs(This is reference data, and does not guarantee the products characteristics.)

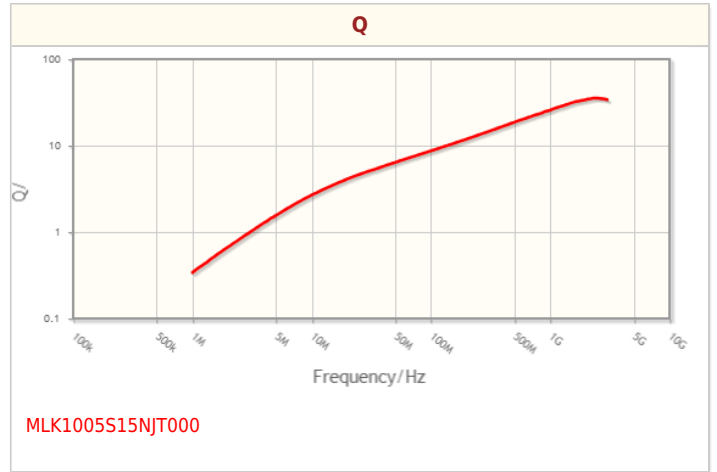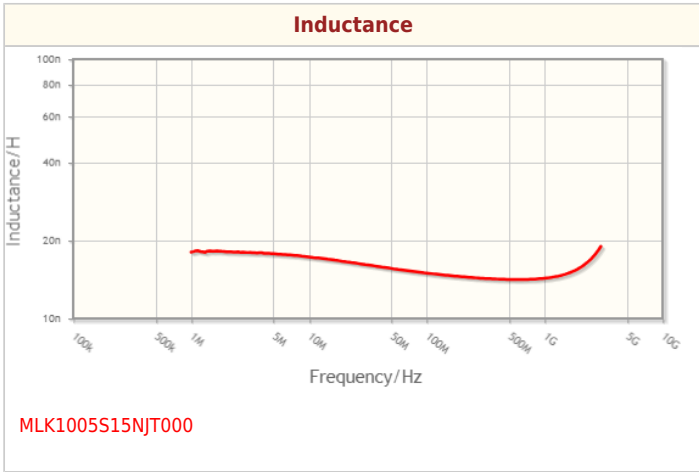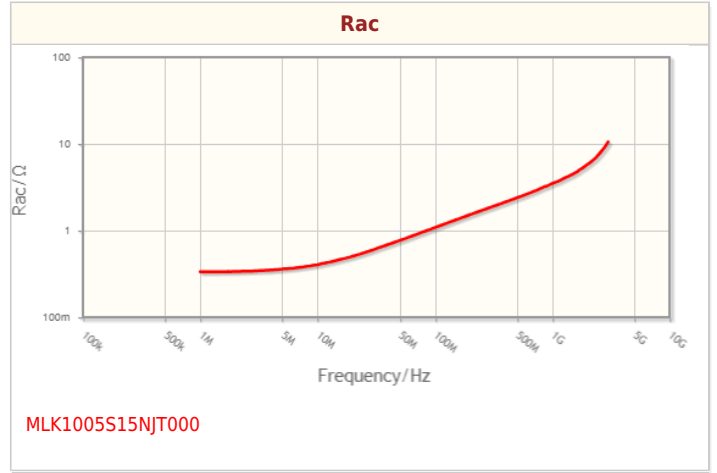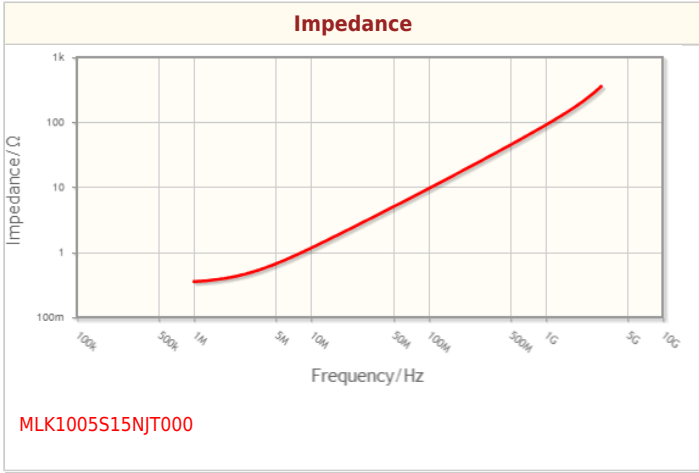

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

MLK1005S15NJT000



Associated Images

