


Inductor

TCK-133





Order Code	TCK-133
Inductance	68 μ H $\pm$ 20% (at 100 kHz / 1 V)
Impedance (DCR)	1117 m Ω max.
Rated Current	0.37 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-133



Impedance Curve

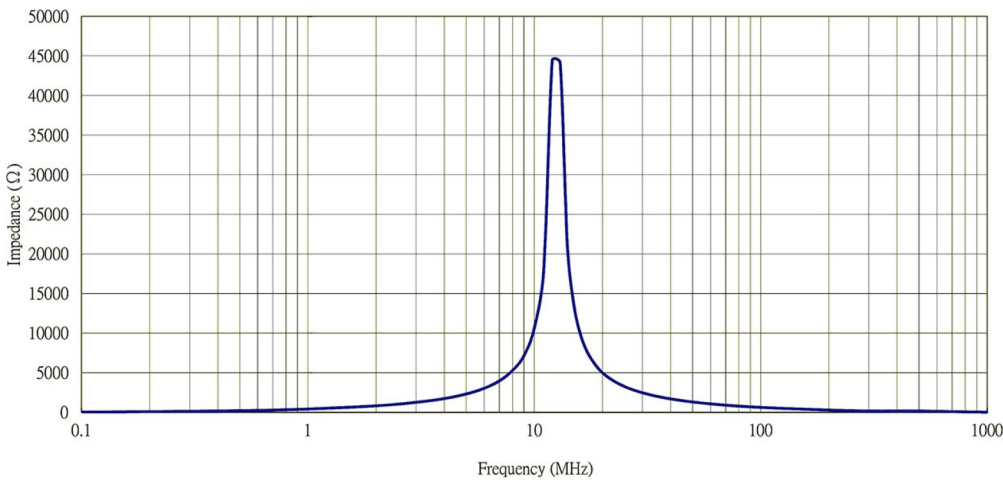

Outline Dimensions

 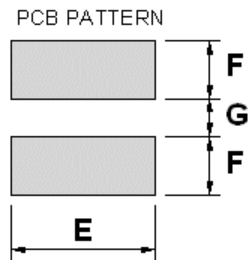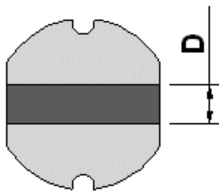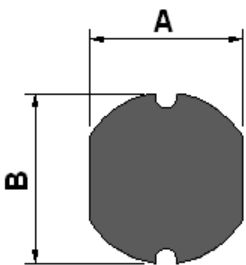

Dimensions [mm]	
A	4.0 $\pm$ 0.5
B	4.5 $\pm$ 0.5
C	3.2 $\pm$ 0.5
D	1.2 typ.
E	4.5
F	1.75
G	1.5

All specifications valid at +25°C, unless otherwise stated.