




PRODUCT NUMBER: 2301-2-00-44-00-00-07-0

2301-X-00-XX-00-00-07-0

Swage mount in .067 hole

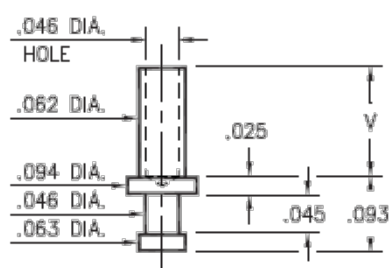

Basic Part Number	Board Thickness	Length V
2XXX-1	.031	.053
2XXX-2	.062	.084
2XXX-3	.094	.115
2XXX-4	.125	.147

DESCRIPTION

Turret Terminal Pin

Current Rating:

Application Specific

Operating Temperature Range:

-55/+125° C (discontinuous)

Mounting Feature:

Swage Mount

Tail Type: Turret

Mounting Hole: .067" (1,702mm)

Tail Diameter: .063" (1,600mm)

Packaging: 00 - Packaged in Bulk

Shell Plating

300 μ" Silver over Copper

Contact Plating

ROHS

RoHS-2
2011/65/EU

ADDITIONAL NOTES & SPECIFICATIONS

In the interest of improved design, quality and performance, Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

© 2020 Mill-Max Mfg. Corp.
190 Pine Hollow Rd , Oyster Bay, NY 11771, USA
Phone: 516.922.6000