


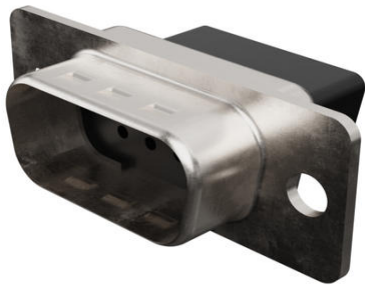

Part Number : [1727040009](#)
Product Description : FCT Standard-Density D-Sub Crimp Housing, Male, Shell with Dimples, 9 Circuits, Black Front and Rear Insulator
Series Number : 172704
Status : Active
Product Category : D-Sub Connectors
Engineering Part Number : FL09P7-K120



Documents and Resources

Drawings
[1727040009 sd.pdf](#)
[STEP AP242](#)
[SOLIDWORKS](#)
[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains 1,1'-(Ethane-1,2-diyl)bis[pentabromobenzene] per D(2025)6375-DC (05 Nov 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	D-Sub Connectors
Series	172704
Description	FCT Standard-Density D-Sub Crimp Housing, Male, Shell with Dimples, 9 Circuits, Black Front and Rear Insulator
IP Rating	IP20
Magnetic	Yes
Product Name	FCT Products
Type	Standard Density
UPC	889056019101

Electrical

Shielded	Yes
----------	-----

Physical

Circuits (Loaded)	0
Circuits (maximum)	9
Color - Resin	Black
Gender	Male
Material - Resin	PBT
Material - Shell	Steel
Net Weight	4.600/g

Number of Rows	2
Orientation	Straight
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
PCB Locator	No
PCB Retention	No
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	No
Ports	1
Shell Size	1
Temperature Range - Operating	-55° to +125°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20

Mates With / Use With

Mates with Part(s)

Description	Part Number
FCT Standard-Density D-Sub Crimp Housing, Female, Shell without Dimples, 9 Circuits, Black Front and Rear Insulator	<u>1727040010</u>

Use with Part(s)

Description	Part Number
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with Rubber Bushing and #4-40 Locking Screws	<u>1727040096</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, 45° Angle	<u>1727040095</u>

Cable Outlet, Large Inner Chamber, with Rubber Bushing and #4-40 Locking Screws	
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with Rubber Bushing and M3 Hex Knurled Thumb Screws	<u>1731110299</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, 45° Angle Cable Outlet, Large Inner Chamber, with Rubber Bushing and M3 Locking Screws	<u>1731110183</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with Rubber Bushing and #4-40 Knurled Thumb Screws	<u>1731110081</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, with Rubber Bushing	<u>1731110086</u>
FCT Plastic Backshell for D-Sub Connector, Black, Shell Size 1, Straight Cable Outlet, IP67 Waterproof, with #4-40 Locking Screws, Individual Packing	<u>1727040105</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet	<u>1731110255</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Flat Body, with #4-40 Locking Screws, Individual Packing	<u>1727040111</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with Rubber Bushing	<u>1731110303</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, 70° Angle Cable Outlet, Large	<u>1731110244</u>

Inner Chamber, with #4-40 Locking Screws	
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with #4-40 Locking Screws	<u>1731110235</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, 45° Angle Cable Outlet, Large Inner Chamber, with #4-40 Locking Screws, Hood Snapped Together	<u>1731110670</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with #4-40 Knurled Thumb Screws, Individually Packed	<u>1731110132</u>
FCT Plastic Backshell for D-Sub Connector, Black, Shell Size 1, Straight Cable Outlet	<u>1731110204</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, 40° Angle Cable Outlet, with Extended Inner Chamber	<u>1731110601</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Individually Packed	<u>1727040110</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, 70° Angle Cable Outlet, Large Inner Chamber, with #4-40 Locking Screws, Individually Packed	<u>1727040109</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Large Inner Chamber, with #4-40 Locking Screws, Individually Packed	<u>1727040112</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Straight Cable Outlet, with Rubber	<u>1727040182</u>

Bushing and #4-40 Knurled Thumb Screws	
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, IP67 Waterproof, with #4-40 Locking Screws, Individual Packing	<u>1727040192</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, Flat Body, with #4-40 Locking Screws	<u>1731110221</u>
FCT Metal Backshell for D-Sub Connector, Shell Size 1, Dual 65° Angle Cable Outlets, with #4-40 Locking Screws	<u>1731110095</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, Straight Cable Outlet, with #4-40 Knurled Thumb Screws	<u>1731110256</u>
FCT Plastic Backshell for D-Sub Connector, Shielded, Shell Size 1, 40° Angle Cable Outlet	<u>1731110168</u>
FCT Plastic Backshell for D-Sub Connector, Black, Shell Size 1, Straight Cable Outlet, Individually Packed	<u>1731110019</u>
FCT Machined Contact, Female, Crimp, 1.30µm Gold Plating, 24-20 AWG, 500 Pieces	<u>1731120210</u>
FCT Machined Contact, Female, Crimp, 1.30µm Gold Plating, 24-20 AWG, 5000 Pieces	<u>1731120727</u>
FCT Machined Contact, Female, Crimp, 1.30µm Gold Plating, 28-26 AWG, 500 Pieces	<u>1731120213</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 24-20 AWG, 5000 Pieces	<u>1731120731</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 24-20 AWG, 500 Pieces	<u>1731120214</u>
FCT Machined Contact, Female,	<u>1731120729</u>

Crimp, 1.30µm Gold Plating, 28-26 AWG, 5000 Pieces	
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, 22-18 AWG, 5000 Pieces	<u>1731121031</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, 22-18 AWG, 500 Pieces	<u>1731120211</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 22-18 AWG, 5000 Pieces	<u>1731121034</u>
FCT Stamped Contact, Female, Crimp, 0.80µm Gold Mating Plating, Split Tine, 28-24 AWG, 10,000 pieces on reel	<u>1731120331</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, 22-18 AWG, 1000 Pieces	<u>1731121030</u>
FCT Machined Contact, Female, Crimp, 0.80µm Gold Plating, Split Tine, 24-20 AWG, 500 Pieces	<u>1731120215</u>
FCT Machined Contact, Female, Crimp, 0.80µm Gold Plating, Split Tine, 24-20 AWG, 5000 Pieces	<u>1731120733</u>
FCT Machined Contact, Female, Crimp, 0.20µm Gold Plating, Split Tine, 28-26 AWG, 500 Pieces	<u>1731120220</u>

This document was generated on Apr 10, 2026